

Artikel Nr.: 343020

Stehleuchte, Asterope linear, weiß, 220-240V AC/50-60Hz, 1x max. 100,00 W

Technische Daten

Charakteristik

Material	Metall
Farbe	weiß
Optik	matt
im Lieferumfang	2,30m Anschlusskabel mit Fußschalter



Elektrische Daten

Leistung	1x max. 100,00 W
Eingangsspannung	220-240V AC/50-60Hz
Eingangsstrom	
Fassung / Sockel	E27
Anzahl Sockel	1
Netzgerät	
Anschlussmöglichkeit	Netzstecker IP20
Schutzklasse I, II, III	II



Artikel Nr.: 343020

Stehleuchte, Asterope linear, weiß, 220-240V AC/50-60Hz, 1x max. 100,00 W

Lichtrichtung


Dreh- und Schwenkbereich	
Neigungswinkel	
Abstrahlverhalten	
Reflektor / Linse	



Abmessungen und Gewicht

Länge	0,00
Breite	0,00
Höhe	1600,00
Durchmesser	210,00
Gewicht	6000 g

Grenzwerte

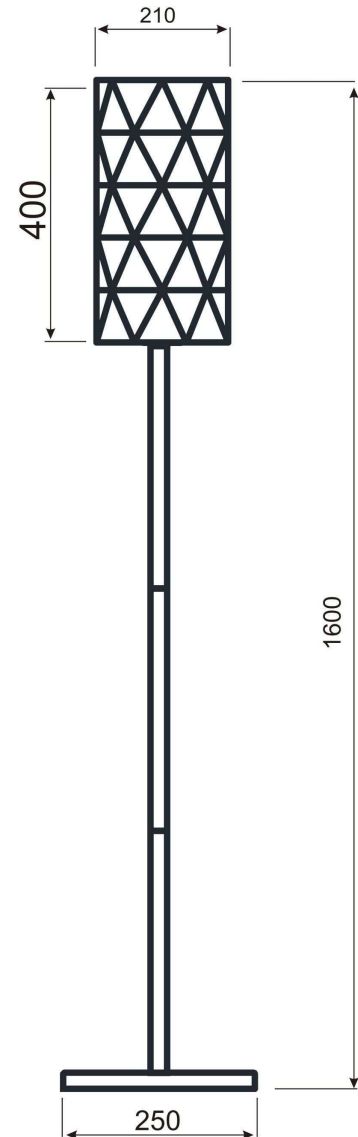Betriebstemperatur	-5°C - +40°C
Lagertemperatur	-10°C - +60°C
IP - Schutzart	IP20



EEI	Die Leuchte ist geeignet für Leuchtmittel der Energieeffizienzklassen A++ bis E
IP20	Schutz gegen das Eindringen von Fremdkörper > 50 mm. Kein Schutz gegen das Eindringen von Wasser.
	Leuchte der Schutzklasse II bei der der Schutz gegen elektrischen Schlag nicht allein auf der Basisisolierung beruht, sondern zusätzliche Sicherheitsvorkehrungen wie zusätzliche oder verstärkte Isolierung vorgesehen sind. Es sind weder Vorkehrungen für den Anschluss eines Schutzleiters vorhanden, noch beruht der Schutz auf den Einrichtungsbedingungen.
	Aufgrund des komplexen Herstellungsprozesses von LED stellen die angegebenen Werte nur rein statistische Größen dar und müssen nicht zwingend den tatsächlichen Parametern jedes einzelnen LED-Moduls entsprechen, sondern können von den typischen Werten abweichen.

Article no.: 343020

Floor lamp, Asterope linear, matt white, 220-240V AC/50-60Hz, 1x max. 100,00 W

Technical Data**General Characteristics**

Material	metal
Colour	matt white
Optics	
included in delivery	2,30m connection cable with foodswitcl

**Electrical Characteristics**

Power	1x max. 100,00 W
Input Voltage	220-240V AC/50-60Hz
Input current	
Base (standard designation)	E27
Number of Bases	1
Power supply unit	
Connection possibility	Powerplug IP20
Protection class I, II, III	II

Article no.: 343020

Floor lamp, Asterope linear, matt white, 220-240V AC/50-60Hz, 1x max. 100,00 W

Light Direction


Rotating and tilting range	
Angle of inclination	
Radiation direction	
Reflector / lense	

Dimensions & Weight

Length	0,00
Width	0,00
Height	1600,00
Diameter	210,00
Product Weight	6000 g

Absolute maximum ratings

Working temperature	-5°C - +40°C
Storage temperature	-10°C - +60°C
IP - Code	IP20

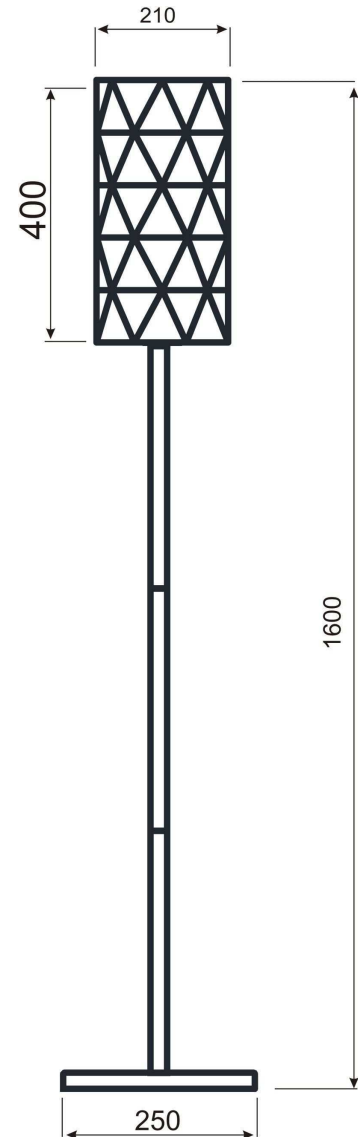

EEL The luminaire is suitable for lamps of energy efficiency classes A++ to E.

IP20 Protection against penetration of foreign objects > 50 mm. No protection against penetration of water.



Lightings of Protection Class II in which the protection against electric shock is not based solely on the insulation, but additional safety precautions such as additional or reinforced insulation are provided. There are no provisions for the connection of an equipment grounding conductor exists, yet underlying the protection of the facility conditions.



Because of the complex manufacturing process of the LED the above shown data are just a statistical size, which is not forced to be the realistic data of every LED.