

**Artikel Nr.: 343021**

Stehleuchte, Asterope linear, schwarz, 220-240V AC/50-60Hz, 1x max. 100,00 W

**Technische Daten****Charakteristik**

<b>Material</b>	Metall
<b>Farbe</b>	schwarz
<b>Optik</b>	matt
<b>im Lieferumfang</b>	2,30m Anschlusskabel mit Fußschalter

**Elektrische Daten**

<b>Leistung</b>	1x max. 100,00 W
<b>Eingangsspannung</b>	220-240V AC/50-60Hz
<b>Eingangsstrom</b>	
<b>Fassung / Sockel</b>	E27
<b>Anzahl Sockel</b>	1
<b>Netzgerät</b>	
<b>Anschlussmöglichkeit</b>	Netzstecker IP20
<b>Schutzklasse I, II, III</b>	II



**Artikel Nr.: 343021**

Stehleuchte, Asterope linear, schwarz, 220-240V AC/50-60Hz, 1x max. 100,00 W

**Lichtrichtung**


Dreh- und Schwenkbereich	
Neigungswinkel	
Abstrahlverhalten	
Reflektor / Linse	



**Abmessungen und Gewicht**

Länge	0,00
Breite	0,00
Höhe	1600,00
Durchmesser	210,00
Gewicht	6000 g

**Grenzwerte**

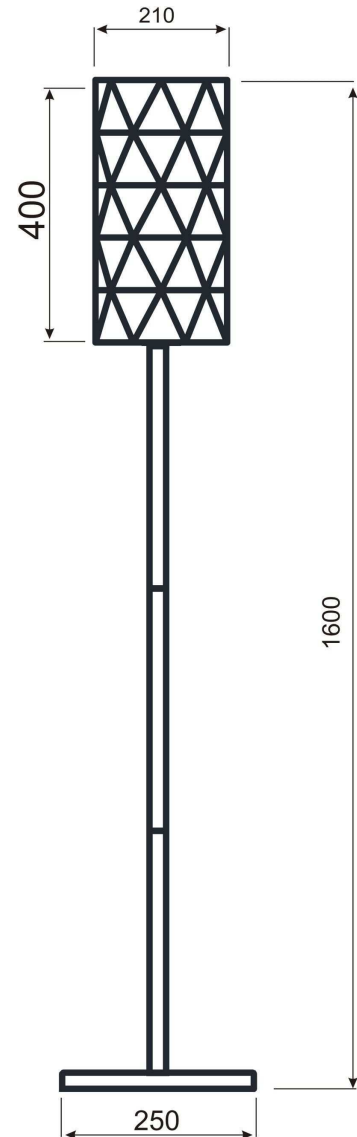Betriebstemperatur	-5°C - +40°C
Lagertemperatur	-10°C - +60°C
IP - Schutzart	IP20



EEI	Die Leuchte ist geeignet für Leuchtmittel der Energieeffizienzklassen A++ bis E
IP20	Schutz gegen das Eindringen von Fremdkörper > 50 mm. Kein Schutz gegen das Eindringen von Wasser.
	Leuchte der Schutzklasse II bei der der Schutz gegen elektrischen Schlag nicht allein auf der Basisisolierung beruht, sondern zusätzliche Sicherheitsvorkehrungen wie zusätzliche oder verstärkte Isolierung vorgesehen sind. Es sind weder Vorkehrungen für den Anschluss eines Schutzleiters vorhanden, noch beruht der Schutz auf den Einrichtungsbedingungen.
	Aufgrund des komplexen Herstellungsprozesses von LED stellen die angegebenen Werte nur rein statistische Größen dar und müssen nicht zwingend den tatsächlichen Parametern jedes einzelnen LED-Moduls entsprechen, sondern können von den typischen Werten abweichen.

**Article no.: 343021**

Floor lamp, Asterope linear, matt black, 220-240V AC/50-60Hz, 1x max. 100,00 W

**Technical Data****General Characteristics**

<b>Material</b>	metal
<b>Colour</b>	matt black
<b>Optics</b>	
<b>included in delivery</b>	2,30m connection cable with foodswitcl

**Electrical Characteristics**

<b>Power</b>	1x max. 100,00 W
<b>Input Voltage</b>	220-240V AC/50-60Hz
<b>Input current</b>	
<b>Base (standard designation)</b>	E27
<b>Number of Bases</b>	1
<b>Power supply unit</b>	
<b>Connection possibility</b>	Powerplug IP20
<b>Protection class I, II, III</b>	II



## Article no.: 343021

Floor lamp, Asterope linear, matt black, 220-240V AC/50-60Hz, 1x max. 100,00 W

### Light Direction


Rotating and tilting range	
Angle of inclination	
Radiation direction	
Reflector / lense	

### Dimensions & Weight

Length	0,00
Width	0,00
Height	1600,00
Diameter	210,00
Product Weight	6000 g

### Absolute maximum ratings

Working temperature	-5°C - +40°C
Storage temperature	-10°C - +60°C
IP - Code	IP20

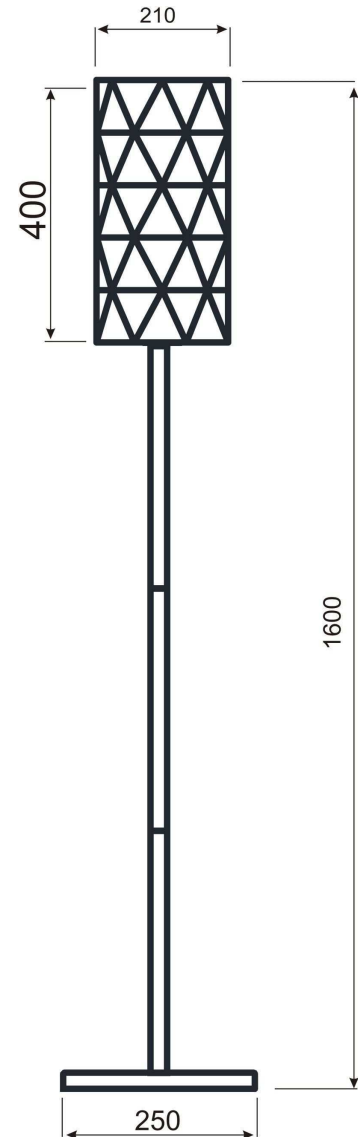

**EEL** The luminaire is suitable for lamps of energy efficiency classes A++ to E.

**IP20** Protection against penetration of foreign objects > 50 mm. No protection against penetration of water.



Lightings of Protection Class II in which the protection against electric shock is not based solely on the insulation, but additional safety precautions such as additional or reinforced insulation are provided. There are no provisions for the connection of an equipment grounding conductor exists, yet underlying the protection of the facility conditions.



Because of the complex manufacturing process of the LED the above shown data are just a statistical size, which is not forced to be the realistic data of every LED.