

Artikel Nr.: 341183

Wandaufbauleuchte, Cube, grau, 220-240V AC/50-60Hz, 1x max. 25,00 W

Technische Daten

Charakteristik

Material	Beton
Farbe	grau
Optik	
im Lieferumfang	



Elektrische Daten

Leistung	1x max. 25,00 W
Eingangsspannung	220-240V AC/50-60Hz
Eingangsstrom	
Fassung / Sockel	G9
Anzahl Sockel	1
Netzgerät	
Anschlussmöglichkeit	Klemme
Schutzklasse I, II, III	I

Artikel Nr.: 341183

Wandaufbauleuchte, Cube, grau, 220-240V AC/50-60Hz, 1x max. 25,00 W

Lichtrichtung


Dreh- und Schwenkbereich	feststehend
Neigungswinkel	
Abstrahlverhalten	2 Side
Reflektor / Linse	

Abmessungen und Gewicht

Länge	115,00
Breite	115,00
Höhe	115,00
Durchmesser	0,00
Gewicht	983 g

Grenzwerte

Betriebstemperatur	-5°C - +40°C
Lagertemperatur	-10°C - +60°C
IP - Schutzart	IP20

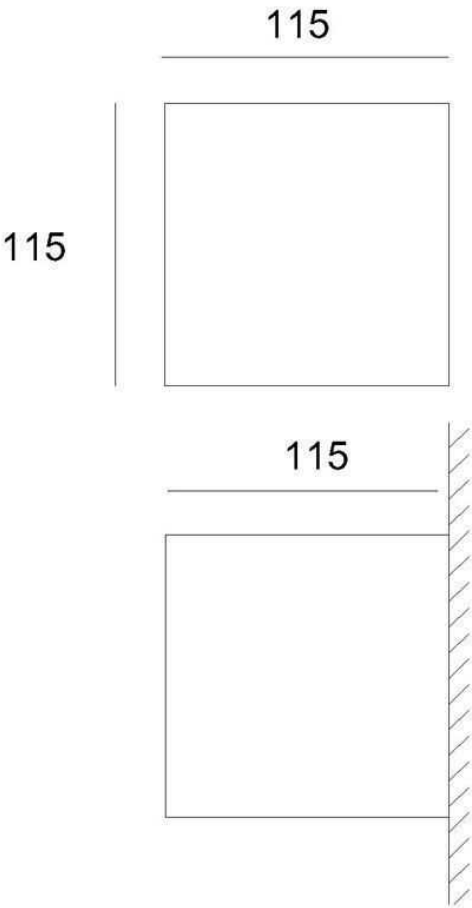

EEI	Die Leuchte ist geeignet für Leuchtmittel der Energieeffizienzklassen A++ bis E
IP20	Schutz gegen das Eindringen von Fremdkörper > 50 mm. Kein Schutz gegen das Eindringen von Wasser.
	Leuchte der Schutzklasse I bei der der Schutz gegen elektrischen Schlag nicht allein auf der Basisisolierung beruht, sondern die eine zusätzliche Sicherheitsvorkehrung derart enthält, dass berührbare leitfähige Teile mit Mitteln zum Anschluss an den Schutzleiter der festen Installation ausgerüstet sind, so dass im Fehlerfall der Basisisolierung berührbare leitfähige Teile nicht aktiv werden können.
	Aufgrund des komplexen Herstellungsprozesses von LED stellen die angegebenen Werte nur rein statistische Größen dar und müssen nicht zwingend den tatsächlichen Parametern jedes einzelnen LED-Moduls entsprechen, sondern können von den typischen Werten abweichen.

Article no.: 341183

Surface mounted wall lamp, Cube, gray, 220-240V AC/50-60Hz, 1x max. 25,00 W

Technical Data

General Characteristics

Material	concrete
Colour	gray
Optics	
included in delivery	



Electrical Characteristics

Power	1x max. 25,00 W
Input Voltage	220-240V AC/50-60Hz
Input current	
Base (standard designation)	G9
Number of Bases	1
Power supply unit	
Connection possibility	clamp
Protection class I, II, III	I

Article no.: 341183

Surface mounted wall lamp, Cube, gray, 220-240V AC/50-60Hz, 1x max. 25,00 W

Light Direction


Rotating and tilting range	fixed
Angle of inclination	
Radiation direction	2 Side
Reflector / lense	

Dimensions & Weight

Length	115,00
Width	115,00
Height	115,00
Diameter	0,00
Product Weight	983 g

Absolute maximum ratings

Working temperature	-5°C - +40°C
Storage temperature	-10°C - +60°C
IP - Code	IP20

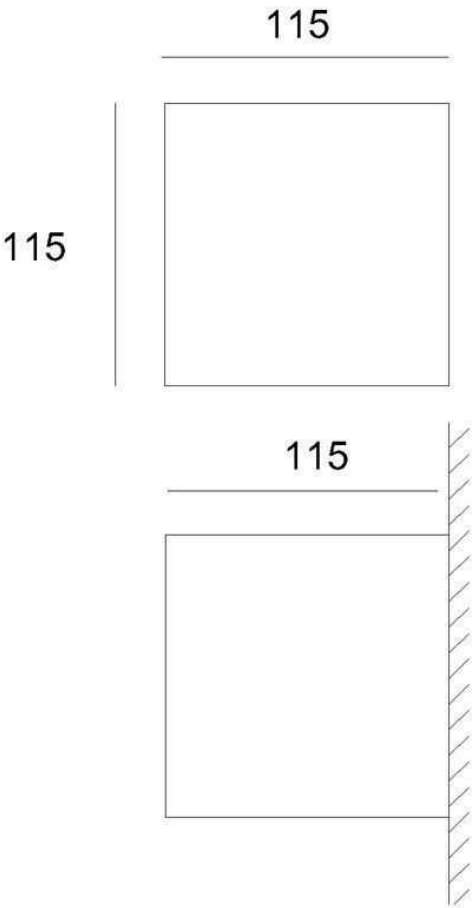

EEI	The luminaire is suitable for lamps of energy efficiency classes A++ to E.
IP20	Protection against penetration of foreign objects > 50 mm. No protection against penetration of water.
	Lightings of Protection Class I in which the protection against electric shock is not based solely on isolation, but an additional safety measure contains such a way that accessible conductive parts are equipped with means for connection to the protective conductor of the fixed installation, so that in case of failure of the basic insulation exposed conductive parts cannot be active.
	Because of the complex manufacturing process of the LED the above shown data are just a statistical size, which is not forced to be the realistic data of every LED.