

120WATT 2-WAY COAXIAL SPEAKER SET
16,5CM / 6,5"



120
WATT
50WATT RMS
SPEAKER SET

16,5 CM
6,5"

INCL.
SPEAKER
GRILL

CDS 6G



- Two 6.5" 2-way coaxial speakers with 30mm Mylar Dome tweeters
- **120W** max, **50W** RMS
- 4Ω impedance
- Sensitivity: 92dB/W/m +3dB
- Mounting depth: 56mm
- Mounting diameter: 143mm
- Mounting hardware included
- With Kevlar look IMPP cone




- Deux haut-parleurs coaxiaux à 2 voies de 6,5 pouces avec tweeters à dôme en Mylar de 30 mm
- **120W** max, **50W** RMS
- Impédance de 4Ω
- Sensibilité : 92dB/W/m +3dB
- Profondeur de montage : 56 mm
- Diamètre de montage : 143 mm
- Matériel de montage inclus
- Avec cône IMPP aspect Kevlar



8 714505 016764



Grill included

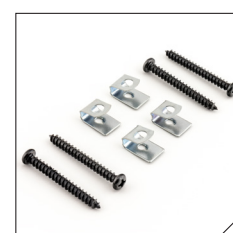

Incl. mounting material
screws + speed clips
(2 sets incl. > shown is 1 set)

CALIBER

120WATT 2-WAY COAXIAL SPEAKER SET
16,5CM / 6,5"



120 WATT
50WATT RMS
SPEAKER SET

16,5 CM
6,5"

INCL.
SPEAKER
GRILL

CDS 6G



- Zwei 6,5" 2-Wege-Koaxiallautsprecher mit 30-mm-Mylar-Kalottenhochtönern
- **120 W** maximal, **50W** RMS
- 4Ω Impedanz
- Empfindlichkeit: 92dB/W/m +3dB
- Einbautiefe: 56mm
- Einbaudurchmesser: 143mm
- Inklusive Befestigungsmaterial
- Mit IMPP-Kegel in Kevlar-Look




- Twee 6,5" 2-wegs coaxiale luidsprekers met 30mm Mylar Dome tweeters
- **120W** max, **50W** RMS
- 4Ω impedantie
- Gevoeligheid: 92dB/W/m +3dB
- Montagediepte: 56mm
- Inbouw diameter: 143mm
- Inclusief bevestigingsmateriaal
- Met IMPP-cone in Kevlar-look



8 714505 016764



Grill included

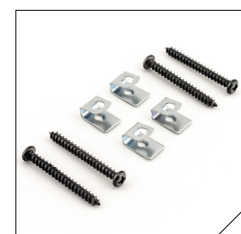

Incl. mounting material
screws + speed clips
(2 sets incl. > shown is 1 set)

CALIBER