

150WATT 3-WAY COAXIAL SPEAKER SET
15X23CM / 6X9" WITH GRILL



150
WATT
55WATT RMS
SPEAKER SET

6X9"
OVAL

INCL.
SPEAKER
GRILL

CDS 69G



- Two 6x9" 3-way coaxial speakers with 30mm Mylar Dome tweeters and 20mm Piezo tweeters
- **150W** max, **55W** RMS
- 4Ω impedance
- Sensitivity: 90dB/W/m
- Mounting depth: 71mm
- Mounting diameter: 153x220mm
- With Kevlar look IMPP cone




- Deux 6x9" haut-parleur coaxial à 3 voies avec tweeters dôme en mylar 30mm et tweeters piezo de 20mm
- **150W** max, **55W** RMS
- Impédance : 4Ω
- Sensibilité: 90dB/W/m
- Profondeur de montage: 71mm
- Diamètre de montage: 153x220mm
- Avec cône IMPP aspect Kevlar



8 714505 040103



Grill included

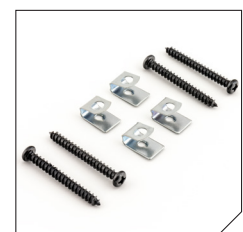

Incl. mounting material
screws + speed clips
(2 sets incl. > shown is 1 set)

CALIBER

150WATT 3-WAY COAXIAL SPEAKER SET
15X23CM / 6X9" WITH GRILL



150
WATT
55WATT RMS
SPEAKER SET

6X9"
OVAL

INCL.
SPEAKER
GRILL

CDS 69G



- Zwei 6x9" 3-Wege-Koaxiallautsprecher mit 30mm Mylar Dome-Hochtönern
- **150W** max, **55W** RMS
- 4Ω Impedanz
- Empfindlichkeit: 90dB/W/m
- Einbautiefe: 71mm
- Einbaudurchmesser: 153x220mm
- Mit IMPP-Kegel in Kevlar-Look




- Twee 6x9" 3-wegs coaxiale luidsprekers met 30mm Mylar Dome tweeters
- **150W** max, **55W** RMS
- 4Ω impedantie
- Gevoeligheid: 90dB/W/m
- Montagediepte: 71mm
- Inbouw diameter: 153x220mm
- Met IMPP-cone in Kevlar-look



8 714505 040103



Grill included

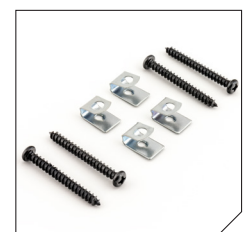

Incl. mounting material
screws + speed clips
(2 sets incl. > shown is 1 set)

CALIBER