

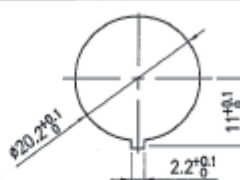


Data Sheet

LED indicator 24V DC, Red

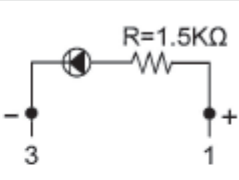

Rating	24V DC	Mounting Hole	Circuit Diagram
Insulation Resistance	DC 500V 100M ohm Min.		
Dielectric Strength	AC 1500V 1 minute		
Operation Temperature	-20°C~85°C		

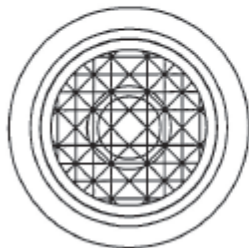

Material:
 Frame: Black, Nylon 66
 Lens: Red, PC
 LED: Red
 Printed: None

