

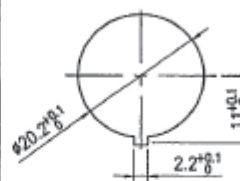


Data Sheet

LED indicator 24V DC, Green

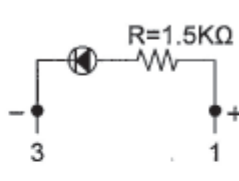

| Rating | 24V DC | Mounting Hole | Circuit Diagram |
|-----------------------|-----------------------|--|---|
| Insulation Resistance | DC 500V 100M ohm Min. |  |  |
| Dielectric Strength | AC 1500V 1 minute | | |
| Operation Temperature | -20°C~85°C | | |
| | | | |

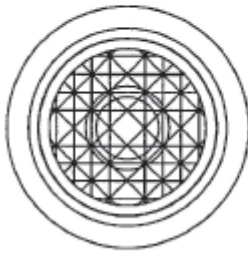

Material:
 Frame: black, nylon 66
 Lens: green, PC
 Terminals: tin plated brass
 LED: green

