
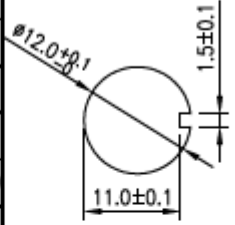


Data Sheet

Toggle switch 12V DC 20A, Green

Rating	20A 12V DC	Mounting Hole		Circuit Diagram	
Contact Resistance	50m ohm Max.				
Insulation Resistance	DC 500V 100M ohm Min.				
Dielectric Strength	AC 1500V 1 minute				
Operation Temperature	-20°C~85°C				
Switch Functlon	3P SPST ON-OFF (LED dependent)				

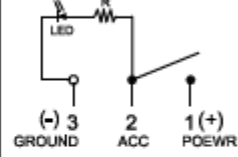