

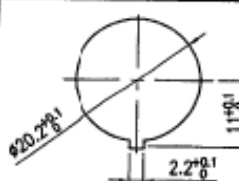


Data Sheet

LED indicator 24V DC, Blue

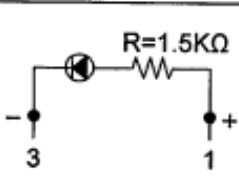

Rating	24V DC	Mounting Hole	Circuit Diagram
Insulation Resistance	DC 500V 100M ohm Min.		
Dielectric Strength	AC 1500V 1 minute		
Operation Temperature	-20°C~85°C		

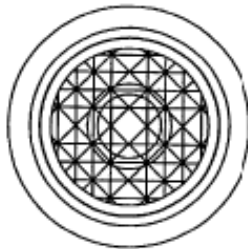

Material:
 Frame: black,nylon 66
 Lens: Blue, PC
 Terminals: tin plated brass
 LED: Blue

