

Smarter  
technology  
for all

# ThinkVision P24q-30 Monitor

## Designed for effortless productivity.

Boost your multitasking efficiency.

The ThinkVision P24q-30 Monitor is innovated to boost your productivity with speed and efficiency. The monitor's generous 23.8-inch QHD panel delivers crisp and clear views in a single glance. Its 3-side NearEdgeless design enables a distraction-free multiscreen experience. And with the In-Plane Switching panel, you can expect this high color accuracy and image quality from almost every angle - offering you an effective collaboration experience. View documents, images, graphics, and even videos you work on, in dynamically vivid and accurate colors with the monitor's 99% sRGB with Avg. Delta E<2, and HDR10 support. Multitask effortlessly by viewing more information at once with daisy chain, which lets you attach additional screens - horizontally or vertically. A dedicated USB Type-A at the top, offers a cableless modular VoIP solution for the addition of MC60 Monitor Webcam<sup>1</sup> and MS30 Monitor Soundbar<sup>1</sup>. The ergonomic stand with lift, tilt, swivel, and pivot functionality offers maximum flexibility to adjust the monitor for a comfortable viewing experience. A one-button joystick helps you quickly access display settings. The Natural Low Blue Light technology reduces harmful blue light emission while keeping on-screen colors true-to-life and enabling longer hours of comfortable working. In an effort to care for the environment, this monitor is delivered to you in a recyclable pulp package. The ThinkVision P24q-30 Monitor is designed to enhance efficiency, clarity, and comfort to improve your productivity.




## Features of ThinkVision P24q-30 Monitor



### Sharper display for superior efficiency.

With a sleek and slim 3-side NearEdgeless design, the ThinkVision P24q-30 Monitor's 23.8-inch display gives you a distraction-free on-screen experience. This QHD display delivers detail-oriented professionals with notably sharper images, line drawings, and texts. This monitor exhibits 99% sRGB with calibrated color accuracy (Avg. Delta E<2), especially crucial when performing professional tasks where color accuracy is critical. And with the addition of HDR10 support, you get a realistic visual experience with vividly dynamic contrasts. The ThinkVision P24q-30 Monitor's Natural Low Blue Light technology protects your eyes from harmful blue light emissions while retaining color accuracy.

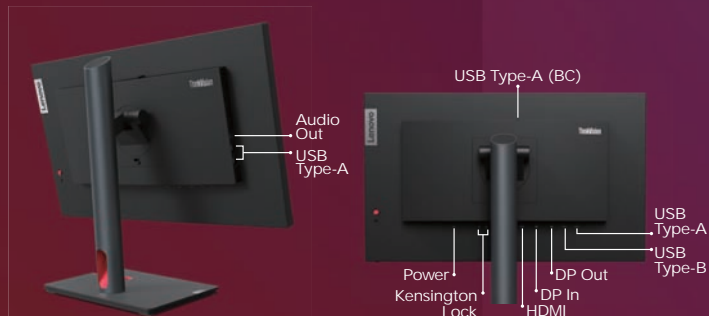

### Unleash limitless efficiency.

The ThinkVision P24q-30 Monitor's daisy chain support enhances your viewing experience and multitasking capabilities by allowing you to attach additional screens so you can view more information simultaneously. Personalize the monitor's settings to your preference with the integrated Lenovo ThinkColour Software's<sup>2</sup> on-screen menu that lets you toggle using the mouse for maximum comfort and a smoother user experience. A dedicated USB Type-A port at the top allows for MC60 Monitor Webcam and MS30 Monitor Soundbar<sup>1</sup> support that delivers video conferencing capabilities without the clutter of multiple wires and plugs.



### Designed for comfort, committed to sustainability.

The ThinkVision P24q-30 lets you adjust the monitor position for a comfortable, relaxing posture with the ergonomic stand's extensive lift, tilt, swivel, and pivot functionality. The ThinkVision P24q-30 Monitor's cable management clip ensures that your workspace is clutter-free. A flexible phone holder helps you keep your phone right where you can see it. The monitor's one-button joystick lets you customize the monitor's settings conveniently. ThinkVision P24q-30 is designed with the environment in mind and delivered a recyclable paper pulp cushion. All in all, the ThinkVision P24q-30 Monitor is crafted to cut the clutter, making your work environment comfortable, efficient, and sustainable.

<sup>1</sup> Sold separately. | <sup>2</sup> This software can only be used with Windows 10 & Windows 11.

# ThinkVision P24q-30 Monitor

## Display

**Panel Size**  
23.8-inch

**Screen Dimensions**  
534.9 mm x 303.1 mm

**Panel Type**  
3-side NearEdgeless  
In-Plane Switching

**Active Area**  
526.8 mm x 296.3 mm

**Backlight**  
WLED

**Aspect Ratio**  
16:9

**Resolution**  
2560 x 1440

**Pixel Pitch**  
0.205 mm x 0.205 mm

**Dot/Pixel Per Inch (DPI/PPI)**  
123

**Viewing Angle (H x V @ CR 10:1)**  
178° / 178°

**Response Time**  
4ms (Extreme Mode),  
6ms (Normal Mode)

**Refresh Rate**  
60 Hz

**Brightness (Typical)**  
300 cd/m<sup>2</sup>

**Contrast Ratio (Typical)**  
1000:1

**Dynamic Contrast Ratio (Typical)**  
3M:1

**Color Gamut (Coverage Ratio)**  
99.0% sRGB (CIE 1931),  
99.0% BT.709 (CIE 1976)

**Color Gamut (Color Area Ratio)**  
111.0% sRGB

**Color Support (Typical)**  
16.7 Million

**Color Depth**  
8-bit (6+FRC)

**HDR Compliance**  
Yes (HDR10)

**Anti-Glare**  
Yes

## Connectivity

**Video Signal**  
1 x HDMI 2.0  
1 x DP 1.4  
1 x DP Out

**Audio Signal**  
1 x Audio Out (3.5 mm)

**USB Hub**  
Yes

**USB Upstream**  
1 x USB 3.2 Gen 1<sup>1</sup> (by USB Type-B)

**USB Downstream**  
4 x USB 3.2 Gen 1<sup>1</sup> (1 x BC1.2)

## Multimedia

**Modular Camera/Speaker Support**  
Yes (Optional Support<sup>2</sup>)

## Special Features

**Factory Calibration**  
Yes (Delta-E Color Accuracy (<2))

**Software**  
Lenovo ThinkColour  
(Lenovo Display Control Center)<sup>3</sup>

**Natural Low Blue Light**  
Yes

## Power

**Power Consumption (Typ. / Max.)**  
25W / 65W

**Power Consumption Sleep/Off Mode**  
< 0.5W

**Power Consumption Switch-Off Mode**  
< 0.3W

**ENERGY STAR Power Consumption (Pon/E<sub>TEC</sub>)**  
16W / 49kWh

**Power Supply**  
Internal

**Voltage Required**  
AC 100 to 240 V (50-60 Hz)

## Mechanical

**Tilt Angle (Front / Back)**  
-5° / 23.5°

**Swivel Angle (Left / Right)**  
-45° / 45°

**Lift (Max. Range)**  
155 mm

**Pivot**  
-90° / 90°

**VESA Mount Capability**  
Yes (100 x 100 mm)

**Kensington Lock Slot**  
Yes

**Cable Management**  
Yes

**Bezel Color**  
Raven Black

**Bezel Width (Side)**  
2.0 mm

**Bezel Width (Top / Bottom)**  
2.0 / 18.0 mm

## Dimension

**Size Packed (D x H x W) (mm/inch)**  
160.0 x 420.0 x 620.0 mm  
6.30 x 16.54 x 24.41 inches

**Size Unpacked w/ Stand (Lowest Position) (D x H x W) (mm/inch)**  
199.7 x 348.8 x 539.5 mm  
7.86 x 13.73 x 21.24 inches

**Size Unpacked w/ Stand (Highest Position) (D x H x W) (mm/inch)**  
199.7 x 503.8 x 539.5 mm  
7.86 x 19.83 x 21.24 inches

**Size Unpacked w/o Stand (Head Only) (D x H x W) (mm/inch)**  
46.5 x 323.7 x 539.5 mm  
1.83 x 12.74 x 21.24 inches

**Weight Packed (kg / lbs.)**  
8.3 kg / 18.3 lbs.

**Weight Unpacked (kg / lbs.)**  
5.7 kg / 12.6 lbs.

**Weight (Monitor Head Only) (kg / lbs.)**  
3.8 kg / 8.4 lbs.

## What's in the Box

**Monitor with Stand**  
Yes

**Power Cable (Cable Length)**  
1 x Power Cable (1.8 m)

**DP Cable (Cable Length)**  
1 x DP 1.2 Cable (1.8 m)

**HDMI Cable (Cable Length)**  
1 x HDMI 2.0 Cable (1.8 m)  
(For PRC WS and PRC SA;  
No for ROW NA, EMEA, AP, and LA)

**USB Cable (Cable Length)**  
USB Type-A to Type-B Cable (1.8 m)

**Factory Calibration Report**  
Yes

**Quick Setup Guide**  
Yes

**Warranty Booklet**  
Yes

## Certification

**ENERGY STAR Certification**  
Yes

**CCC**  
Yes

**TCO**  
9.0

**TCO Edge**  
2.0

**EPEAT**  
Gold

**Volatile Organic Compound Certification**  
Yes

**RoHS (2011/65/EU)**  
Yes

**Windows Certification**  
Windows 10, Windows 11

**China Energy Efficiency Standard**  
Tier 1

**TÜV Rheinland Eye Comfort**  
Yes

**TÜV Rheinland Low Blue Light**  
Yes

**TÜV Rheinland Flicker Free**  
Yes

**TÜV Low Blue Light (Hardware Solution)**  
Yes

**Eyesafe Display Certification**  
Yes



<sup>1</sup> Depending on many factors such as the processing capability of peripheral devices, file attributes, and other factors related to system configuration and operating environments, the actual transfer rate using the various USB connectors on this device will vary and is typically slower than the data rates as defined by the respective USB specifications: 5 Gbit/s for USB 3.2 Gen 1; 10 Gbit/s for USB 3.2 Gen 2 & 20 Gbit/s for USB 3.2 Gen2x2.  
<sup>2</sup> Compatible with ThinkVision VoIP Stack MC60 Monitor Webcam and MS30 Monitor Soundbar. <sup>3</sup> This software can only be used with Windows 10 & Windows 11.

© 2022 Lenovo. All rights reserved. These products are available while supplies last. Prices shown are subject to change without notice. For any questions concerning price, please contact your Lenovo Account Executive. Lenovo is not responsible for photographic or typographic errors. Warranty: For a copy of applicable warranties, write to: Warranty Information, 500 Park Offices Drive, RTP, NC 27709, U.S.A., Attn: Dept. ZPYA/B600. Lenovo makes no representation or warranty regarding third-party products or services. Trademarks: Lenovo, the Lenovo logo, Rescue and Recovery, ThinkPad, ThinkCentre, ThinkStation, ThinkVantage, ThinkVision, and ThinkColour are trademarks or registered trademarks of Lenovo. Microsoft, Windows, and Vista are registered trademarks of Microsoft Corporation. Intel, the Intel logo, Intel Inside, Intel Core, and Core Inside are trademarks of Intel Corporation in the U.S. and/or other countries. Other company, product, and service names may be trademarks or service marks of others. Specifications may vary depending upon region.

Smarter  
technology  
for all

Lenovo