





BOSCH

D-CO

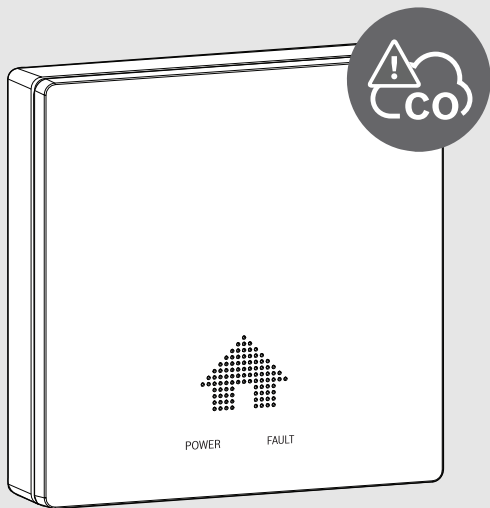

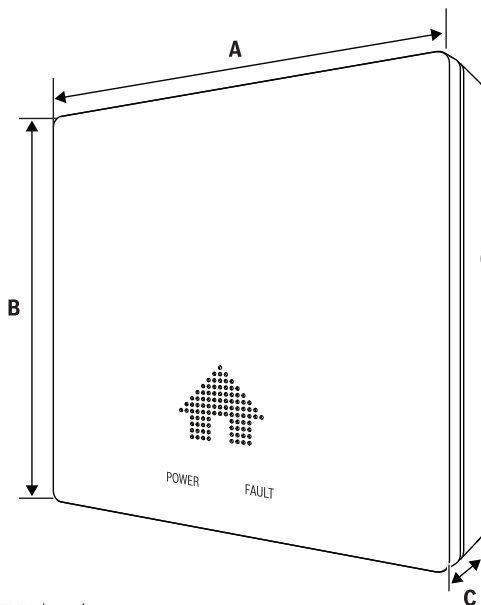

BS EN50291-1:2018



KM616830

0010043045-002


D-CO
A 95 mm

B 95 mm

C 25 mm


120 g



Type B



10 y





-10 ... 45 °C



25 ... 95 RH%












≥85 dB@3m

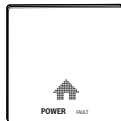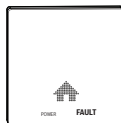
Power

Fault


Alarm

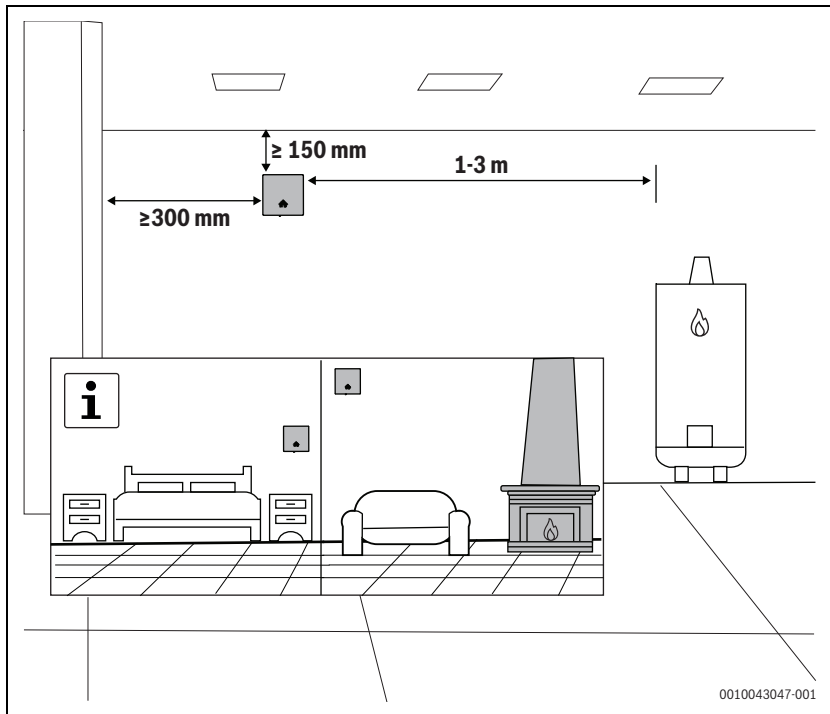
0010043046-001

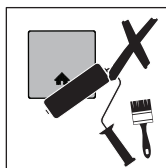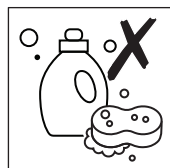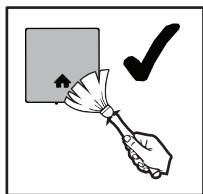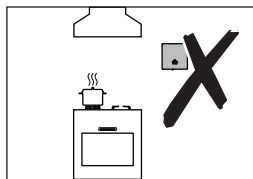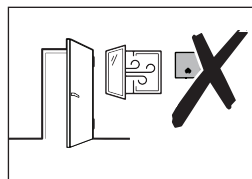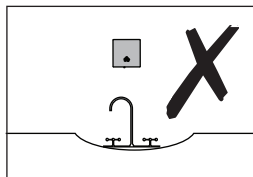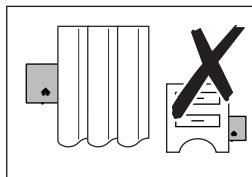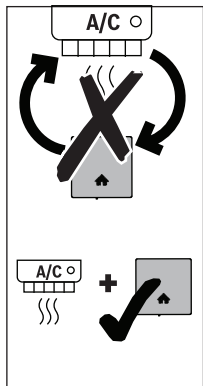





0010043048-001

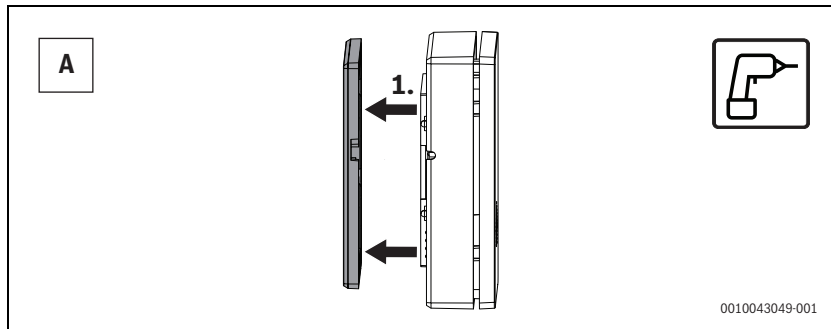


5

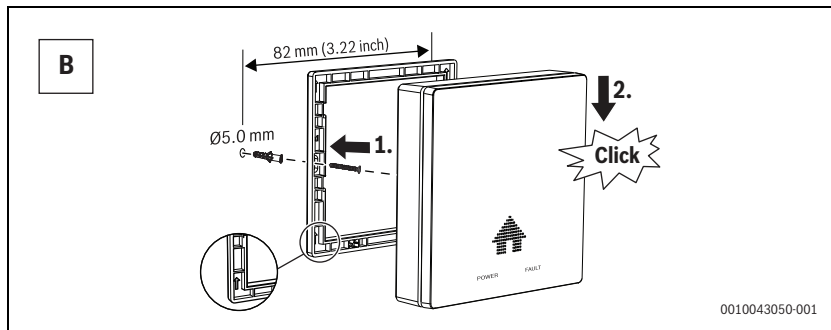


6

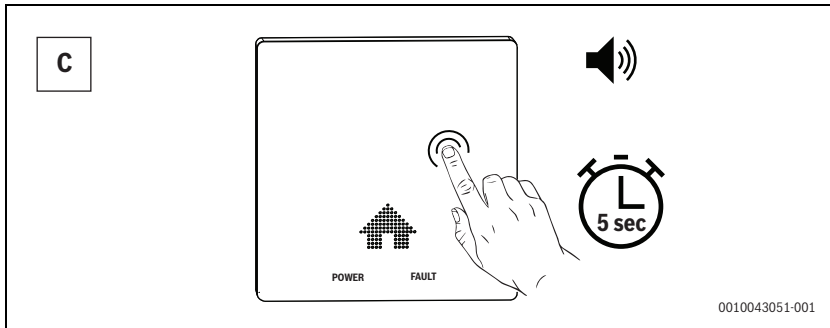


7

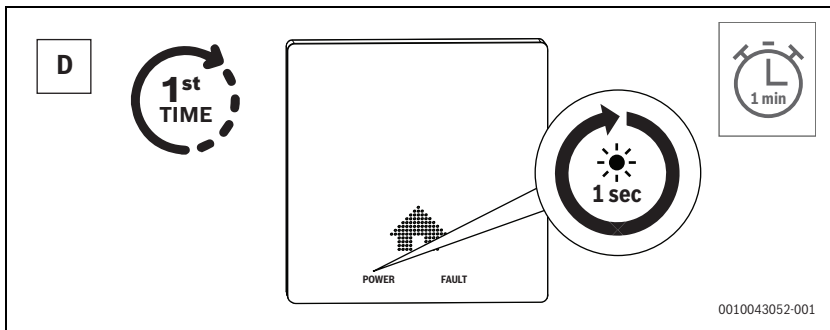




8

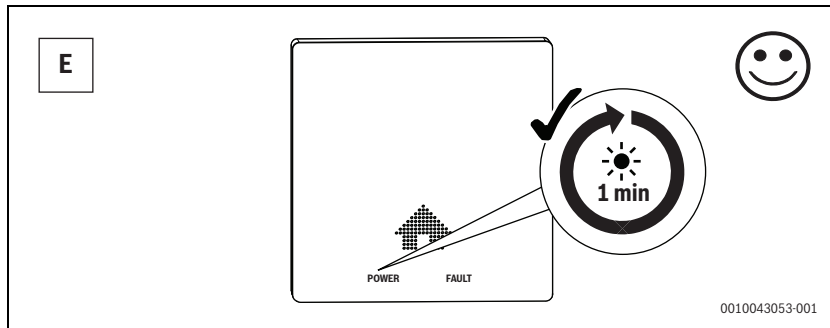





9

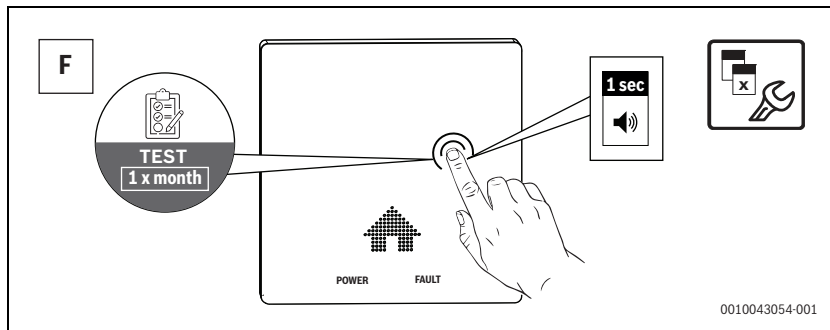



10

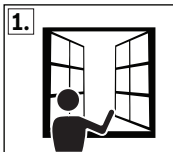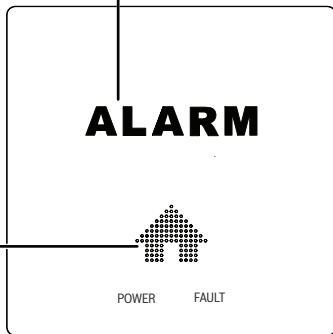 



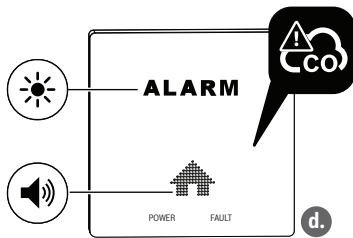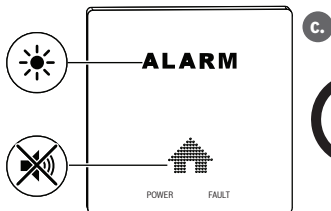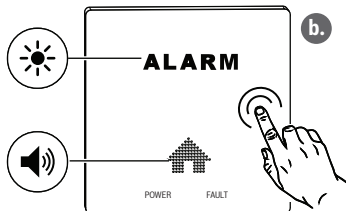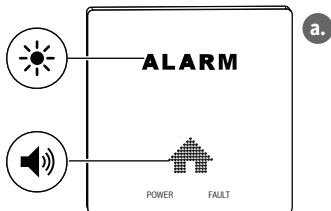



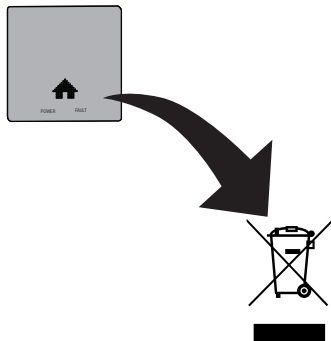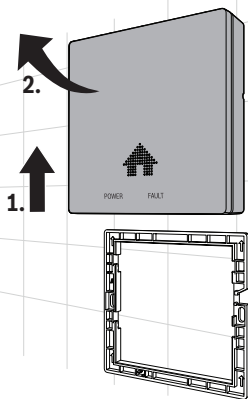




 







 


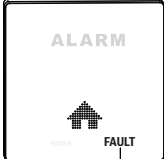

0010043055-001




0010043056-001



0010043057-001

 	 1x — — 1x   1min		  X 9 h	
  	 2x — — 2x   1min	 Fault		  
	 3x — — 3x   1min	 End of life		<p style="text-align: right;">0010043058-001</p>

 

0010043059-001





Bosch Thermotechnik GmbH
Junkersstrasse 20-24
D-73249 Wernau

www.bosch-thermotechnology.com

Importer

Bosch Thermotechnology Ltd.
Cotswold Way, Warndon
Worcester WR4 9SW
United Kingdom