

ThinkVision T24i-30 Monitor

Inspired by design.
Designed to inspire.

Smarter
technology
for all

Stunning power to get you ahead.

Locked and loaded with a whole lot of innovation, the ThinkVision T24i-30 Monitor is powered to help you seize every day. This ample 23.8-inch FHD IPS screen with a wide color gamut of 99% sRGB makes its vibrancy and color accuracy a delight to look at even from wide angles. You can adjust the monitor for a more convenient and enjoyable viewing experience with the ergonomic stand's tilt, lift, swivel, and pivot functions. Or simply VESA mounts it to save more desk space. With 90% screen real estate, it's built with a 3-side NearEdgeless bezel design, so your view has fewer distractions and more of what needs to be seen. Integrated Natural Low Blue Light technology reduces toxic blue light while delivering high-fidelity colors. In addition, the ThinkVision T24i-30 Monitor's TÜV Rheinland Eye Comfort certification, lets you do more by protecting your eyes from fatigue even during long hours at work. Take functionality to a whole new level by connecting an endless list of devices compatible with the connectivity hub, including VGA, DP 1.2, HDMI 1.4, and four USB 3.0 ports. Connect your external sound systems conveniently with the Audio Out port. You can also view more data and multitask more efficiently with multi-monitor support. This monitor packs a world of features without impacting the environment by following the latest TCO 9.0 regulations. The ThinkVision T24i-30 Monitor is a powerhouse built to make working a pleasure.



Features of ThinkVision T24i-30 Monitor




Envision the brilliance

It's easy to admire the ThinkVision T24i-30 Monitor's vivid and dynamic picture quality from any angle with its FHD IPS display. The 99% sRGB color gamut brings to life brilliant color accuracy, especially important when dealing with visual tasks. With the ergonomic stand, you can lift, tilt, swivel, and pivot the monitor conveniently for a comfortable viewing experience, that's convenient especially while collaborating. Its lift range, at 155 mm, is comfortable for most users. At its lowest position, the ThinkVision T24i-30 Monitor is designed to enhance your comfort every minute of the day.



Extensive connectivity

Widen your horizons by plugging an extensive range of devices and accessories into the ThinkVision T24i-30 Monitor, with a comprehensive range of ports, including VGA, DP 1.2, and HDMI 1.4. Customize your audio experience for shared meetings and content by plugging your external audio systems with the Audio Out port. Need to import or export large files? No problem. The four USB 3.0 ports allow you to transfer data at a super speed of 5 Gbps so that nothing slows you down. The ThinkVision T24i-30 Monitor lets you do more by expanding your view vertically or horizontally by connecting additional screens with multi-monitor support.

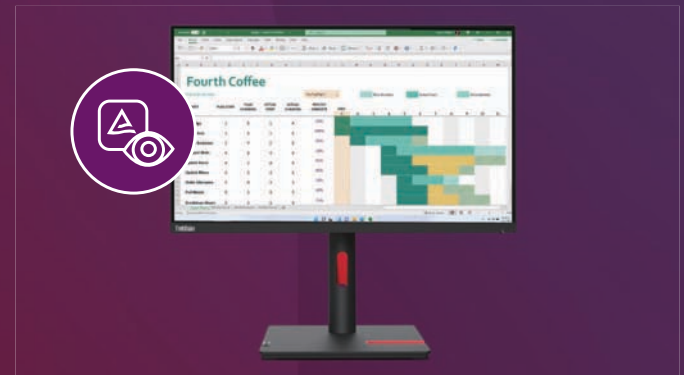

Environment-friendly. User-friendly.

Navigate and customize the ThinkVision T24i-30 Monitor's settings to your preferred settings with the easy-to-use joystick placed behind the screen. The monitor features Natural Low Blue Light technology reducing harmful blue light without compromising high color fidelity. TÜV Rheinland Eye Comfort certification keeps your vision refreshed and fatigue-free even after hours of work. This monitor brings you the best features with minimal impact on the environment throughout its lifecycle. It's made in compliance with the latest TCO 9.0 regulations and made with 90% recyclable materials and is fully packaged using paper pulp, to protect the planet.

ThinkVision T24i-30 Monitor

Display

Panel Size
23.8-inch

Screen Dimensions
535.0 mm x 313.0 mm

Panel Type
3-side NearEdgeless In-Plane Switching

Active Area
527.0 mm x 296.5 mm

Backlight
WLED

Aspect Ratio
16:9

Resolution
1920 x 1080

Pixel Pitch
0.275 mm x 0.275 mm

Dot/Pixel Per Inch (DPI/PPI)
93

Viewing Angle (H x V @ CR 10:1)
178° / 178°

Response Time
4ms (Extreme Mode), 6ms (Normal Mode)

Refresh Rate
60Hz

Brightness (Typical)
250 cd/m²

Contrast Ratio (Typical)
1000:1

Dynamic Contrast Ratio (Typical)
3M:1

Color Gamut (Coverage Ratio)
99% sRGB

Color Gamut (Color Area Ratio)
110% sRGB

Color Support (Typical)
16.7 Million

Color Depth
6-bit (Hi+FRC)

Anti-glare
Yes

Connectivity

Video Signal
1 x HDMI 1.4
1 x DP 1.2
1 x VGA

Audio Signal
1 x Audio Out (3.5 mm)

USB Hub
Yes

USB Upstream
1 x USB 3.0

USB Downstream
4 x USB 3.0

Special Features

Software
Lenovo ThinkColour (Lenovo Display Control Center)*

Natural Low Blue Light
Yes

Power

Power Consumption (Typ. / Max.)
14W / 51W

Power Consumption Sleep/Off Mode
< 0.5W

Power Consumption Switch-Off Mode
< 0.3W

ENERGY STAR Power Consumption (Pon/E_{TEC})
12W / 38kWh

Power Supply
Internal

Voltage Required
AC 100 to 240 V (50-60Hz)

Mechanical

Tilt Angle (Front / Back)
-5° / 23.5°

Swivel Angle (Left / Right)
-45° / 45°

Lift (Max. Range)
155 mm

Pivot
-90° / 90°

VESA Mount Capability
Yes (100 x 100 mm)

Kensington Lock Slot
Yes

Cable Management
Yes

Bezel Color
Raven Black

Bezel Width (Side)
2.0 mm

Bezel Width (Top / Bottom)
2.0 mm / 17.1 mm

Dimension

Size Packed (D x H x W) (mm/inch)
152.0 x 422.0 x 592.0 mm
5.98 x 16.61 x 23.31 inches

Size Unpacked w/ Stand (Lowest Position) (D x H x W) (mm/inch)
199.7 x 349.8 x 539.8 mm
7.86 x 13.77 x 21.25 inches

Size Unpacked w/ Stand (Highest Position) (D x H x W) (mm/inch)
199.7 x 504.8 x 539.8 mm
7.86 x 19.87 x 21.25 inches

Size Unpacked w/o Stand (Head Only) (D x H x W) (mm/inch)
49.0 x 321.4 x 539.8 mm
1.93 x 12.65 x 21.25 inches

Weight Packed (kg / lbs.)
7.8 kg / 17.2 lbs.

Weight Unpacked (kg / lbs.)
5.4 kg / 11.9 lbs.

Weight (Monitor Head Only) (kg / lbs.)
3.4 kg / 7.5 lbs.

What's in the Box

Monitor with Stand
Yes

Power Cable (Cable Length)
1 x Power Cable (for standalone 1.8m)

HDMI Cable (Cable Length)
1 x HDMI Cable (1.8m)

USB Cable (Cable Length)
1 x USB Type-A to Type-B (1.8m)

Quick Setup Guide
Yes

Warranty Booklet
Yes

Certification

ENERGY STAR Certification
Yes

CCC
Yes

TCO
9.0

TCO Edge
2.0

EPEAT
Gold

Volatile Organic Compound Certification
Yes

RoHS (2011/65/EU)
Yes

Windows Certification
Windows 10, Windows 11

China Energy Efficiency Standard
Tier 1

TÜV Rheinland Low Blue Light
Yes

TÜV Rheinland Flicker Free
Yes

TÜV Low Blue Light (Hardware Solution)
Yes

Eyesafe Display Certification
Yes



* This software can only be used with Windows 10 & Windows 11.

© 2022 Lenovo. All rights reserved. These products are available while supplies last. Prices shown are subject to change without notice. For any questions concerning price, please contact your Lenovo Account Executive. Lenovo is not responsible for photographic or typographic errors. Warranty: For a copy of applicable warranties, write to: Warranty Information, 500 Park Offices Drive, RTP, NC 27709, U.S.A., Attn: Dept. ZPYA/B600. Lenovo makes no representation or warranty regarding third-party products or services. Trademarks: Lenovo, the Lenovo logo, Rescue and Recovery, ThinkPad, ThinkCentre, ThinkStation, ThinkVantage, ThinkVision, and ThinkColour are trademarks or registered trademarks of Lenovo. Microsoft, Windows, and Vista are registered trademarks of Microsoft Corporation. Intel, the Intel logo, Intel Inside, Intel Core, and Core Inside are trademarks of Intel Corporation in the U.S. and/or other countries. Other company, product, and service names may be trademarks or service marks of others.

Specifications may vary depending upon region.

Smarter
technology
for all

Lenovo