




CONCRETO M

WL, recessed wall light grey, 8.5W, 350lm, 3000K

The concrete CONCRETO M wall-mounted light adds a fresh touch to outdoor areas. With a colour temperature of 3000 Kelvin, the integrated LED bulb emits a very pleasant, warm white light with a particularly sustainable lifespan of 50,000 hours. Thanks to the IP65 protection class rating, the grey concrete light is ideally protected against penetration by dirt or moisture.

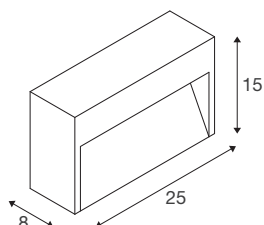

TECHNICAL DATA

Item no.	1006404
IP Code	IP 65
Impact resistance class	IK 02
Impact resistance	0.2 Joule
Assembly	Surface
Assembly details	Wall
Primary nominal voltage	220-240V ~50/60Hz
Secondary power / voltage	700 mA
Safety class	II
Wattage	8.5 W
Minimum ambient temperature	-20 °C
Maximum ambient temperature	35 °C
Operating efficiency (LOR)	0,38
Number of luminaires at LS B16A	92
Number of luminaires at LS C16A	92
Level of inrush current	4.7 A
Duration of inrush current	30 µs
Temperature at glass (light emission)	46 °C
Lumen	270 lm
Colour temperature	3000 Kelvin
Color	grey
CRI	80

Light Source

1319289	
---------	---

LXXBXX data	L80B50
Service life	50000 h
Risk Group	0
Width	25 cm
Height	15 cm
Depth	8 cm
Net weight	3 kg
Gross weight	3.21 kg