



Parts List



Shell x1

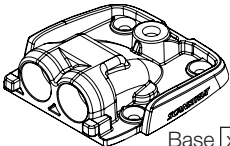

Base x1

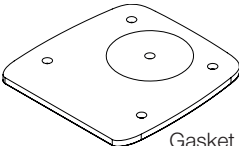

Gasket x1



M5X10 Bolt - (Black)
x1



No. 6 X16
Self tapping screw
x4



2x Blank



2x 5mm



2x 6mm

Bungs x6

Tools Required



Pozi Screwdriver



Silicone



ø2.5mm (3/32")
ø3mm (1/8")
Drill Bit



ø25mm (1")
Hole Saw/Drill Bit

1


Choose bung closest to cable ø.

DE - Wähle Dichtung nahe dem Kabel ø.


IT - Scegliere il passafili adatto al ø del cavo.

ES - Elija el tapón con el diámetro más parecido al cable.

FR - Choisissez le joint le plus proche du diamètre du câble.

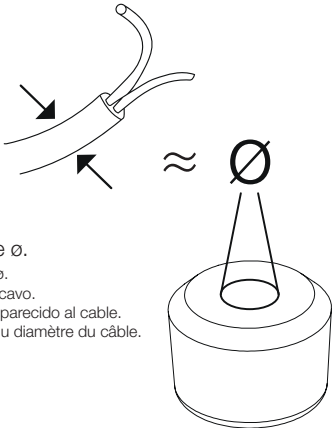


2

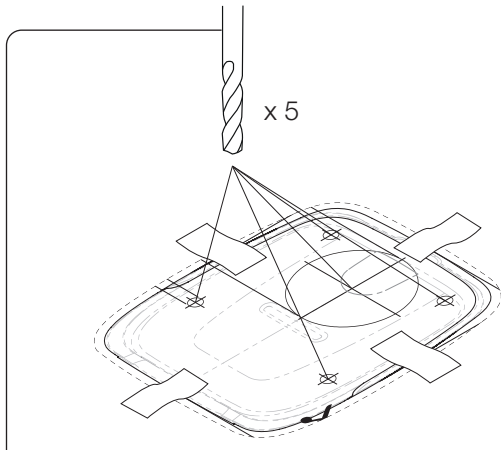


Material	Drill	Fixing
Soft Material e.g. plywood	2.5mm (3/32")	No.6 Screw (Included)
Hard Material e.g. fiberglass, hardwoods, acrylics	3mm (1/8")	
Metal e.g. Steel, aluminium	3mm (1/8")	<u>Recommended</u> >12mm x M3 Countersunk Bolt with washer and Nyloc (Not included)

3

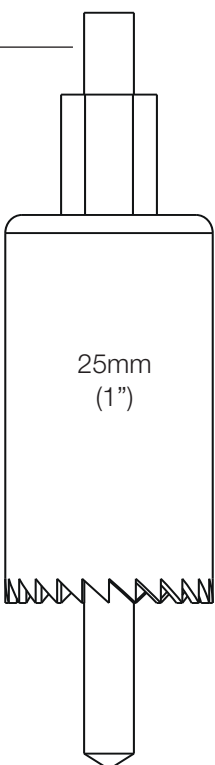


4


Deburr

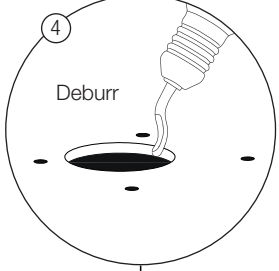

5

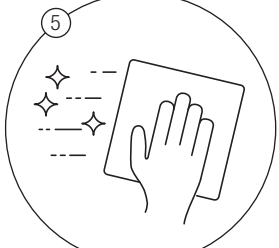

6


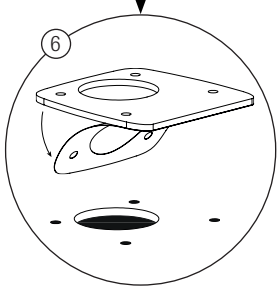


UK & International
+44 (0)1392531280
sales@scanstrut.com

For further installation
and warranty information
please visit:
www.scanstrut.com

USA
+1 860 308 1416
usasales@scanstrut.com

SCANSTRUT®

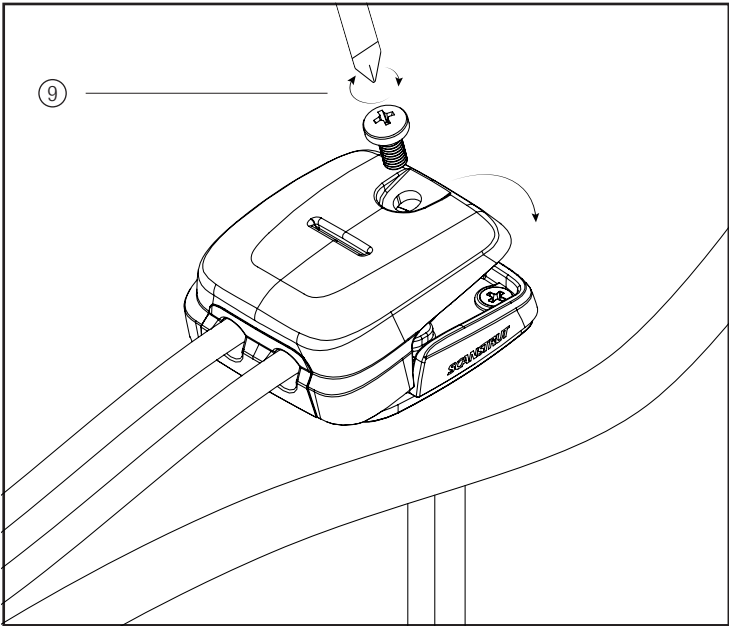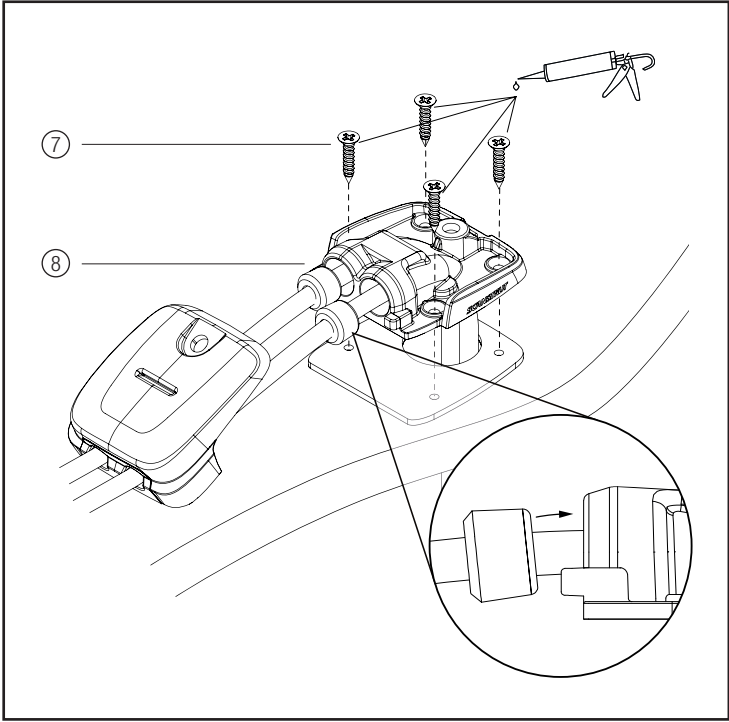

Cutting Template

Width: (54)
Height: (63)
Central circular cutout: $\varnothing 25.00$
Warning Check Scale: 50 mm, 2"

Print document 1:1 Scale
for correct cutting template size.

Share your installation with us.



UK & International
+44 (0)1392531280
sales@scanstrut.com

For further installation
and warranty information
please visit:
www.scanstrut.com

USA
+1 860 308 1416
usasales@scanstrut.com

