



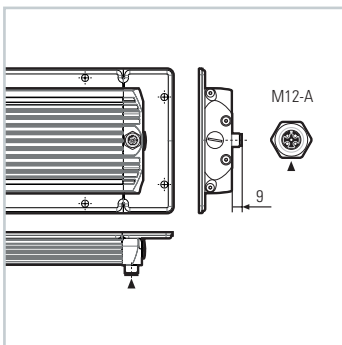

FIELDLED EVO 790_96 Einbau, 790 mm, 24V DC

Artikel-Nr.: 153210-12
EAN: 4260556625522

Bestell-Nr.: 153210-12
Modell: FIELDLED EVO 96 Einbau
Bauform: LED Einbauleuchte für Maschinen
Leuchtmittel: SMD LED
Lampenleistung: ~58 W
Lampenlichtstrom: 9000 lm
Lampenlichtausbeute: 155 lm/W
Lichtverteilung: direkt
Lichtfarbe: Tageslichtweiß (5200 - 5700K)
Anschlusswert Leuchte: 24V DC \pm 10%
Anschluss Leuchte: M12 Sensorstecker A-kodiert, rückseitig
Schutzart: IP67/IP69K
Schutzklasse: III
Entblendung: Mikroprismen
Abstrahlwinkel: 100°
Betriebstemperatur: -30... +60 °C
Farbwiedergabe (Ra): > 85
Lampenlebensdauer: > 60.000 h
Material Gehäuse: Aluminium
Material Abdeckung: ESG (Sicherheitsglas), splitterfrei
Höhe [B] x Breite [C]: 30 x 96 mm, Rahmen: 5,6 x 132 mm
Länge [A]: 790 mm, Rahmen: 846 mm
Gewicht: ~2600 g
Bruttogewicht: ~3500 g
Risikogruppe: freie Gruppe
Dimmbar: optional über Zubehör
Kennzeichnung: CE, ETL Listed
Gefertigt in: Deutschland

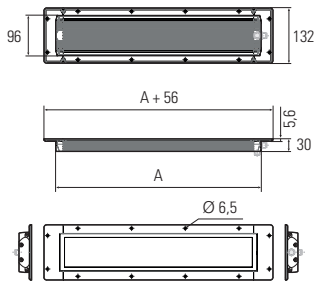



Lampenlebensdauer in Betriebsstunden (L80/B10)



FIELDLED EVO 790_96 Einbau, 790 mm, 24V DC

Item number: 153210-12
EAN: 4260556625522

Order number:	153210-12
Model:	FIELDLED EVO 96 Einbau
Type:	LED recessed luminaire for machines
Illuminant:	SMD LED
Power consumption:	~58 W
Lamp luminous flux:	9000 lm
Lamp luminous efficiency:	155 lm/W
Light distribution:	direct
Light colour:	daylight white (5200 - 5700K)
Connected load:	24V DC \pm 10%
Connection:	M12 sensor connector, A-type encoded, on the back
Degree of protection:	IP67/IP69K
Class of protection:	III
Glare-free	microprism
Beam angle (optics):	100°
Operating temperature:	-30... +60 °C
Colour rendering (Ra):	> 85
Lamps lifetime:	> 60,000 h
Housing material:	aluminium
Cover material:	ESG (toughened safety glass), shatterproof
Height [B] x Width [C]:	30 x 96 mm, frame: 5,6 x 132 mm
Length [A]:	790 mm, frame: 846 mm
Weight (net):	~2600 g
Gross weight:	~3500 g
Risk group (DIN EN 62471):	free group
Dimmable:	via optional accessory
Marking:	CE, ETL Listed
Made in:	Germany

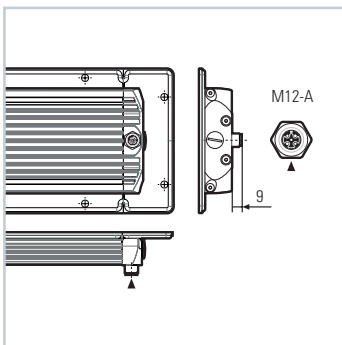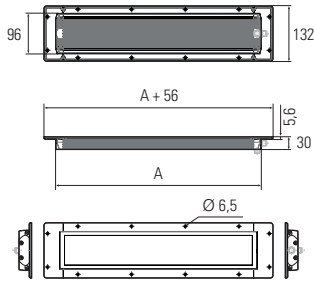

Lamps lifetime in operation hours (L80/B10)