



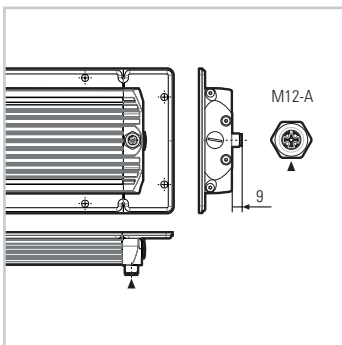

FIELDLED EVO 1040_96 Einbau, 1040 mm, 24V DC

Artikel-Nr.: 153310-12
EAN: 4260556625560

Bestell-Nr.:	153310-12
Modell:	FIELDLED EVO 96 Einbau
Bauform:	LED Einbauleuchte für Maschinen
Leuchtmittel:	SMD LED
Lampenleistung:	~78 W
Lampenlichtstrom:	12000 lm
Lampenlichtausbeute:	155 lm/W
Lichtverteilung:	direkt
Lichtfarbe:	Tageslichtweiß (5200 - 5700K)
Anschlusswert Leuchte:	24V DC ± 10%
Anschluss Leuchte:	M12 Sensorstecker A-kodiert, rückseitig
Schutzart:	IP67/IP69K
Schutzklasse:	III
Entblendung:	Mikroprismen
Abstrahlwinkel:	100°
Betriebstemperatur:	-30... +60 °C
Farbwiedergabe (Ra):	> 85
Lampenlebensdauer:	> 60.000 h
Material Gehäuse:	Aluminium
Material Abdeckung:	ESG (Sicherheitsglas), splitterfrei
Höhe [B] x Breite [C]:	30 x 96 mm, Rahmen: 5,6 x 132 mm
Länge [A]:	1040 mm, Rahmen: 1096 mm
Gewicht:	~3450 g
Bruttogewicht:	~4250 g
Risikogruppe:	freie Gruppe
Dimmbar:	optional über Zubehör
Kennzeichnung:	CE, ETL Listed
Gefertigt in:	Deutschland

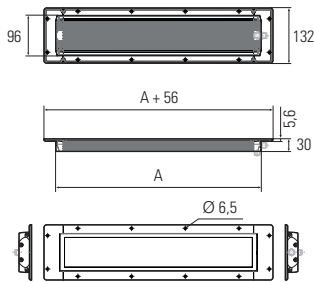



Lampenlebensdauer in Betriebsstunden (L80/B10)



FIELDLED EVO 1040_96 Einbau, 1040 mm, 24V DC

Item number: 153310-12
EAN: 4260556625560

Order number: 153310-12
Model: FIELDLED EVO 96 Einbau
Type: LED recessed luminaire for machines
Illuminant: SMD LED
Power consumption: ~78 W
Lamp luminous flux: 12000 lm
Lamp luminous efficiency: 155 lm/W
Light distribution: direct
Light colour: daylight white (5200 - 5700K)
Connected load: 24V DC \pm 10%
Connection: M12 sensor connector, A-type encoded, on the back
Degree of protection: IP67/IP69K
Class of protection: III
Glare-free: microprism
Beam angle (optics): 100°
Operating temperature: -30... +60 °C
Colour rendering (Ra): > 85
Lamps lifetime: > 60,000 h
Housing material: aluminium
Cover material: ESG (toughened safety glass), shatterproof
Height [B] x Width [C]: 30 x 96 mm, frame: 5,6 x 132 mm
Length [A]: 1040 mm, frame: 1096 mm
Weight (net): ~3450 g
Gross weight: ~4250 g
Risk group (DIN EN 62471): free group
Dimmable: via optional accessory
Marking: CE, ETL Listed
Made in: Germany

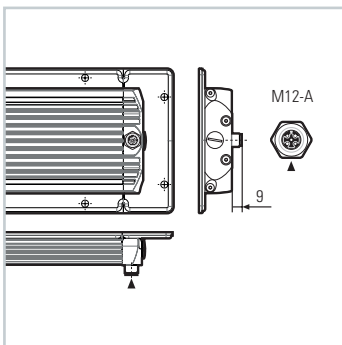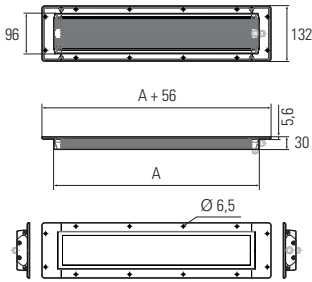

Lamps lifetime in operation hours (L80/B10)