

110310-01



TUBELED_70, 100°, 300 mm, 24V DC

Artikel-Nr.:	110310-01
EAN:	4260556621319
Bestell-Nr.:	110310-01
Modell:	TUBELED_70 DC
Bauform:	LED Aufbauleuchte für Maschinen
Leuchtmittel:	High Power LED
Lampenleistung:	~15 W
Lampenlichtstrom:	1848 lm
Lampenlichtausbeute:	ca. 132 lm/W
Lichtverteilung:	direkt
Lichtfarbe:	Tageslichtweiß (5200 - 5700K)
Anschlusswert Leuchte:	24V DC \pm 10%
Anschluss Leuchte:	M12 A-kodiert
Schutzart:	IP67/IP69K
Schutzklasse:	III
Entblendung:	opalweiß
Abstrahlwinkel:	100°
Betriebstemperatur:	-30... +70 °C
Farbwiedergabe (Ra):	> 85
Lampenlebensdauer:	> 60.000 h
Material Gehäuse:	Aluminium
Material Abdeckung:	Sicherheitsglas gefrostet, sprungsicher
Höhe [B] x Breite [C]:	Ø 70 mm
Länge [A]:	300 mm
Gewicht:	1300 g
Bruttogewicht:	1700 g
Risikogruppe:	freie Gruppe
Kennzeichnung:	CE, ETL Listed
Befestigungszubehör:	optional
Dimmbar:	optional über Zubehör
Gefertigt in:	Deutschland
Besonderheit:	Retrofitting: genormte LED Rohrleuchte zum 1:1 Austausch


Lampenlebensdauer in Betriebsstunden (L80/B10)



TUBELED_70, 100°, 300 mm, 24V DC

Item number: 110310-01
EAN: 4260556621319

Order number: 110310-01
Model: TUBELED_70 DC
Type: LED surface-mounted luminaire for machines
Illuminant: High Power LED
Power consumption: ~15 W
Lamp luminous flux: 1848 lm
Lamp luminous efficiency: ca. 132 lm/W
Light distribution: direct
Light colour: daylight white (5200 - 5700K)
Connected load: 24V DC \pm 10%
Connection (connector): M12 A-type encoded
Degree of protection: IP67/IP69K
Class of protection: III
Glare-free opal white
Beam angle (optics): 100°
Operating temperature: -30... +70 °C
Colour rendering (Ra): > 85
Lamps lifetime: > 60,000 h
Housing material: aluminium
Cover material: safety glass, frosted, shatterproof
Height [B] x Width [C]: \varnothing 70 mm
Length [A]: 300 mm
Weight (net): 1300 g
Gross weight: 1700 g
Risk group (DIN EN 62471): free group
Marking: CE, ETL Listed
Mounting accessories: optional
Dimmable: via optional accessory
Made in: Germany
Feature: retrofitting: standardised LED luminaire for 1:1 replacement

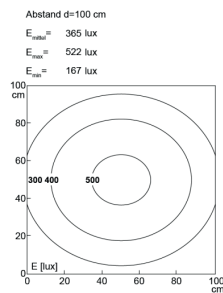

Lamps lifetime in operation hours (L80/B10)