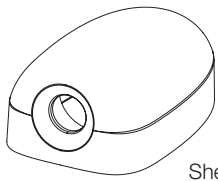
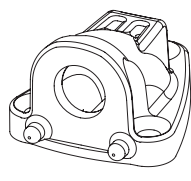
 
 
 



Parts List

 Shell x1	 Base x1	 Gasket x1				
 M4X12 Bolt - (Black*) x1	Self Drill 2mm 3mm 4mm 5mm 6mm  Bungs x6					
 No. 4X16 self tapping screw x3						


Tools Required

 Pozi Screwdriver	 Silicone
 ø2.5mm (3/32") ø3mm (1/8") ø10mm (25/64") Drill Bit	 3mm (1/8") Allen Key

① Choose bung closest to cable ø.

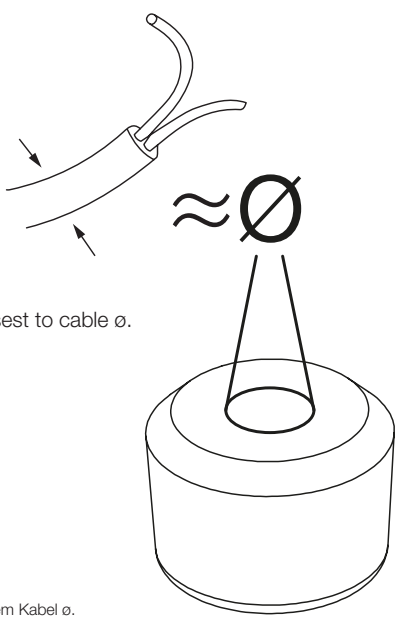


DE - Wähle Dichtung nahe dem Kabel ø.
IT - Scegliere il passafili adatto al ø del cavo.
ES - Elija el tapón con el diámetro más parecido al cable.
FR - Choisissez le joint le plus proche du diamètre du câble.

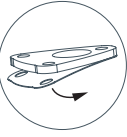
② 


③ 10mm (0.39") 


④ Suggested pilot holes:

Material	No. 4 Screw
Soft Material e.g. plywood	2mm (5/64")
Hard Material e.g. fiberglass, acrylic, hardwoods	2.5mm (3/32")

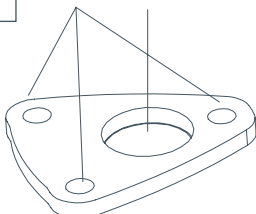

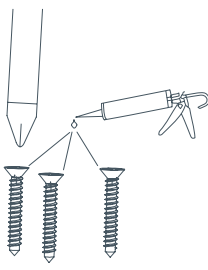⑤ 

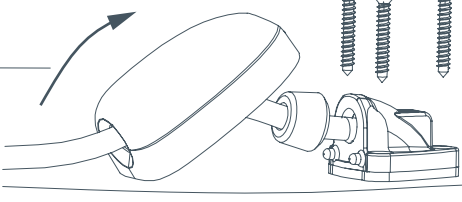⑥ 

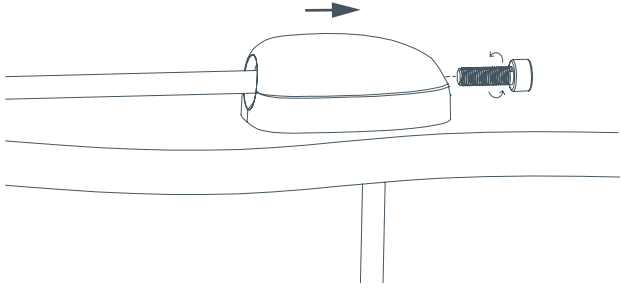⑦ 

Share your installation with us.

    
@scanstrut

UK & International
+44 (0)1392 531280
sales@scanstrut.com

For further installation
and warranty information
please visit:
www.scanstrut.com

USA
+1 860 308 1416
usasales@scanstrut.com

SCANSTRUT®