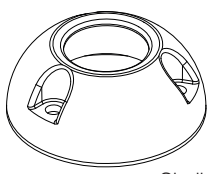
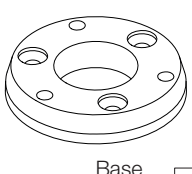
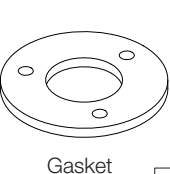
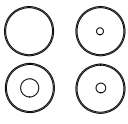
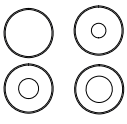
 
 


Parts List

 Shell x1	 Base x1	 Gasket x1	 Self tapping screw DS21 No. 6X16 x3 DS16 No. 4X16 x3
 Bolt - (Black*) DS21 M4X10 x3 DS16 M3X10 x3	 DS21A Bungs x4	 DS21B Bungs x4	 DS16 Bungs x4

Tools Required

 Pozi Screwdriver	 Silicone
 DS21 - ø21mm (0.82") DS16 - ø16mm (0.62") Hole Saw	 ø2mm (5/64") / ø2.5mm (3/32") ø3mm (1/8") Drill Bit

① Choose bung closest to cable ø.

DE - Wähle Dichtung nahe dem Kabel ø.
IT - Scegliere il passafili adatto al ø del cavo.
ES - Elija el tapón con el diámetro más parecido al cable.
FR - Choisissez le joint le plus proche du diamètre du câble.

Tip: freeze before drilling

-18°C

1a

1b

Ø = +1.5mm

4mm (0.16")

②

③ 16mm (0.62")
21mm (0.82")

④

Suggested pilot holes:

Material	No. 4 Screw	No. 6 Screw
Soft Material e.g. plywood	2mm (5/64")	2.5mm (3/32")
Hard Material e.g. fiberglass, acrylic, hardwoods	2.5mm (3/32")	3mm (1/8")

⑦

⑥

⑤

Share your installation with us.



UK & International
+44 (0)1392 531280
sales@scanstrut.com

For further installation
and warranty information
please visit:
www.scanstrut.com

USA
+1 860 308 1416
usasales@scanstrut.com

SCANSTRUT®