


### BR 50-BC-M12


### BR50-BC-Sxxx-M12

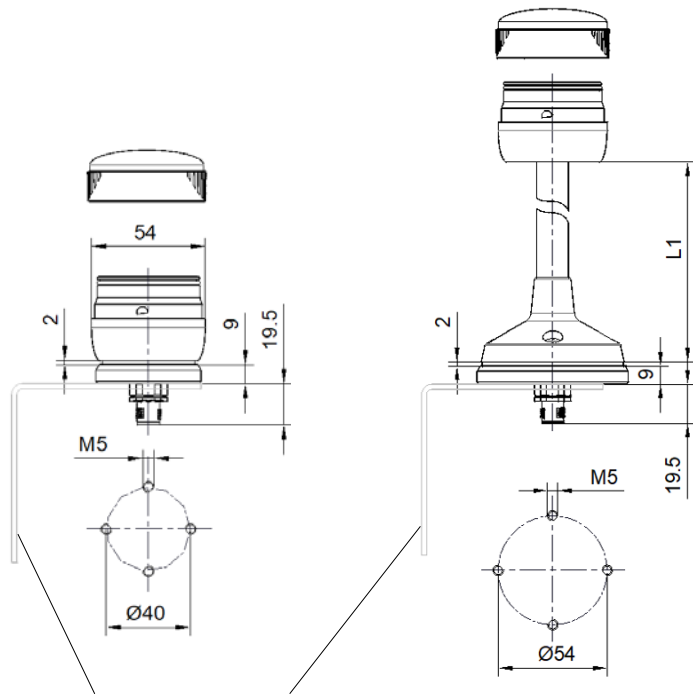

Option Winkel, Maße siehe Blatt 2  
Option bracket, dimensions see sheet 2

### BR50-BC-SR

### BR50-BC-Sxxx-SR

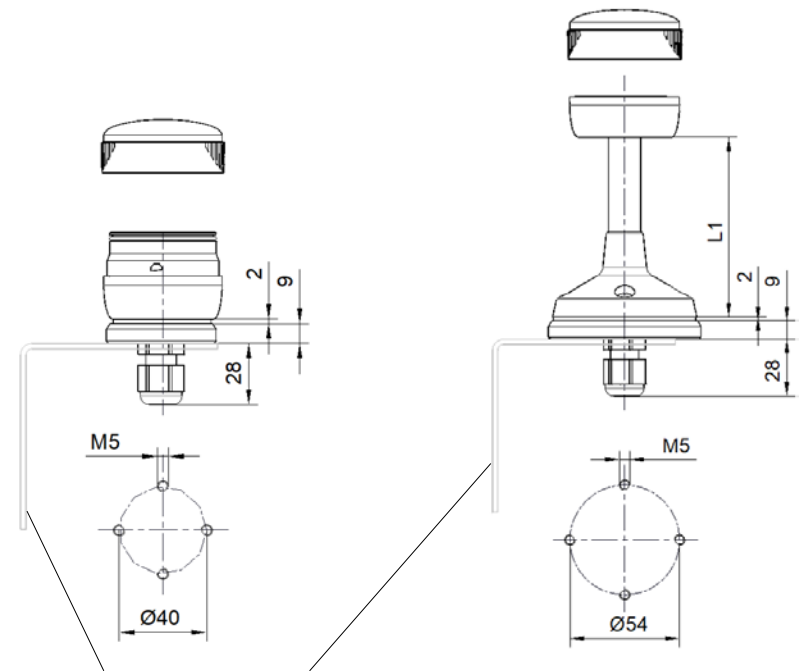

Option Winkel, Maße siehe Blatt 2  
Option bracket, dimensions see sheet 2

Eingangsspannung/ Input voltage : 12 - 24V AC/DC

Eingangsspannung/ Input voltage : 12 – 230V


#### Pin-Belegung/ Pin assignment

M12-Stecker/ connector Pin	Anschluss BR 50-Stufe/ Connection BR50 stage
1	1
2	2
3	3
4	4
5	5
6	/
7	- / N (COM)
8	/

	BR50 -BC-S100	BR50 S250	BR50 S400
L1	88,5 mm	238,5 mm	388,5


Befestigungsmaterial/ Fixing material:
4x Schraube/ Screw M5x12
4x Scheibe/ Lock washer 5,3

## Option : BR 50-W (Winkel/ Bracket)

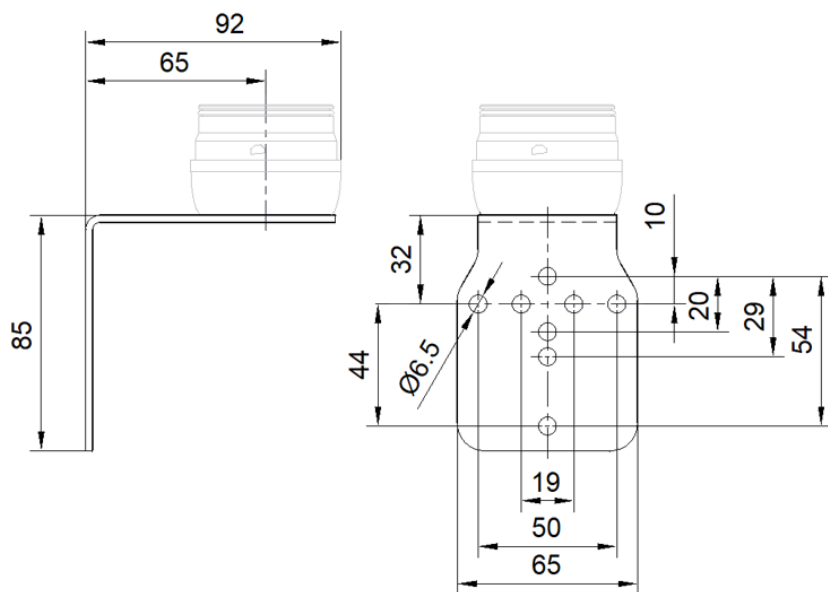

28250180000

BR 50-W Winkel für Direktmontage  
BR 50-W bracket for direct mounting

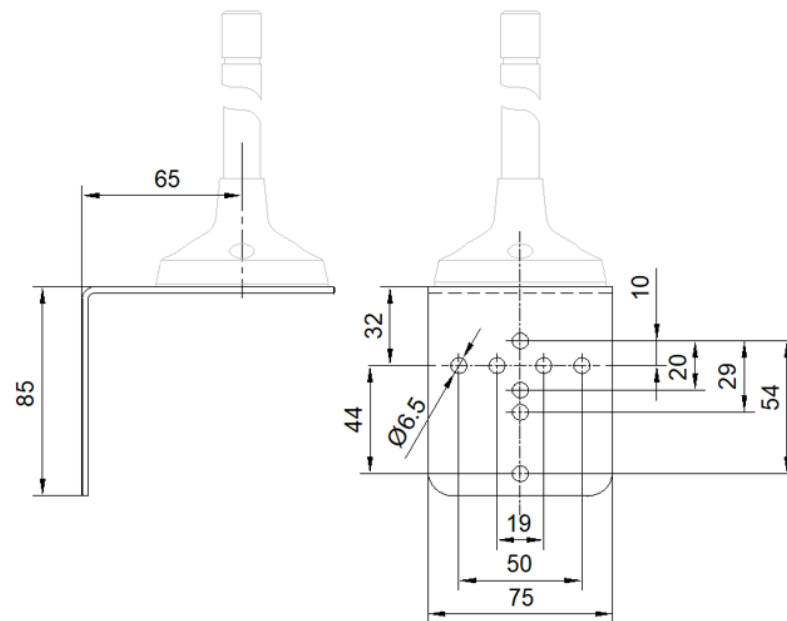

28250190000

BR 50-W Winkel für Stativ  
BR 50-W bracket for stand




**Pfannenberg GmbH**

 Werner-Witt-Straße 1 • D- 21035 Hamburg 1

Tel.: +49/ (0)40/ 734 12-0 • Fax: +49/ (0)40/ 734 12-101

service@pfannenberg.com

<http://www.pfannenberg.com>



[www.pfannenberg.com/disposal](http://www.pfannenberg.com/disposal)