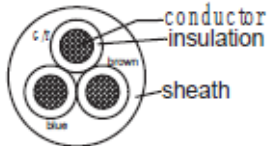


Item no.: 2898982

# Data Sheet

SPECIFICATION				
<b>Style</b>		H07RN-F 3G4		
<b>Standard</b>		EN50525-2-21		
<b>Applications</b>		Heavy duty rubber cable		
Construction Details:				
Test Item		Unit	3G4	
Conductor	Material		Bare Copper	
	Construction	mm	56/0.284±0.01	
	Conductor DC resistance at 20°C ≤	Ω/km	4.95	
Core Insulation	Material		EPDM	
	Avg. thickness	mm	1.0	
	Min. thickness	mm	0.8	
	Surface		Smooth	
	Colors		Green/yellow、 blue 、 brown	
Jacket	Material		CPE	
	Avg. thickness	mm	1.9	
	Min. thickness	mm	1.52	
	Over Diameter	mm	13.8±0.7	
	Surface		Smooth	
	Colors		BLACK	
marking	◁VDE▷ 40015999 H07RN-F 450/750V 3G4mm <sup>2</sup> RIFENG			