

Sicherheits-Kurzschlussstecker

- berührungsgeschützt
- mit axialen Messbuchsen Ø 4 mm

Best.-Nr. SKURZ 6100 / 19 – 4 IG 2MB Ni /
..(Farbe)



- Kontaktteile **vernickelt**
- Isolierteile PA 6.6 (Polyamid)
- **Farben** siehe Tabelle

Safety connecting plug

- moulded insulation
- with rear sockets Ø 4 mm

Order No. SKURZ 6100 / 19 – 4 IG 2MB Ni /
..(colour)

- contact parts **nickel-plated**
- insulation PA 6.6 (Polyamid)
- **colours** see table

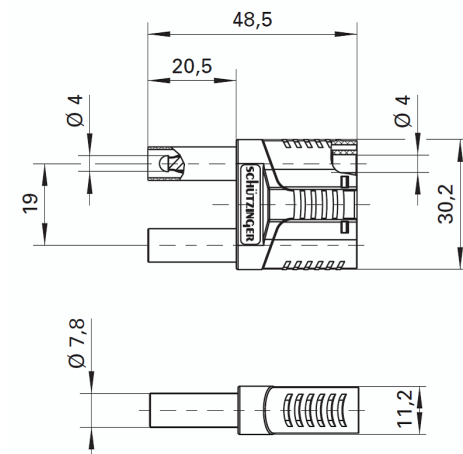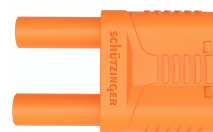

Allgemeine Angaben	
Best.-Nr. ¹⁾	SKURZ 6100 / 19 – 4 IG 2MB Ni / ..(Farbe) Kontaktteile vernickelt
Farben	schwarz, rot, blau, gelb, grün, grau, braun, weiß, orange, grüngelb
Technische Daten	
Anschluss	Sicherheits-Messbuchse (2x)
Durchgangswiderstand	8 mΩ
Bemessungsspannung ²⁾	1000 V CAT II
Bemessungsstrom ²⁾	32 A
Temperatur-Einsatzbereich	von -25 °C bis +80 °C

¹⁾ andere Kontaktoberflächen und Farben auf Anfrage
²⁾ bei normalen Umgebungstemperaturen

General information	
Order No. ¹⁾	SKURZ 6100 / 19 – 4 IG 2MB Ni / ..(colour) contact parts nickel-plated
colours	black, red, blue, yellow, green, grey, brown, white, orange, green-yellow
Technical data	
terminal	safety rear socket (2x)
transition resistance	8 mΩ
rated voltage ²⁾	1000 V CAT II
rated current ²⁾	32 A
operating temperature	from -25 °C to +80 °C

¹⁾ other contact platings and colours on request
²⁾ at normal ambient temperatures