

PL Oprawa LED **EN** LED fitting **DE** LED-Leuchte **RU** Светодиодный светильник **CS** LED svítidlo **SK** LED svetidlo **HU** LED lámpatest **HR** LED rasvjetno tijelo **FR** Luminaire LED **ES** Luminaria LED **IT** Portalampada a LED **RO** Corp de iluminat LED **LT** LED šviestuvas **LV** LED gaismeklis **ET** LED valgusti **PT** Luminária LED **BE** Светлодыёдны свяцільнік **UK** Світлодіодний світильник **BG** LED осветително тяло **SL** LED-svetilka **BS** LED rasvjetno tijelo **SRP** LED rasvjetno tijelo **SR** LED rasvetno telo **MK** LED светилка **MO** Corp de iluminat LED

HAGEN



 
Dostępne kształty | Available shapes | Доступные формы
Erhältliche Ausführungen | Kapható formák



LD-HAG136-30




LD-HAG158-30



LD-HAG218-30




 LD-HAG236-30



LD-HAG258-30

Folder Icon	INFO	Box Icon	Weight Icon	Color Icon	Barcode Icon
LD-HAG136-30	HAGEN LED 136	PC / PC	520 g	biała, white, белый, weiß, fehér	5901867194060
LD-HAG158-30	HAGEN LED 158		900 g		5902801009877
LD-HAG218-30	HAGEN LED 218		1000 g		5901867194053
LD-HAG236-30	HAGEN LED 236		900 g		5901867154606
LD-HAG258-30	HAGEN LED 258		1000 g		5901867166395

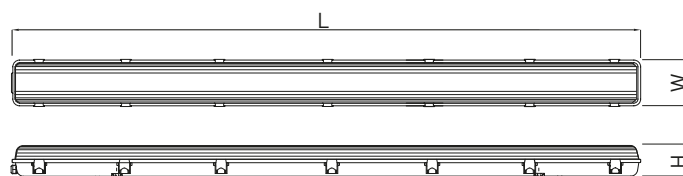

Folder Icon	L x W x H
LD-HAG136-30	1280 x 67 x 50
LD-HAG158-30	1600 x 68 x 65
LD-HAG218-30	690 x 115 x 58
LD-HAG236-30	1270 x 100 x 60
LD-HAG258-30	1590 x 110 x 60