



WS 9455

Thermo-Hygrometer

- Quartz clock
- Date and weekday display
- Indoor temperature display
- Indoor humidity display
- MIN/MAX memory
- Low battery indicator
- Wall mounting or table standing

Specifications

Thermo-Hygrometer WS 9455


Dimensions (WxHxD): 107 x 55 x 13 mm

Power: 1x CR2032 (included)

Temperature measuring range:

-9,9°C to 49,9°C

Humidity measuring range: 20% to 95%

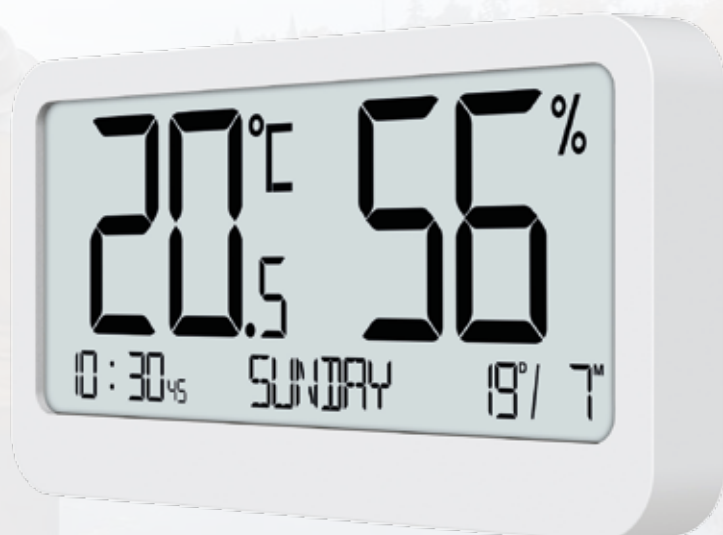

EAN: 4029665094557