




INDUSTRY BATTEN V 1500

22/42W 830/840/857

Discover our new technical product range: SLVtec. With state-of-the-art LED technology, we offer energy-efficient and functional lighting solutions for indoor and outdoor use. From wet room lights to high-bay spotlights – our high-quality products impress with functionality and a fair price-performance ratio. These include the INDUSTRY BATTEN V light, which is adjustable in terms of output (22-W/41W), light colour (3000K/4000K/5700K) and light intensity (5220lm/5460/5760lm) via dip switches. Installation is easy thanks to the removable equipment rack, and electrical connection is possible without tools thanks to the integrated pressure clamp. Decide in favour of SLVtec today.

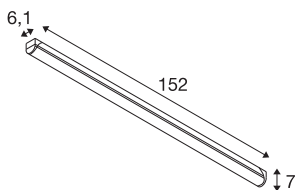

TECHNICAL DATA

Item no.	1007507
IP Code	IP 20
Impact resistance class	IK 04
Impact resistance	0.5 Joule
Assembly	Surface
Assembly details	Ceiling, Wall
Primary nominal voltage	220-240V ~50/60Hz
Secondary power / voltage	500/960 mA
Safety class	I
Wattage	42 W
Minimum ambient temperature	-20 °C
Maximum ambient temperature	40 °C
Operating efficiency (LOR)	0,94
Number of luminaires at LS B16A	13
Number of luminaires at LS C16A	20
Level of inrush current	9.33 A
Duration of inrush current	850 µs
Stroboscopic effect (SVM)	0.02
Lumen	5220/5760/5460 lm
Colour temperature	3000/4000/5700 Kelvin
Beam angle	150 °
Color	white

Light Source



CRI	80
LXXBXX data	L70B50
Service life	50000 h
Risk Group	0
Length	152 cm
Width	6.1 cm
Height	7 cm
Net weight	1.55 kg
Gross weight	1.659 kg