




OUTDOOR BULKHEAD V 360

20W 830/840 IP65 IK10 Sensor

Discover our new technical product range: SLVtec. With state-of-the-art LED technology, we offer energy-efficient and functional lighting solutions for indoor and outdoor use. From wet room lights to high-bay spotlights – our high-quality products impress with functionality and a fair price-performance ratio. These include the OUTDOOR BULKHEAD V light, which is perfectly protected in all weathers thanks to its protection code IP65 and robust aluminium housing. The light colour (3000K/4000K/6500K) and light intensity (1750lm/1850lm/1900lm) can be easily changed via dip switches. And while the removable gearbox makes for easy installation, the optional motion sensor helps save energy. Decide in favour of SLVtec today.

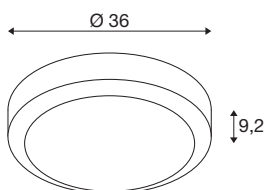

TECHNICAL DATA

Item no.	1007515
IP Code	IP 65
Impact resistance class	IK 10
Assembly	Surface
Assembly details	Ceiling, Wall
Primary nominal voltage	200-240V ~50/60Hz
Secondary power / voltage	500 mA
Safety class	I
Wattage	20 W
Ambient temperature	25 °C
Minimum ambient temperature	-20 °C
Maximum ambient temperature	45 °C
Operating efficiency (LOR)	62,5
Network rated standby power	0.43 W
Number of luminaires at LS B16A	38
Number of luminaires at LS C16A	63
Level of inrush current	8.6 A
Duration of inrush current	282 µs
Stroboscopic effect (SVM)	0
Lumen	1750/1850/1900 lm
Colour temperature	3000/4000/6500 Kelvin
Beam angle	110 °

Light Source

	
--	-----------------------------------------------------------------------------------

Color	black
CRI	80
LXXBXX data	L80B50
Service life	50000 h
Risk Group	0
Height	9.2 cm
Diameter	36 cm
Net weight	2.5 kg
Gross weight	2.675 kg