


Item no.: 2924130 – Silver
2924131 – Black

Data Sheet

Turning knob aluminium (\varnothing x H): 40 mm x 17 mm
Inner bore dia.: 6.0 mm

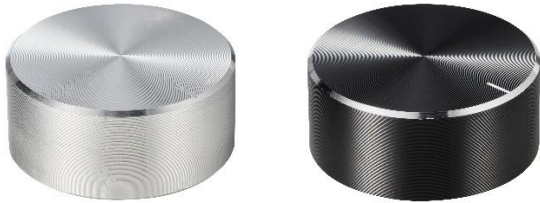

Technical data

Turning knob size (\varnothing x H): 40 mm x 17 mm

Inner bore diameter: 6 mm

Material: Aluminum & plastic

Operating & Storage temperature: -25 °C ~ +85 °C

Operating & Storage humidity: 20 %RH ~ 85 %RH

Drawing:

