


Data Sheet

A notice:

Lamps only for special applications, e.g. in machines, in signal lights or for scale lighting. Not intended for household room lighting.


Socket E10 (11,5 x 24 mm)

BN	Voltage	Current	W
2984275	1.5V	0.2A	0.3W
2984287	2.5V	0.2A	0.5W
2984273	4.5V	0.1A	0.45W
2984280	4.8V	0.3A	1.4W
2984286	6V	330MA	2W
2984293	6V	500MA	3W
2984278	8V	0.05A	0.4W
2984284	14V	0.2A	2.8W
2984279	24V	125MA	3W

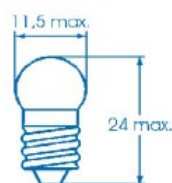

Socket E10 (9 x 23 mm)

BN	Voltage	W
2984277	12V	1.2W
2984283	24V	2W

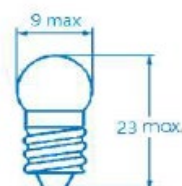

Socket BA9s (9 x 23 mm)

BN	Voltage	Current	W
2984289	24V	40MA	1W
2984285	24V	50MA	1.2W
2984274	24V	80MA	2W
2984281	24V	125MA	3W
2984276	24-30V	83MA	2W
2984282	30V	66MA	2W
2984288	110-130V	20MA	2W

