

Baton 3 Pro

ENHANCED POWER
AND UPGRADED EXPERIENCE

MAX OUTPUT	MAX RUNTIME	MAX THROW
1,500 lumens	120 days	175 meters

*This information is for market reference only. Please DO NOT make it public.



BLACK

OD GREEN

DESERT TAN

MARKET APPLICATIONS

Camping & Hiking & Mountaineering & Household

UPC :

- 697237812659 7 (Black)(CW)
- 697237812660 3(Black)(NW)
- 697549800009 9(OD Green)(CW)
- 697549800020 4(OD Green)(NW)
- 697549800010 5(Desert Tan)(CW)
- 697549800019 8(Desert Tan)(NW)

DESCRIPTION

The Baton 3 Pro is the upgraded version of S2R Baton II. It is more powerful with up to 1,500 lumens, an increase of 30% from the S2R Baton II. Compared with the previous proximity sensor, the new and technologically advanced hidden one is designed to increase the flashlight light output during daily use, while automatically reducing the brightness when the sensor detects an obstruction nearby. With two color temperature options, cool white and neutral white, it meets a variety of needs and can tackle any scenarios. The enlarged concave side switch makes it more comfortable to touch and easy to operate. With the customized 18650 3200mAh rechargeable lithium-ion battery, it is fully charged in 3.5 hours using a USB magnetic charging cable. You can run the Baton 3 Pro for up to incredible 120 days. The included L-shape stand is used to store the flashlight conveniently after use. The widened and lengthened two-way clip is more secure when clipping in the pocket and backpack. The new body knurling design is more non-slip and comfortable to grip. Fully upgraded, the Baton 3 Pro will bring you a better EDC flashlight experience.



FEATURES

- **Higher Output:** It delivers a max. output of 1,500 lumens and max. throw of 175 meters, powerful and useful in outdoor activities.
- **Hidden Proximity Sensor:** Designed to increase the flashlight light output during daily use, while automatically reducing the brightness when the sensor detects an obstruction nearby.
- **Two Color Temperature Options:** Cool white and neutral white, select the color temp. you like or the one that is more suitable to meet your daily need.
- **Larger Side Switch:** The newly enlarged, concave side switch is now even easier to use, and it simultaneously reduces the chance of accidental activation.
- **Longer Runtime:** It runs up to 120 days, perfect for long hours of work.
- **Magnetic Charging:** With the MCC3 USB magnetic charging cable, it's easily fully charged in 3.5 hours.
- **Convenient to Store:** The included L-shape stand, which can be stuck anywhere, makes it easier for you to store the flashlight after use.

OUTPUT

SPECIFICATIONS	MODE 1	MODE 2	MODE 3	MODE 4	MODE 5	STROBE
	1,500 ±600 lumens	600 ±120 lumens	120 lumens	15 lumens	0.5 lumens	13Hz at 1,500 lumens
	2+177 minutes	180+25 minutes	17 hours	100 hours	120 days	
	175 meters	110 meters	50 meters	20 meters	N/A	
	7,900 cd	3,206 cd	650 cd	100 cd	N/A	

* Note:
 (1) All data above are test results according to ANSI/NEMA FL 1-2009 standards.
 (2) The test using the product with the fully charged customized 18650 battery.

LIGHT SOURCE

High Performance Cool White LED
 High Performance Neutral White LED

DIMENSIONS

Length: 3.99in/101.4mm
 Head Diameter: 0.91in/23mm
 Body Diameter: 0.91in/23mm

WEIGHT

3.63oz/103g (Including Battery)

BODY MATERIAL

Aluminum Alloy

POWERED BY

Customized 3200mAh 3.6V 18650
 Rechargeable Lithium-ion Battery

WARRANTY

Olight's 5-Year Warranty
 Visit: <https://olightworld.com/olight-warranty>


IN THE BOX

Baton 3 Pro (Battery Included) x1
 MCC3 Charging Cable x 1
 L-shape Stand x1
 Pouch x1
 User Manual x1

OPTIONAL ACCESSORIES

MCC1A Charging Cable x 1
 Omino x 1

WATERPROOF IPX8

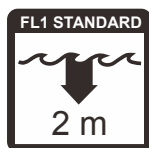

DROP TEST



COMPLIANCE



olightworld.com © OLIGHT 08/05/22 V1

Made in China

Note: There are slight differences between the picture and the real item caused by light color temperature. All the pictures are for reference only.