



Seeker 4 Mini

MINI EDC FLASHLIGHT
WITH WHITE AND UV LIGHT

| MAX OUTPUT | MAX RUNTIME | MAX THROW |
|---|---|---|
|  |  |  |
| 1,200 lumens | 12 Days | 120 meters |

*This information is for market reference only. Please DO NOT make it public.



↑
RED



↑
BLACK



↑
OD GREEN

Seeker 4 Mini

MINI EDC FLASHLIGHT WITH WHITE AND UV LIGHT




MARKET APPLICATIONS

Everyday Carry
Outdoors
Law Enforcement
Daily Tasks

UPC: 6975498002567 (Black NW)
6975498001829 (Black CW)
6975498007661 (OD Green NW)
6975498007371 (OD Green CW)
6975498007388 (Red)

DESCRIPTION

The Seeker 4 Mini is the first compact flashlight with both white and UV light in Seeker Series. The two light sources allow this flashlight to be used in a variety of scenarios, such as climbing, camping, repairs, power outages, fluorescent agent detection, stain detection, hotel cleanliness checking, ringworm detection, etc. Measuring only 3.43 inches in length and with a two-way clip, it is easy to carry and fits nicely into your palm. Its metal side switch is more wear-resistant, and the indicator in the center of the switch visually displays the remaining battery level in real time. The ergonomically curved surface of the flashlight body is non-slip and comfortable to grip. The magnetic charging cable quickly and easily snaps onto the bottom of the flashlight, fully charging the battery in 1.5 hours. Its aluminum alloy body can easily handle water immersion and hard drops. The Seeker 4 Mini is a perfect illumination tool to be used at home, outdoors, or to tackle daily tasks.

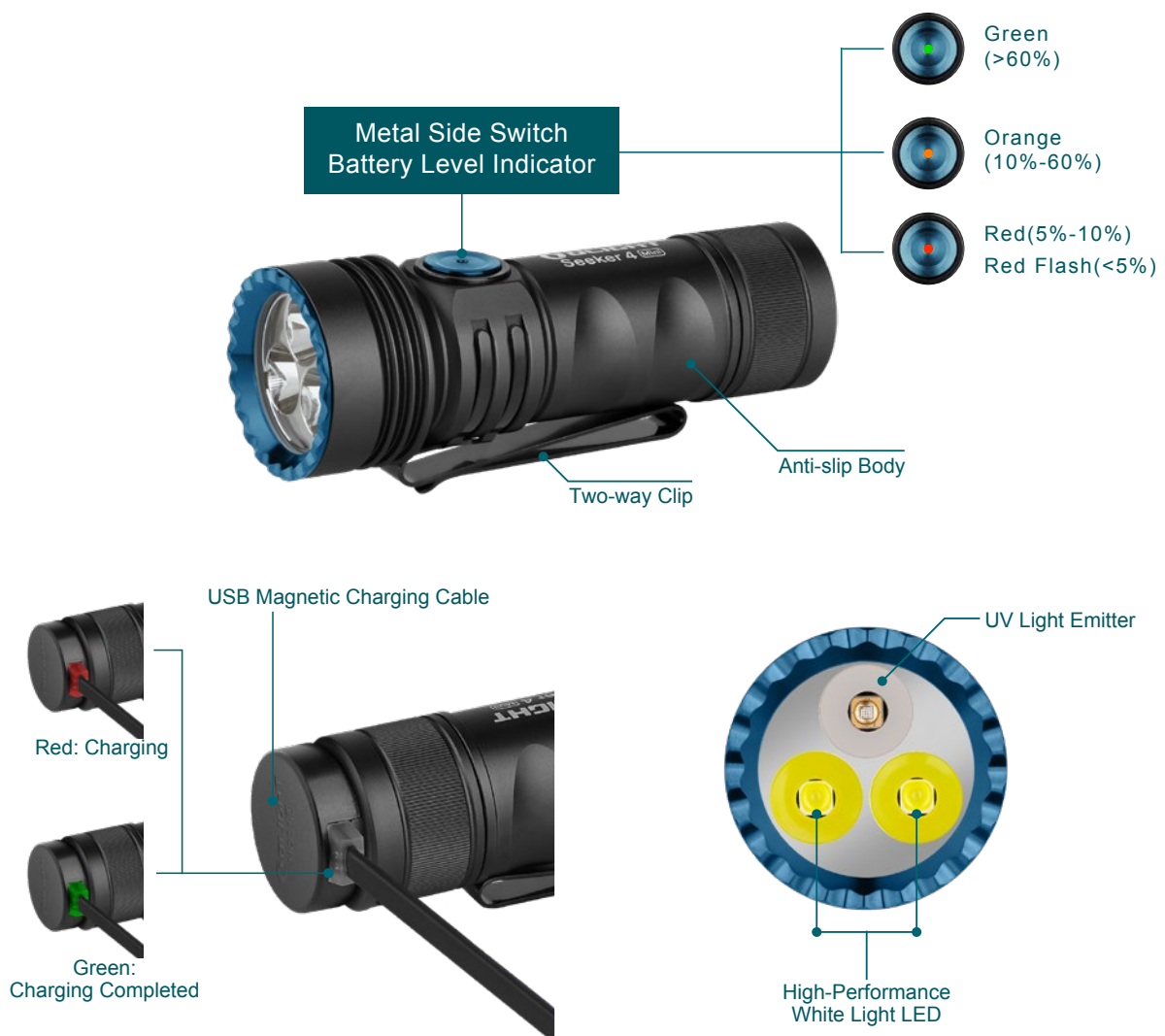

Seeker 4 Mini

MINI EDC FLASHLIGHT WITH WHITE AND UV LIGHT



FEATURES

- **Two Light Sources:** Featuring both white and UV light, this versatile flashlight is suitable for a diverse range of applications; including but not limited to climbing, camping, repair work, power outages, fluorescent agent detection, stain identification, hotel cleanliness inspection, ringworm detection, and much more.
- **Mini and Portable:** With a length of merely 3.43 inches and a two-way clip, it is effortless to carry and conveniently fits in the palm of your hand.
- **Premium Metal Side Switch:** The high-end side switch is extremely durable, and the battery level indicator in the center of it allows you to easily see the remaining power at a single glance.
- **Non-slip Body:** The ergonomically designed curved body provides a good and comfortable grip.
- **Magnetic Charging:** Just snap it on to fully charge the flashlight in only 1.5 hours.
- **Dual Color Temperature Options:** The black and OD green models offer both CW and NW options, allowing you to select the appropriate hue for any given situation.
- **Sturdy Build:** IPX8 waterproof and 1.5-meter impact-resistant, the Seeker 4 Mini is ready for any environment and adventure.

OUTPUT

WHITE LIGHT


| SPECIFICATIONS | MODE 1 | MODE 2 | MODE 3 | MODE 4 | MODE 5 |
|----------------|--------------------------|----------------|-------------|------------|----------|
| | 1,200±600 ±120 lumens | 600±120 lumens | 120 lumens | 15 lumens | 2 lumens |
| | 3+41+25 minutes | 50+25 minutes | 320 minutes | 33.5 hours | 12 days |
| | 120 meters | 85 meters | 38 meters | 14 meters | 4 meters |
| | 3,600 cd | 1,824 cd | 370 cd | 49 cd | 4 cd |
| | 13Hz at 1,200 lumens | | | | |

UV LIGHT

| OPTICAL POWER(TYP.) | WAVELENGTH(TYP.) | RUNTIME |
|---------------------|------------------|---------|
| 760 mW | 365 nm | 95 min |

*All data above are test results according to ANSI/NEMA FL 1-2009 standards.

 WATERPROOF IPX8



DROP TEST



COMPLIANCE



olightworld.com © OLIGHT 04/27/23 V1

Made in China

Note: There are slight differences between the picture and the real item caused by light color temperature. All the pictures are for reference only.

LIGHT SOURCE

Black:

High Performance Cool White LED (5700~6700K)
High Performance Neutral White LED (4000~5000K)
UV 365nm

OD Green:

High Performance Cool White LED (5700~6700K)
High Performance Neutral White LED (4000~5000K)
UV 365nm

Red:

High Performance Cool White LED (5700~6700K)
UV 365nm

DIMENSIONS

Length: 3.43in/87mm
Head Diameter: 1.18in/30mm
Body Diameter: 0.94in/24mm

WEIGHT

3.95oz/112g (Including Battery)

BODY MATERIAL

Aluminum Alloy

POWERED BY

Customized 18350 3.6V 1100mAh Rechargeable
Lithium-ion Battery

WARRANTY

Olight's 5-Year Warranty
Visit: <https://olightworld.com/olight-warranty>

IN THE BOX

Seeker 4 Mini (Battery Included) x 1
MCC1A Magnetic USB Charging Cable x 1
Lanyard x 1
User Manual x 1