






SEEKER 4 Pro

THE ULTIMATE EXPERIENCE INSIDE AND OUT

4,600 LUMENS WITH DUAL CHARGING OPTIONS

MAX OUTPUT	MAX RUNTIME	MAX THROW
		
4,600 lumens	15 days	260 meters

* This information is for market reference only. Please DO NOT make it public.



▲
BLACK



▲
ORANGE



▲
MIDNIGHT BLUE

SEEKER 4 Pro

THE ULTIMATE EXPERIENCE INSIDE AND OUT

4,600 LUMENS WITH DUAL CHARGING OPTIONS



MARKET APPLICATIONS

Everyday Carry
Outdoors
Law Enforcement

UPC

6975498002291 (Matte Black CW)
6975498002871 (Matte Black NW)
6975498006152 (Orange CW)
6975498006169 (Midnight Blue CW)

DESCRIPTION

The Seeker 4 Pro features an incredible max output of 4,600 lumens and a 260-meter beam distance. This is a 400-lumen increase from the previous Seeker 3 Pro by implementing higher circuit efficiency, without compromising the runtime with its included 5,000mAh 21700 battery. The enlarged metal side switch offers improved rotational grip and a much smoother stepless dimming experience, allowing for easier operation even while wearing heavy gloves. The flashlight incorporates Laser Microperforation technology for the first time in the flashlight industry, creating small holes with a laser and resulting in a distinctive translucent dashboard display on metal. More importantly, this upgraded version comes with an industry-leading innovative holster that offers flashlight auto lock/unlock, charging, storage, and carrying options. When the flashlight is in the holster, it intelligently lowers the brightness to below 600 lumens, ensuring user safety. You can also select between two different color temperatures, cool white (5700K~7000K) or neutral white (4000K~5000K), for your preferred lighting experience. Enjoy the ultimate experience brought by the Seeker 4 Pro!




Switch (Rotate or Press and Hold to Change Brightness)



Type-C Charging Cable



High Performance LEDs

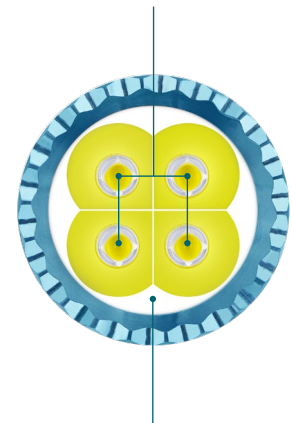

TIR Optic Lens

Brightness Level Indicator

Battery Level Indicator

SEEKER 4 Pro

THE ULTIMATE EXPERIENCE INSIDE AND OUT

4,600 LUMENS WITH DUAL CHARGING OPTIONS



FEATURES

- **Higher performance:** Max throw: 260m; max output: 4,600 lumens, 10% higher than the Seeker 3 Pro.
- **Effortless Operation at your Fingertips:** The enlarged metal side switch offers improved rotational grip and a much smoother stepless dimming experience.
- **First Laser Microperforation in the Flashlight Industry:** 1,200 micro holes are created on the metal bezel to display visible indicators with a futuristic and elegant look.
- **The Best Wingman Ever - the Versatile Holster:** As an industry-leading and innovative holster, this groundbreaking design offers flashlight auto lock/unlock, charging, storage, and carrying options.
- **Dual Charging Options:** Type-C charging (with Holster) or MCC3 magnetic charging (MCC3 2A charging).
- **Two color temperatures available:** Select between two different color temperatures: cool white (5700K~7000K) or neutral white (4000K~5000K).

OUTPUT

SPECIFICATIONS	MODE 1	MODE 2	MODE 3	MODE 4	MODE 5
	4,600 \pm 1,200 \pm 600 lumens	1,200 \pm 600 \pm 300 lumens	300 lumens	50 lumens	5 lumens
	2.5 \pm 122 \pm 35 minutes	135 \pm 35 \pm 10 minutes	660 minutes	60 hours	15 days
	260 meters	130 meters	65 meters	25 meters	9 meters
	16,895 cd	4,225 cd	1,044 cd	164 cd	21 cd
	13 Hz at 4,600 lumens				

* All data above are test results according to ANSI/NEMA FL 1-2009 standards.

LIGHT SOURCE

- High-Performance Neutral White LED (4000K~5000K)
- High-Performance Cool White LED (5700K~7000K)

DIMENSIONS

Length: 5.24in/133mm
Head Diameter: 1.38in/35mm
Body Diameter: 1.10in/28mm

WEIGHT

7.23oz/205g (Including Battery)

BODY MATERIAL

Aluminum Alloy

POWERED BY

Customized 3.6V 5000mAh 21700
Lithium-ion Battery

WARRANTY

Olight's 5-Year Warranty
Visit: <https://olightworld.com/olight-warranty>


IN THE BOX

Seeker 4 Pro (battery included) x 1
Vertical Holster x 1
USB-C Charging Cable x 1
Holster fixing bracket x 1
Plastic Expansion Screw x 2
Stainless Steel Screw x 2
User Manual x 1

OPTIONAL ACCESSORY

Pocket Clip
Horizontal Holster
MCC3 Magnetic Charging Cable

WATERPROOF IPX8

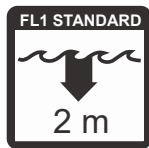

DROP TEST



COMPLIANCE



olightworld.com © Olight 09/16/21 V1

Made in China

Note: There are slight differences between the picture and the real item caused by light color temperature. All the pictures are for reference only.