

## Artikel Nr.: 348212

Deckenaufbauleuchte, Madera, 22 W, DIM, 3000 K, Eiche natur, Braun;Schwarz, 100-240 V/AC 50 / 60 Hz, Warmweiß (WW)



### Technische Daten

#### Charakteristik

|                        |                  |
|------------------------|------------------|
| <b>Material</b>        | Eichenholz/Eisen |
| <b>Farbe</b>           | Braun;Schwarz    |
| <b>Optik</b>           | / Opal           |
| <b>im Lieferumfang</b> |                  |

#### Elektrische Daten

|                                |                            |
|--------------------------------|----------------------------|
| <b>Leistung</b>                | 22 W                       |
| <b>Eingangsspannung</b>        | 100-240 V/AC 50 / 60 Hz    |
| <b>Bemessungsstrom</b>         |                            |
| <b>Fassung / Sockel</b>        |                            |
| <b>Anzahl Sockel</b>           |                            |
| <b>Netzgerät</b>               | Ja                         |
| <b>Ansteuerung</b>             | Mit Phasenanschnittsdimmer |
| <b>Anschlussmöglichkeit</b>    | Klemme                     |
| <b>Schutzklasse I, II, III</b> | II                         |

#### Lichttechnische Eigenschaften

|                             |                               |
|-----------------------------|-------------------------------|
| <b>Leuchtmittel</b>         | LED;Lichtquelle wechselbar TC |
| <b>Lichtfarbe</b>           | Warmweiß (WW)                 |
| <b>Farbtemperatur</b>       | 3000 K                        |
| <b>Lichtstrom</b>           | 2740 lm                       |
| <b>Abstrahlwinkel</b>       |                               |
| <b>LED Typ</b>              | SMD                           |
| <b>LED Anzahl</b>           |                               |
| <b>Strahlungsverteilung</b> |                               |




## Artikel Nr.: 348212

Deckenaufbauleuchte, Madera, 22 W, DIM, 3000 K, Eiche natur, Braun;Schwarz, 100-240 V/AC 50 / 60 Hz, Warmweiß (WW)

### Lichtrichtung

|                                 |             |
|---------------------------------|-------------|
| <b>Dreh- und Schwenkbereich</b> |             |
| <b>Neigungswinkel</b>           |             |
| <b>Abstrahlverhalten</b>        | Oben;Unten  |
| <b>Reflektor / Linse</b>        | Symmetrisch |

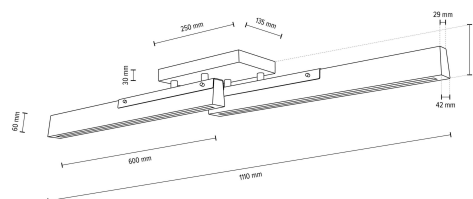

### Abmessungen und Gewicht

|                             |         |
|-----------------------------|---------|
| <b>Länge (mm)</b>           | 1100,00 |
| <b>Breite (mm)</b>          | 42,00   |
| <b>Höhe (mm)</b>            | 60,00   |
| <b>Durchmesser (mm)</b>     | 0,00    |
| <b>Deckenabhängung (mm)</b> | 0,00    |
| <b>Gewicht</b>              |         |

### Sockelmaß

|                         |        |
|-------------------------|--------|
| <b>Länge (mm)</b>       | 250,00 |
| <b>Breite (mm)</b>      | 135,00 |
| <b>Höhe (mm)</b>        | 30,00  |
| <b>Durchmesser (mm)</b> | 0,00   |

**Artikel Nr.: 348212**

Deckenaufbauleuchte, Madera, 22 W, DIM, 3000 K, Eiche natur, Braun;Schwarz, 100-240 V/AC 50 / 60 Hz, Warmweiß (WW)

**Grenzwerte**

|                           |               |
|---------------------------|---------------|
| <b>Betriebstemperatur</b> | -25 bis 45 °C |
| <b>Lagertemperatur</b>    | -25 bis 60 °C |
| <b>IP - Schutzart</b>     | IP 20         |


**Allgemeine Eigenschaften**

**Umwelteigenschaften**

|                               |              |
|-------------------------------|--------------|
| <b>Energieeffizienzklasse</b> | D            |
| <b>Energieverbrauch</b>       | 22 kWh/1000h |

**Lebensdauer**

|                                      |       |
|--------------------------------------|-------|
| <b>Bemessungslebensdauer L70/B50</b> |       |
| <b>Lichtstrom Ende Lebensdauer</b>   | 0,9   |
| <b>Schaltzyklen</b>                  | 50000 |

|   |   |
|---|---|
| <b>EEL</b>  | Dieses Produkt enthält eine Lichtquelle der Energieeffizienzklasse D  |
| <b>IP 20</b>  | Schutz gegen das Eindringen von Fremdkörper > 50 mm. Kein Schutz gegen das Eindringen von Wasser.   |
|  | Leuchte der Schutzklasse II bei der der Schutz gegen elektrischen Schlag nicht allein auf der Basisisolierung beruht, sondern zusätzliche Sicherheitsvorkehrungen wie zusätzliche oder verstärkte Isolierung vorgesehen sind. Es sind weder Vorkehrungen für den Anschluss eines Schutzleiters vorhanden, noch beruht der Schutz auf den Einrichtungsbedingungen. |

**Article no.: 348212**

Surface mounted ceiling lamp, Madera, 22 W, DIM, 3000 K, Eiche natur, Brown;Black, 100-240 V/AC 50 / 60 Hz, Warm white (WW)

**Technical Data****General Characteristics**

|                             |               |
|-----------------------------|---------------|
| <b>Material</b>             | Oak wood/iron |
| <b>Colour</b>               | Brown;Black   |
| <b>Optics</b>               | / Opal        |
| <b>included in delivery</b> |               |

**Electrical Characteristics**

|                                    |                         |
|------------------------------------|-------------------------|
| <b>Power</b>                       | 22 W                    |
| <b>Input voltage</b>               | 100-240 V/AC 50 / 60 Hz |
| <b>Input current</b>               |                         |
| <b>Base (standard designation)</b> |                         |
| <b>Number of bases</b>             |                         |
| <b>Power supply unit</b>           |                         |
| <b>Electronically reversible</b>   | Leading-edge dimmer     |
| <b>Connection possibility</b>      | Clamp                   |
| <b>Protection class I, II, III</b> | II                      |

**Light Technical Data**

|                                    |                               |
|------------------------------------|-------------------------------|
| <b>Bulb</b>                        | LED;Lichtquelle wechselbar TC |
| <b>Colour Designation</b>          | Warm white (WW)               |
| <b>Colour temperature</b>          | 3000 K                        |
| <b>Luminous flux</b>               | 2740 lm                       |
| <b>Beam angle</b>                  |                               |
| <b>LED type</b>                    | SMD                           |
| <b>LED quantity</b>                |                               |
| <b>Spectral power distribution</b> |                               |




## Article no.: 348212

Surface mounted ceiling lamp, Madera, 22 W, DIM, 3000 K, Eiche natur, Brown;Black, 100-240 V/AC 50 / 60 Hz, Warm white (WW)

### Light Direction

|                                   |             |
|-----------------------------------|-------------|
| <b>Rotating and tilting range</b> |             |
| <b>Angle of inclination</b>       |             |
| <b>Radiation direction</b>        | Oben;Unten  |
| <b>Reflector / lense</b>          | Symmetrisch |

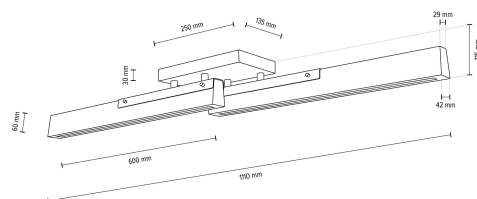

### Dimensions & Weight

|                                      |         |
|--------------------------------------|---------|
| <b>Length (mm)</b>                   | 1100,00 |
| <b>Width (mm)</b>                    | 42,00   |
| <b>Height (mm)</b>                   | 60,00   |
| <b>Diameter (mm)</b>                 | 0,00    |
| <b>Suspensions from ceiling (mm)</b> | 0,00    |
| <b>Product Weight</b>                |         |

### Base dimensions

|                      |        |
|----------------------|--------|
| <b>Length (mm)</b>   | 250,00 |
| <b>Width (mm)</b>    | 135,00 |
| <b>Height (mm)</b>   | 30,00  |
| <b>Diameter (mm)</b> | 0,00   |

**Article no.: 348212**

Surface mounted ceiling lamp, Madera, 22 W, DIM, 3000 K, Eiche natur, Brown;Black, 100-240 V/AC 50 / 60 Hz, Warm white (WW)

**Absolute maximum ratings**

|                            |               |
|----------------------------|---------------|
| <b>Working temperature</b> | -25 bis 45 °C |
| <b>Storage temperature</b> | -25 bis 60 °C |
| <b>IP - Code</b>           | IP 20         |


**General product data**

**Environmental Characteristics**

|                           |              |
|---------------------------|--------------|
| <b>Energy label</b>       | D            |
| <b>Energy consumption</b> | 22 kWh/1000h |

**Lifespan**

|  |       |
|--|-------|
| <b>Rated Life Time L70 / B50</b>       |       |
| <b>Luminous flux (end of lifetime)</b> | 0,9   |
| <b>Number of switching cycles</b>      | 50000 |

|   |   |
|---|---|
| <b>EEL</b>  | This product contains a light source of energy efficiency class D   |
| <b>IP 20</b>  | Protection against penetration of foreign objects > 50 mm. No protection against penetration of water.  |
|  | Lightings of Protection Class II in which the protection against electric shock is not based solely on the insulation, but additional safety precautions such as additional or reinforced insulation are provided. There are no provisions for the connection of an equipment grounding conductor exists, yet underlying the protection of the facility conditions. |