

# WARRIOR X 4 DEFY DARKNESS

MAX OUTPUT	MAX RUNTIME	MAX THROW
<b>2,600</b> lumens	<b>8</b> hours	<b>630</b> meters

\*This information is for market reference only. Please DO NOT make it public.



BLACK



CAMOUFLAGE



**MARKET APPLICATIONS**


Night Security/Patrol      Law Enforcement  
Hunting                      Search & Rescue  
Self-defense                Outdoors

**UPC**

697549800260 4 (Black)  
697549800626 8 (Camouflage)

**DESCRIPTION**



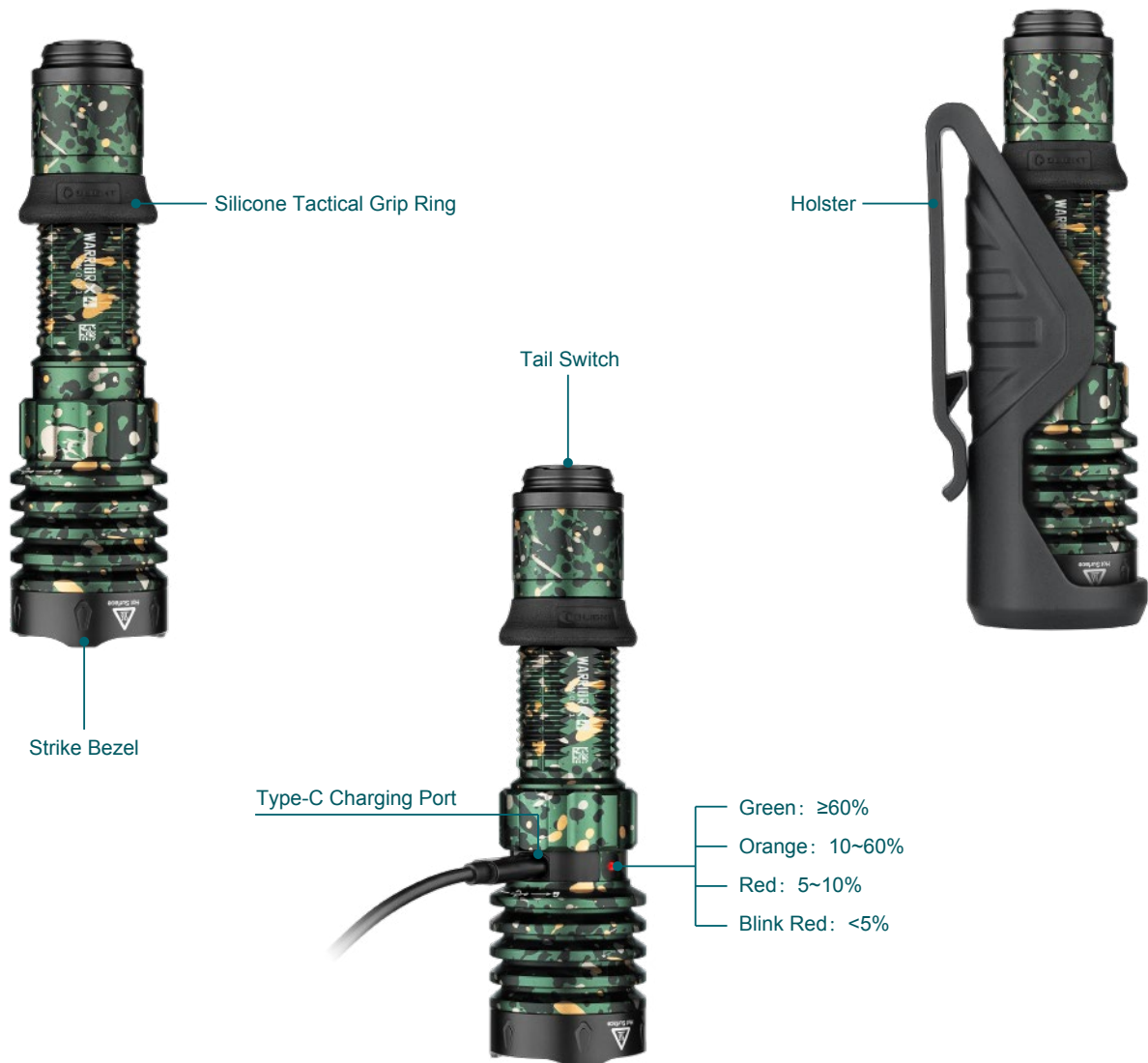


The Warrior X4 is a remarkable rechargeable tactical flashlight that combines high output and long-range capabilities, boasting an impressive 2600 lumens and a beam distance of 630 meters. Its stainless steel strike bezel and tail switch add exceptional ruggedness and reliability, providing a significant tactical advantage. In addition to MCC charging, the flashlight offers a hidden Type-C charging port, ensuring versatile charging options to suit various needs. The power indicator is designed to display the remaining battery level with clarity and effectiveness. With the programming function, users have the freedom to customize their experience with the enlarged tail switch, whether they prefer regular or tactical lighting modes. This level of versatility together with the added holster enhance both performance and user-friendliness, making the Warrior X4 an indispensable lighting tool for a wide range of applications. Whether it's for patrol, hunting, repair work, or any outdoor and household use, the Warrior X4 delivers improved performance and meets the diverse needs of users.



## FEATURES

- **Remarkable Performance:** Max output: 2,600 lm; Max throw: 630 m; Peak beam intensity: 99,310 candela.
- **Dual Charging Options:** In addition to MCC charging, the flashlight offers a hidden Type-C charging port, ensuring versatile charging options to suit various needs.
- **Enlarged Tail Switch with Nano Molding Technology:** The new tail switch clearly distinguishes between light and heavy presses, while nano molding technology makes metal dust cleaning on the tail switch a breeze.
- **Programmable Modes:** Freedom to easily choose between regular mode and tactical mode, with different experience with the tail switch. Strobe is available in Tactical mode.
- **Battery Indicator:** The tri-color indicator allows you to easily stay informed about the remaining battery level with just a single glance.

## OUTPUT

SPECIFICATIONS	REGULAR MODE		TACTICAL MODE	
	mode 1	mode 2	mode 3	mode 4
	2,600-1,000-300 lumens	300 lumens	1,000-300 lumens	/
	3+140+20 minutes	8 hours	159+20 minutes	
	630 meters	210 meters	390 meters	
	99,310 cd	11,360 cd	38,160 cd	
	/			13Hz@2600 lumens

\*All data above are test results according to ANSI/NEMA FL 1-2009 standards.

## LIGHT SOURCE

High Performance LED(5700-6700k)

## DIMENSIONS

Length: 5.87in/149mm  
 Head Diameter: 1.56in/39.5mm  
 Body Diameter: 1.02in/26mm

## WEIGHT

8.78oz/249g (Including Battery)

## BODY MATERIAL

Aluminum Alloy

## POWERED BY


Customized 5000mAh 3.6V 21700  
 Rechargeable Battery

## WARRANTY

Lifetime Warranty in the USA, Australia, Germany, France and China.  
 5 Year Warranty in other countries and regions.

### WATERPROOF

IPX8

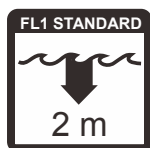

### DROP TEST



### COMPLIANCE



olightworld.com © Olight 11/18/21 V1

Made in China

Note: There are slight differences between the picture and the real item caused by light color temperature. All the pictures are for reference only.

## IN THE BOX

Warrior X 4 x 1  
 USB-C Charging Cable x 1  
 Holster x 1  
 User Manual x 1

## OPTIONAL ACCESSORIES

Warrior Ring  
 MCC3 USB Magnetic Charging Cable x 1  
 sROD-7 Magnetic Remote Switch  
 sROD Long Coil Wire Magnetic Remote Switch  
 E-WM25 Mount