




# WARRIOR Nano

## UNLEASH INCREDIBLE POWER IN YOUR PALM


For EDC & Tactical Use

MAX OUTPUT	MAX RUNTIME	MAX THROW
		
<b>1,200</b> lumens	<b>40</b> days	<b>135</b> meters

\*This information is for market reference only. Please do not make it public.



Black

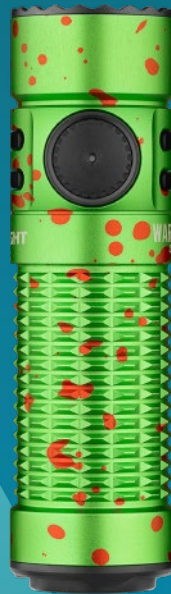

Zombie Green

## MARKET APPLICATIONS


Everyday Carry  
Outdoors  
Self-defense

UPC:

6975498001706 (Black)  
6975498006299 (Zombie Green)

## DESCRIPTION

The Warrior Nano is Olight's most compact rechargeable tactical flashlight. It delivers an impressive output of 1,200 lumens and has a throw of 135 meters, all in a compact 3.19-inch-long form. The Warrior Nano features a metal side switch for daily use and a tail switch for tactical operations. The 1100mAh battery offers a stunning runtime of 40 days in Moonlight mode. The tri-color battery indicator displays the battery level and alerts when it is time to charge. Designed with user safety features, it includes lockout and Half-Turbo mode, making it pocket-safe. It is fast and easy to recharge with the included MCC magnetic charging cable. The two-way stainless steel pocket clip allows for bezel up or bezel down carry. As a must-have for storage and display, the sturdy L-stand included ensures your flashlight is always easy to find and within reach. Compact but mighty, the Warrior Nano is suitable for outdoor lighting, hiking, camping and is also a perfect choice for other illumination needs.

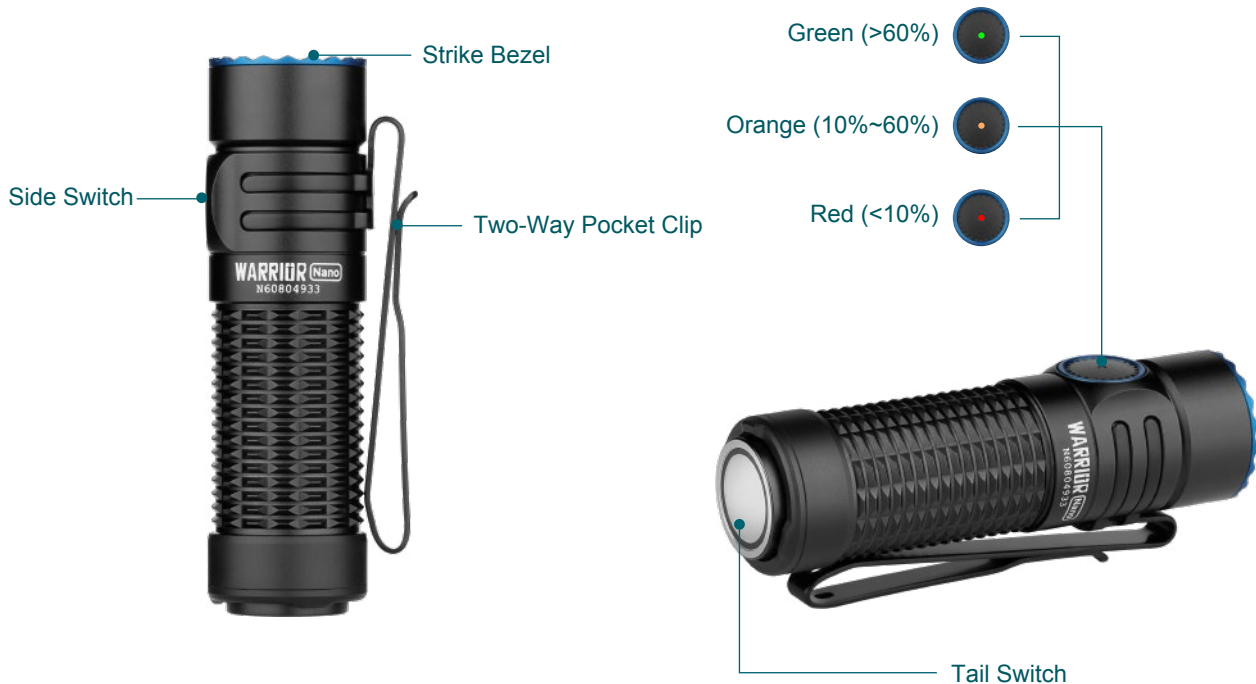

## FEATURES


- **Put 1,200 lumens in the Palm of Your Hands:** Delivers an impressive output of 1,200 lumens and a throw of 135 meters, all packed into a compact 3.19-inch-long form.
- **Versatile and Intuitive:** In addition to the versatile side switch for daily use, the tail switch allows immediate high output for instant activation during urgent situations.
- **Unlock Endless Lighting Possibilities:** Features six brightness levels (Turbo, Half-Turbo, High, Medium, Low, and Moonlight) and two tactical modes (Strobe and Momentary-on).
- **Lasts 40 Days Before Recharge:** With its 1100mAh battery, it delivers a stunning runtime of 40 days in Moonlight mode.
- **Designed with User Safety in Mind:** Includes a lockout feature and Half-Turbo mode to make the light pocket-safe.
- **Fits Comfortably in Your Pocket:** The two-way stainless steel pocket clip allows for deep bezel down or bezel up pocket carry.

## OUTPUT

SPECIFICATIONS	Turbo	Half-Turbo	High	Medium	Low	Moonlight
	<b>1,200</b> ±400 lumens	<b>600</b> ±400 lumens	<b>400</b> ±60 lumens	<b>60</b> lumens	<b>15</b> lumens	<b>0.5</b> lumen
	<b>3+77</b> minutes	<b>10+75</b> minutes	<b>85+35</b> minutes	<b>10</b> hours	<b>36</b> hours	<b>40</b> days
	<b>135</b> meters	<b>96</b> meters	<b>80</b> meters	<b>32</b> meters	<b>16</b> meters	N/A
	<b>4,697</b> cd	<b>2,304</b> cd	<b>1,577</b> cd	<b>262</b> cd	<b>65</b> cd	N/A
	<b>13Hz at 1,200 lumens</b>					

\* All data above are test results according to ANSI/NEMA FL 1-2009 standards.

### WATERPROOF IPX8

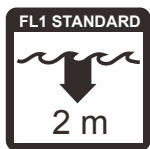

### DROP TEST



### COMPLIANCE



olightworld.com © Olight 07/10/23 V1

Made in China

## LIGHT SOURCE

High Performance LED (5700-6700K)

## DIMENSIONS

Length: 3.19in/81mm  
Head Diameter: 0.91in/23mm  
Body Diameter: 0.91in/23mm

## WEIGHT

3.0oz/85g (Including Battery)

## BODY MATERIAL

Aluminum Alloy

## POWERED BY

Customized 1100mAh 3.6V 18350  
Rechargeable Battery

## WARRANTY

Lifetime Warranty in the USA, Australia, Germany, France and China.  
5-Year Warranty in other countries and regions.  
Visit: <https://olightworld.com/olight-warranty>

## IN THE BOX

Warrior Nano (battery included) x 1  
MCC-1A x 1  
L-Stand x 1  
User Manual x 1

## OPTIONAL ACCESSORY

Omino  
Olink

Note: There are slight differences between the picture and the real item caused by light color temperature. All the pictures are for reference only.