
 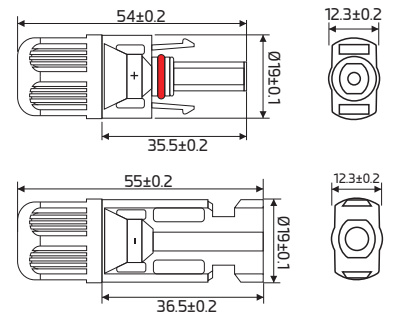



Data Sheet

Solar PV Connector to SAE Battery Connector Cable, 10AWG, L:300MM

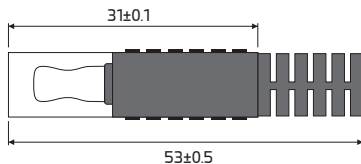

Technical Data

Rated Voltage: 12 V/DC
 Rated Current: 20 A max.
 Contact Resistance: <2.0 mΩ
 Insulation Resistance: >500 MΩ
 Cable Size: AWG 10 / 5.26 mm²
 Cable Length: 300 mm
 Flame Retardant Grade: UL 94V-0
 Operating Temperature: -20°C ~ 85°C
 Protection Level: IP 67 (PV Connector)
 Material
SAE Connector
 Insulation: PVC
 Contact: Nickel Plated Brass
Solar PV Connector
 Hosing: Polycarbonate (PC)
 Terminal Contact: Tin Plated Copper
Solar Cable
 Conductor: Bare Copper
 Insulation Jacket: PVC / VW-1

