


Data Sheet

Solar PV Connector to XT 60 Connector Extension Cable, AWG 12, L: 3M

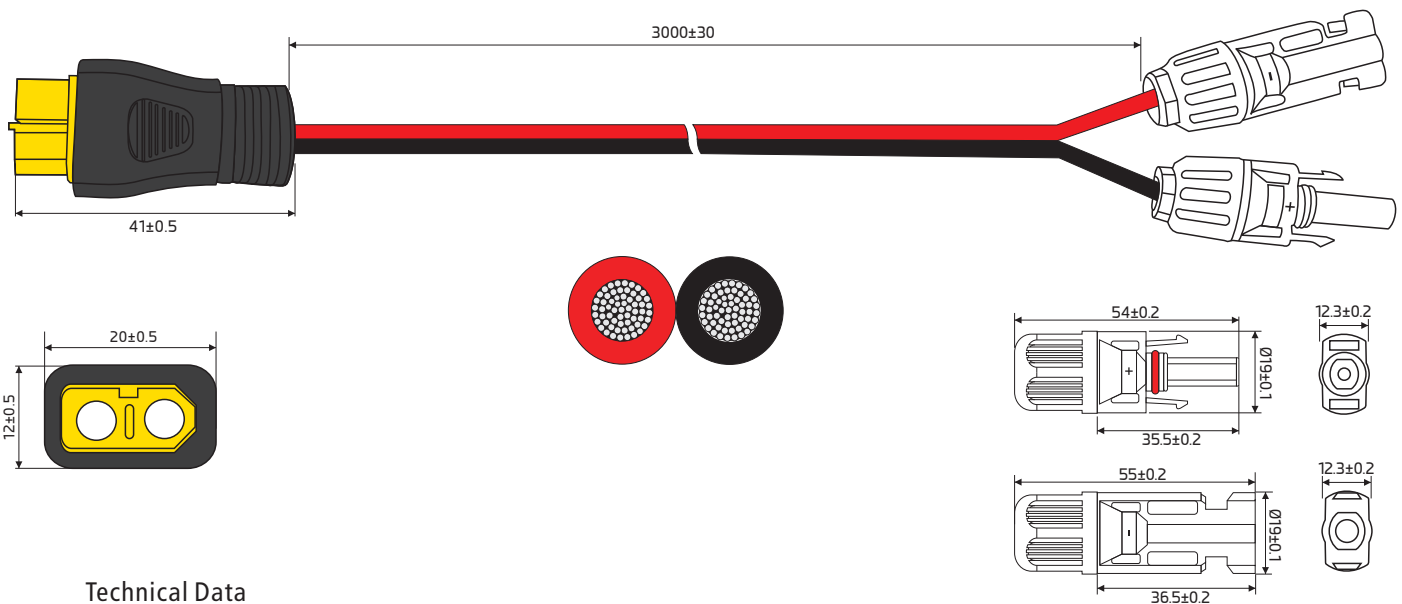

Technical Data

Rated Voltage: 300V
Rated Current: 20 A max.
Contact Resistance: <10 mΩ
Insulation Resistance: >500 MΩ
Cable Size: AWG 12 / 3.30 mm²
Cable Length: 3m
Flame Retardant Grade: UL 94V-0
Operating Temperature: -20°C ~ 85°C
Protection Level: IP 67 (PV Connector)

Material:
XT 60 Connector
Insulation: PA 66, 94V-0
Contact: Gold Plated Copper
Solar PV Connector
Hosing: Polycarbonate (PC)
Terminal Contact: Tin Plated Copper
Solar Cable
Conductor: Bare Copper
Insulation Jacket: PVC / VW-1