


Data Sheet

High Current Battery Connector Extension Cable 50A, 8AWG, 300 mm

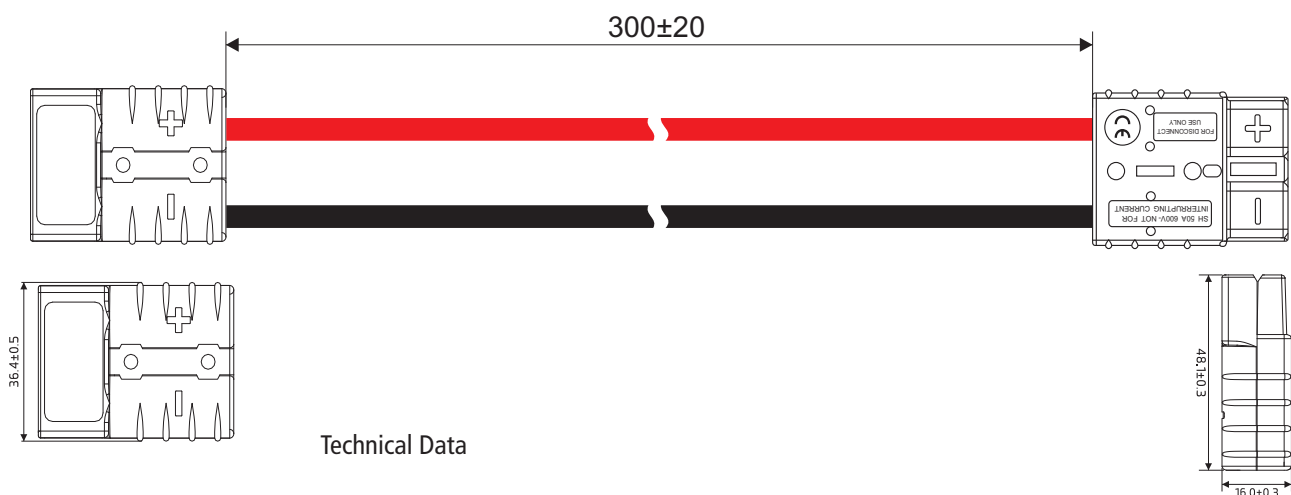

Technical Data

Rated Voltage: 600 V
Rated Current: 50 A max.
Contact Resistance: <2.0 mΩ
Insulation Resistance: >500 MΩ
Connector Housing: Polycarbonate
Terminal Contact: Silver Plated Copper
Cable Size: 8 AWG / 8.36 mm²
Cable Length: 300 mm
Cable Conductor: Bare Copper
Cable Jacket: PVC / VW-1
Flame Retardant Grade: UL 94V-0
Operating Temperature: -20°C ~ 105°C