
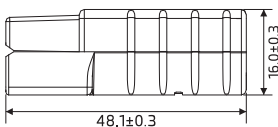
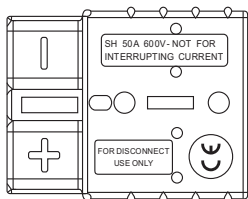


Data Sheet

High Current Connector to M6 Ring Terminal Cable 8AWG, L: 300mm

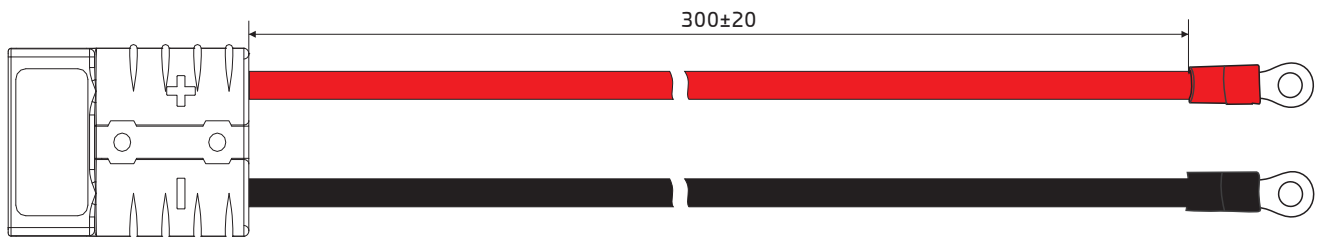

Technical Data

Rated Voltage: 600 V
Rated Current: 50 A max.
Contact Resistance: <2 mΩ
Insulation Resistance: >500 MΩ
Cable Size: 8 AWG / 8.36 mm²
Cable Length: 300 mm
Flame Retardant Grade: UL 94V-0
Operating Temperature: -20°C ~ 75°C
Material:
Ring Terminal
Insulation: PVC
Terminal: Tin Plated Copper
Battery Connector
Hosing: Polycarbonate (PC)
Terminal Contact: Silver Plated Copper
Cable
Conductor: Bare Copper
Insulation: PVC / VW-1

