


Data Sheet

High Current Connector to M6 Ring Terminal Cable, with 50A Car Fuse, 8AWG,L: 400mm

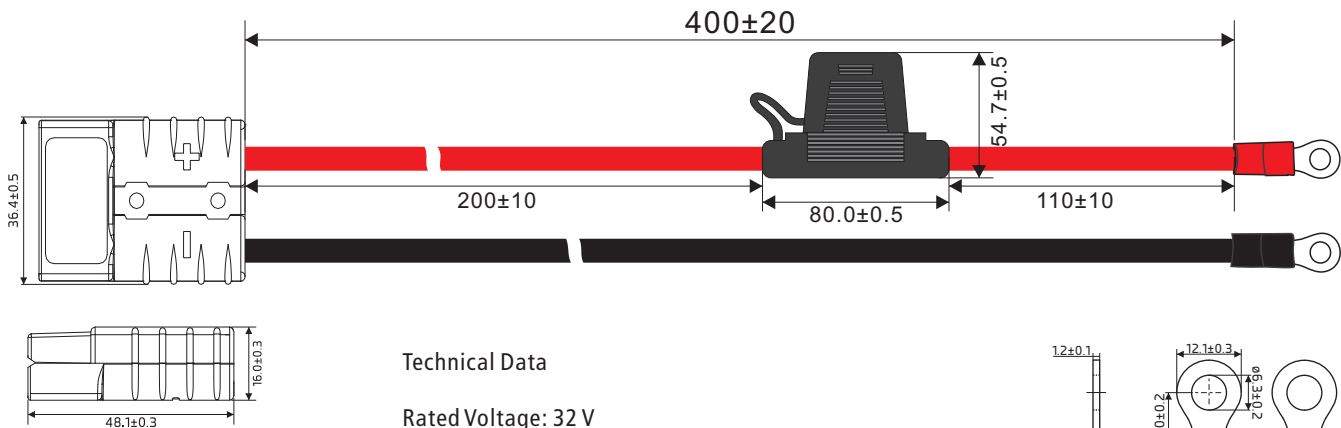

Technical Data

Rated Voltage: 32 V
 Rated Current: 50 A
 Contact Resistance: <1.5 mΩ
 Insulation Resistance: >500 MΩ
 Cable Size: AWG 8 / 8.36 mm²
 Cable Length: 400 mm
 Flame Retardant Grade: UL 94V-0
 Operating Temperature: -20°C ~ 85°C
 Material
Ring Terminal
 Insulation: PVC
 Terminal: Tin Plated Copper
Battery Connector
 Hosing: Polycarbonate (PC)
 Terminal Contact: Silver Plated Copper
Cable
 Conductor: Bare Copper
 Insulation: PVC / VW-1

