
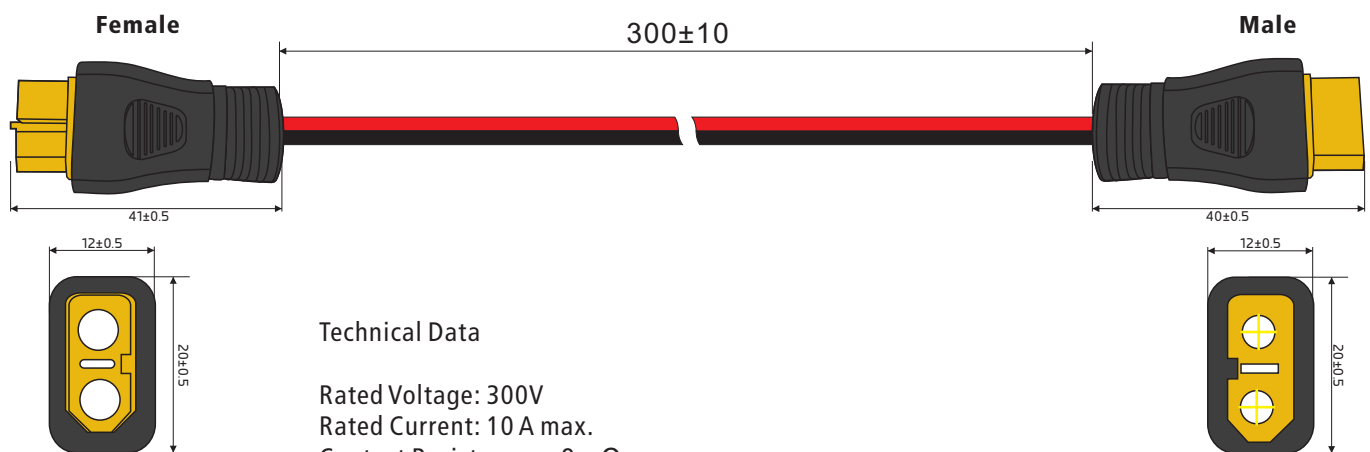
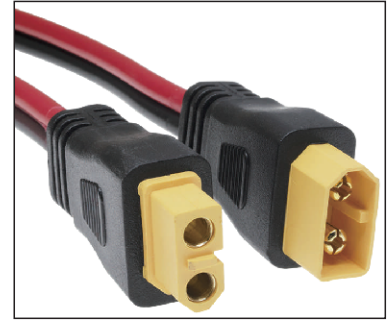


Data Sheet

XT60 Male to Female Extension Cable, 16 AWG, L: 300mm

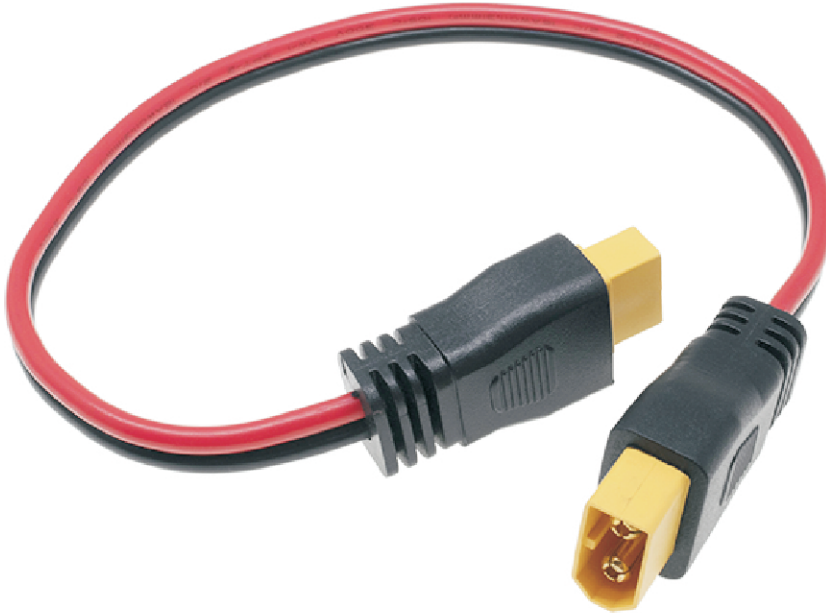

Technical Data

Rated Voltage: 300V
Rated Current: 10 A max.
Contact Resistance: <8 mΩ
Insulation Resistance: >500 MΩ
Cable Size: AWG 16 / 1.3 mm²
Cable Length: 300 mm
Flame Retardant Grade: UL 94V-0
Operating Temperature: -10°C ~ 105°C
Material
XT 60 Connector
Insulation: PA 66, 94V-0
Contact: Gold Plated Copper
Cable
Conductor: Bare Copper
Insulation Jacket: PVC / VW-1