


Data Sheet

Solar PV Connector to Mini Battery Connector Cable, 10 AWG,L:250mm

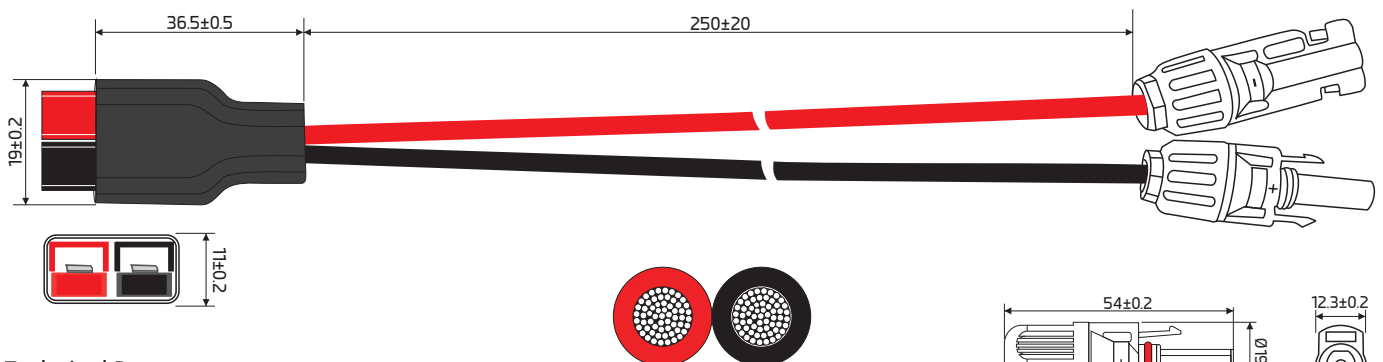

Technical Data

Rated Voltage: 600 V
 Rated Current: 30 A max.
 Contact Resistance: <2.0 mΩ
 Insulation Resistance: >500 MΩ
 Cable Size: AWG 10 / 5.26 mm²
 Cable Length: 250 mm
 Flame Retardant Grade: UL 94V-0
 Operating Temperature: -20°C ~ 85°C
 Protection Level: IP 67 (PV Connector)
 Material
 Battery Connector
 Housing: Polycarbonate (PC)
 Insulation Cover: PVC
 Terminal Contact: Silver Plated Copper
 Solar PV Connector
 Hosing: Polycarbonate (PC)
 Terminal Contact: Tin Plated Copper
 Solar Cable
 Conductor: Bare Copper
 Insulation Jacket: PVC / VW-1

