
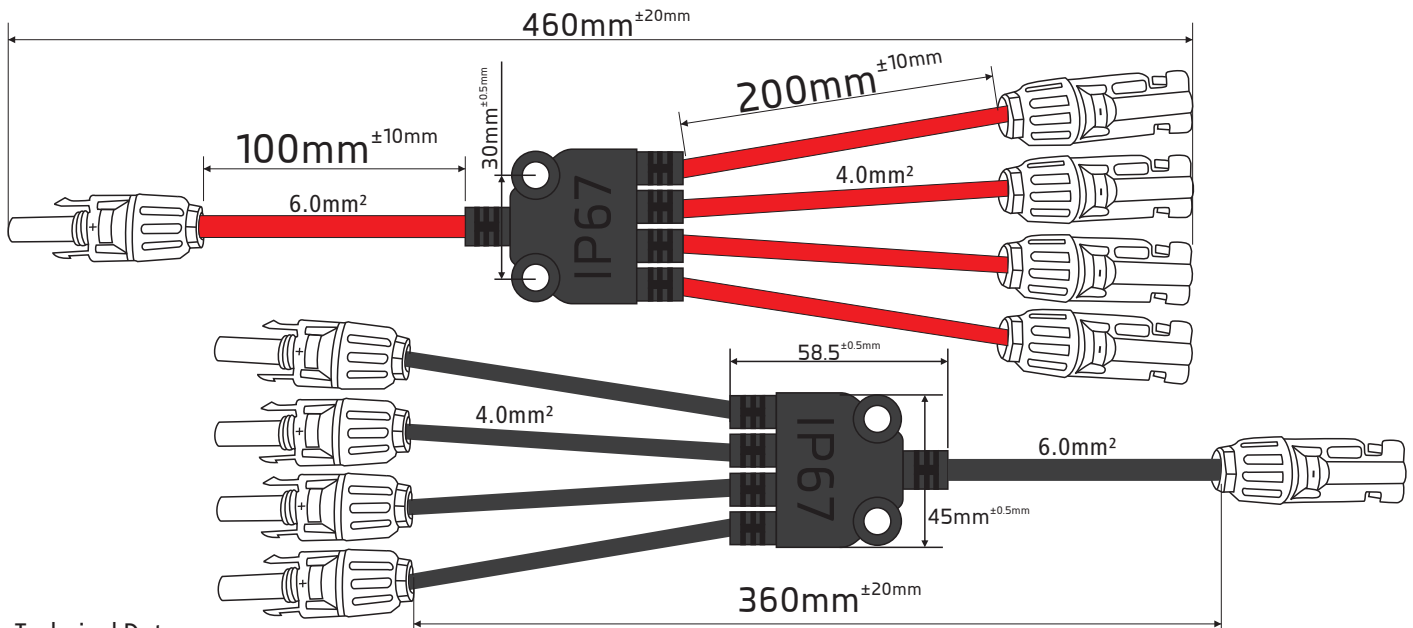
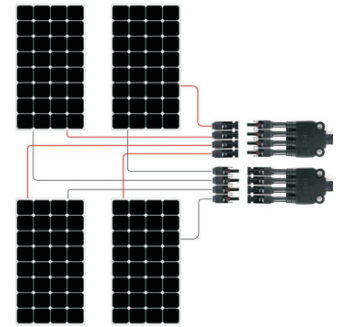


Data Sheet

Solar PV Connectors Y Branch 1 Male to 4 Female and 1 Female to 4 Male

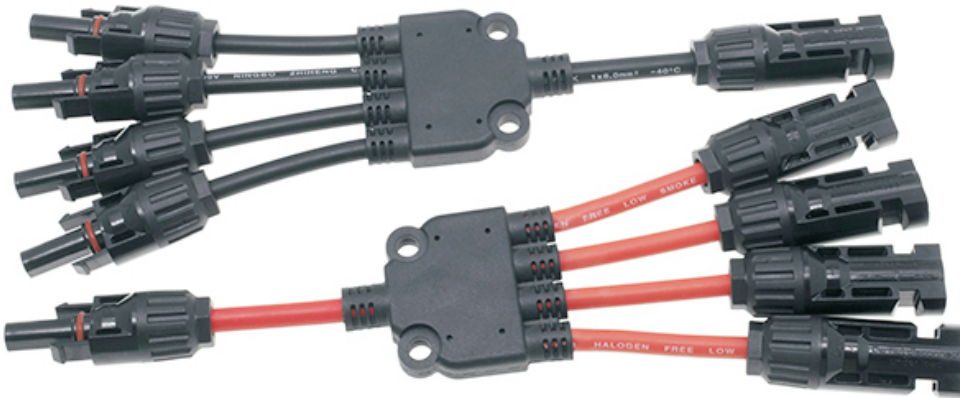

Technical Data

Rated Voltage: 1000 V/DC
 Rated Current: 30 A max.
 Contact Resistance: <2.0 mΩ
 Insulation Resistance: >500 MΩ
 Connector Housing: Polycarbonate
 Terminal Contact: Tin Plated Copper
 Cable Cross Section: 6.0 / 4.0 mm²
 Cable Length: 360 mm, overall 460 mm
 Cable Conductor: Tin Plated Copper
 Cable Jacket: XLPE
 Flame Retardant Grade: UL 94V-0
 Operating Temperature: -20°C ~ 85°C
 Protection Level: IP 67

