


NO MERCURY AND CADMIUM ADDED

Description	: Mercury & Cadmium Free Alkaline Manganese Battery, AA Size
Chemical System	: Alkaline Manganese
Nominal Voltage	: 1.5 Volts
Nominal Dimensions	: \varnothing 14.5 mm x 50.5 mm
Terminals	: Protruded positive (+) and flat negative (-) contacts
Jacket	: Foil jacket
Applications	: Internet of Things (IoT), sensors, home security products, smart remote control, wireless mouse/ keyboard, toys, smart meters, medical/ smart healthcare, thermometers, dispensers
Average Weight	: 23g

Model No.: **GN15A**

FOR INDUSTRIAL MARKET ONLY

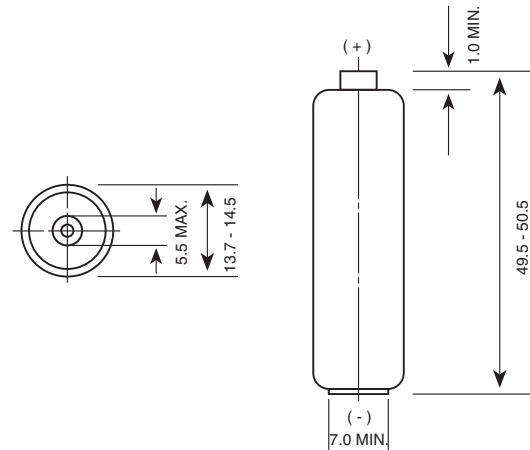

Unit : mm

Cross References:

GP	JIS	IEC	Eveready	Duracell
15A	LR6	LR6	E91	MN1500

The information (subject to change without prior notice) contained in this document is for reference only and should not be used as a basis for product guarantee or warranty. For applications other than those described here, please consult your nearest GP Sales and Marketing Office or Distributors.

