


NO MERCURY AND CADMIUM ADDED

| | |
|---------------------------|--|
| Description | : Mercury & Cadmium Free Alkaline Manganese Battery, AAA Size |
| Chemical System | : Alkaline Manganese |
| Nominal Voltage | : 1.5 Volts |
| Nominal Dimensions | : $\varnothing 10.5$ mm x 44.5 mm |
| Terminals | : Protruded positive (+) and flat negative (-) contacts |
| Jacket | : Foil jacket |
| Applications | : Internet of Things (IoT), sensors, home security products, smart remote control, wireless mouse/ keyboard, toys, smart meters, medical/ smart healthcare, thermometers, dispensers |
| Average Weight | : 11.5g |

Model No.: **GN24A**

FOR INDUSTRIAL MARKET ONLY

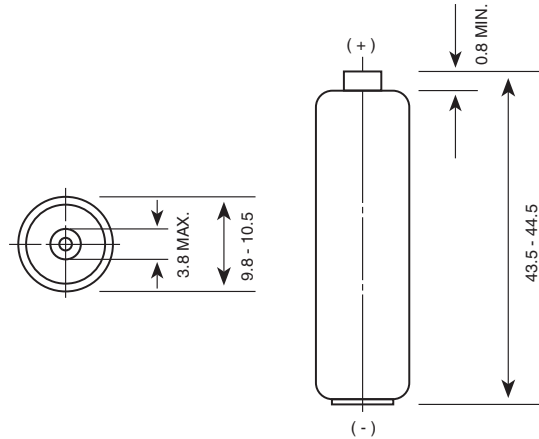

Unit : mm

Cross References:

| GP | JIS | IEC | Eveready | Duracell | Varta |
|-----|------|------|----------|----------|-------|
| 24A | LR03 | LR03 | E92 | MN2400 | 4003 |

The information (subject to change without prior notice) contained in this document is for reference only and should not be used as a basis for product guarantee or warranty. For applications other than those described here, please consult your nearest GP Sales and Marketing Office or Distributors.

