


Kat. Nr. 43.2040.01

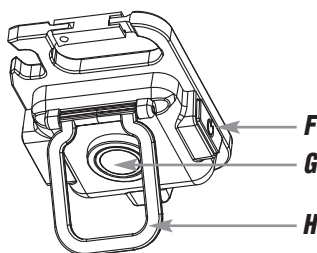

Kat. Nr. 43.2040.01

## Bedienungsanleitung – COB Mini Arbeitsleuchte

(D)

Vielen Dank, dass Sie sich für dieses Gerät aus dem Hause TFA entschieden haben.

### 1. Bevor Sie mit dem Gerät arbeiten:

- Lesen Sie sich bitte die Bedienungsanleitung genau durch.
- Die Bedienungsanleitung liegt dem Gerät bei oder zum Download unter [www.tfa-dostmann.de/service/downloads/anleitungen](http://www.tfa-dostmann.de/service/downloads/anleitungen).
- Durch die Beachtung der Bedienungsanleitung vermeiden Sie auch Beschädigungen des Gerätes und die Gefährdung Ihrer gesetzlichen Mängelrechte durch Fehlgebrauch.
- Beachten Sie besonders die Sicherheitshinweise!
- Bewahren Sie die Bedienungsanleitung gut auf!

### 2. Lieferumfang

- Universallampe
- USB-C Ladekabel
- Bedienungsanleitung

### 3. Zu Ihrer Sicherheit

- Verwenden Sie das Produkt nicht anders, als in dieser Bedienungsanleitung dargestellt wird.



**Vorsicht!**  
**Lebensgefahr durch Stromschlag!**

- Schließen Sie das Gerät über das USB-Kabel nur an eine geeignete USB-Spannungsquelle an.
- Das Gerät darf beim Ladevorgang nicht mit Wasser oder Feuchtigkeit in Kontakt kommen.
- Laden Sie das Gerät nicht, wenn das Gehäuse beschädigt ist.
- Laden Sie das Gerät außerhalb der Reichweite von Personen (auch Kindern) auf, die möglichen Gefahren im Umgang mit elektrischen Geräten nicht richtig einschätzen können.
- Trennen Sie das Gerät sofort von der Ladestromquelle, wenn eine Störung auftritt.



**WARNUNG!**  
**Verletzungsgefahr!**

- Mit der Lampe nicht direkt in die Augen leuchten!
- Kleinteile können von Kindern (unter drei Jahren) verschluckt werden.
- Explosions- und Brandgefahr lithiumhaltiger Akkus durch Hitze oder mechanische Beschädigungen!
- Vor hohen Temperaturen schützen. Nicht ins Feuer werfen, kurzschließen oder auseinandernehmen.
- Wird das Gerät beim Laden heiß, oder wird die Batterie nicht mehr aufgeladen, ist das ein Zeichen für einen Defekt. Trennen Sie das Gerät sofort von der Ladestromquelle.
- Der Akku kann und darf nicht selbst ausgetauscht oder ausgebaut werden. Bei unsachgemäßem Auswechseln des Akkus besteht Explosionsgefahr. Qualifiziertes Fachpersonal kann bei Bedarf unter [info@tfa-dostmann.de](mailto:info@tfa-dostmann.de) Instruktionen zum Demontieren des fest eingebauten Akkus einholen, sollte dies zu Zwecken einer Reparatur oder Recycling des Produktes erforderlich sein.



**ACHTUNG**

- Das eigenmächtige Reparieren, Umbauen oder Verändern des Gerätes ist nicht gestattet.
- Setzen Sie das Gerät keinen extremen Temperaturen, Vibrationen und Erschütterungen aus.
- Das Gerät ist nicht bruchsicher. Beim Herunterfallen könnten sich Teile lösen.
- Reinigen Sie das Gerät mit einem weichen, leicht feuchten Tuch. Keine Scheuer- oder Lösungsmittel verwenden!

### 4. Bestandteile

- A:** Karabiner  
**B:** Flaschenöffner  
**C:** COB Licht  
**D:** USB-C Anschluss  
**E:** LED Ladestatus-Anzeige  
**F:** ON/OFF Taste  
**G:** Magnet  
**H:** Flexibler Klappständer

### 5. Aufladen

- Entfernen Sie die Gummi-Schutzkappe. Achten Sie darauf, dass sie dabei nicht verloren geht. Stecken Sie das mitgelieferte USB-Kabel in den vorgesehenen Anschluss am Gerät und schließen Sie das Gerät an eine geeignete USB-Spannungsquelle an.
- Zum vollständigen Aufladen lassen Sie das Gerät für ungefähr 70 Minuten angeschlossen.
- Der Ladestatus der Batterie wird durch die LED-Kontrollleuchte ersichtlich: Rotes Licht: Akku wird aufgeladen, grünes Licht: Akku ist aufgeladen.
- Trennen Sie dann das Gerät von der Ladestromquelle.
- Laden Sie den Akku alle sechs Monate nach, auch wenn das Produkt nicht benötigt wird.
- Nach dem Aufladen die Ladebuchse wieder mit der Gummi-Schutzkappe verschließen.

## Bedienungsanleitung – COB Mini Arbeitsleuchte

(D)

### 6. Inbetriebnahme und Bedienung

- Entfernen Sie die Schutzfolie.
- Vor dem ersten Gebrauch bitte vollständig aufladen.
- Drücken Sie kurz die **ON/OFF** Taste und wählen Sie die gewünschte Lichteinstellung aus. Die Reihenfolge ist wie folgt:
  - Weißes Licht normal
  - Weißes Licht schwach
  - Rotes Blinklicht
  - Rotes Licht
- Bei erneutem Drücken schaltet sich die Lampe aus.
- Halten Sie die **ON/OFF** Taste gedrückt, schaltet sich das starke Licht an.

### 7. Fehlerbeseitigung

| Problem    | Lösung                                                                             |
|------------|------------------------------------------------------------------------------------|
| Kein Licht | → Zum Einschalten <b>ON/OFF</b> Taste drücken<br>→ Akku mit USB-Ladekabel aufladen |

Wenn Ihr Gerät trotz dieser Maßnahmen immer noch nicht funktioniert, wenden Sie sich an den Händler, bei dem Sie das Produkt gekauft haben.

### 8. Entsorgung

Dieses Produkt und die Verpackung wurden unter Verwendung hochwertiger Materialien und Bestandteile hergestellt, die recycelt und wiederverwendet werden können. Dies verringert den Abfall und schon die Umwelt.

Entsorgen Sie die Verpackung umweltgerecht über die eingerichteten Sammelssysteme.



#### Entsorgung des Elektrogeräts

**Achtung!** Dieses Gerät enthält einen Akku, der fest eingebaut ist und nicht entnommen werden kann, ohne das Gehäuse zu zerstören. Ein unsachgemäßer Ausbau stellt ein Sicherheitsrisiko dar. Geben Sie das Gerät ungeöffnet bei der Sammelstelle ab, die Gerät und Akku fachgerecht entsorgt.

Dieses Gerät ist entsprechend der EU-Richtlinie über die Entsorgung von Elektro- und Elektronik-Altgeräten (WEEE) gekennzeichnet.

Dieses Produkt darf nicht mit dem Hausmüll entsorgt werden. Der Nutzer ist verpflichtet, das Altgerät zur umweltgerechten Entsorgung bei einer ausgewiesenen Annahmestelle für die Entsorgung von Elektro- und Elektronikgeräten abzugeben. Beachten Sie die aktuell geltenden Vorschriften!



**WARNUNG!**

#### Explosionsgefahr bei lithiumhaltigen Batterien

- Bei lithiumhaltigen Altbatterien und Akkus (Li=Lithium) besteht hohe Brand- und Explosionsgefahr durch Hitze oder mechanische Beschädigungen mit möglichen schwerwiegenden Folgen für Mensch und Umwelt. Achten Sie besonders auf die ordnungsgemäße Entsorgung.

### 9. Technische Daten

|                     |                                              |
|---------------------|----------------------------------------------|
| Lichtquelle         | 6W COB LED                                   |
| Spannungsversorgung | Integrierter Li-Ion Akku                     |
| Akku-Typ            | 3,7V, 300 mAh                                |
| Ladeeingang         | USB Typ C                                    |
| Lumen               | 350/180/40                                   |
| Zubehör             | USB-C Ladekabel                              |
| Ladedauer           | Ca. 70 Minuten                               |
| Akkulaufzeit        | Ca. 1-3,5 Stunden (je nach Lichteinstellung) |
| Gehäusemaße         | 47 x 22 x 62 mm                              |
| Gewicht             | 40 g (nur das Gerät)                         |

TFA Dostmann GmbH & Co.KG, Zum Ottersberg 12, 97877 Wertheim, Deutschland


Diese Anleitung oder Auszüge daraus dürfen nur mit Zustimmung von TFA Dostmann veröffentlicht werden. Die technischen Daten entsprechen dem Stand bei Drucklegung und können ohne vorherige Benachrichtigung geändert werden.

Die neuesten technischen Daten und Informationen zu Ihrem Produkt finden Sie auf unserer Homepage unter Eingabe der Artikel-Nummer in das Suchfeld.

E-Mail: [info@tfa-dostmann.de](mailto:info@tfa-dostmann.de)


[www.tfa-dostmann.de](http://www.tfa-dostmann.de)

03/24

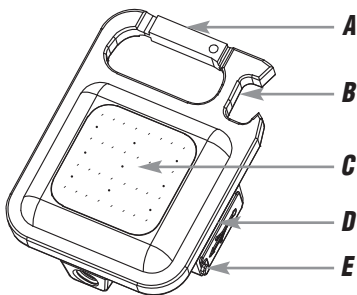

TFA

Cat.-No. 43.2040.01

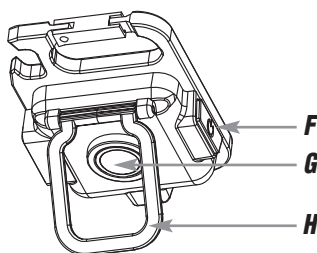

TFA



Cat.-No. 43.2040.01

## Instruction manual – COB mini work light

GB

Thank you for choosing this product from TFA..

### 1. Before you use this device

- Please make sure you read the instruction manual carefully.
- The operating instructions are enclosed with the device or can be downloaded at [www.tfa-dostmann.de/en/service/downloads/instruction-manuals](http://www.tfa-dostmann.de/en/service/downloads/instruction-manuals)
- Following and respecting the instructions in your manual will prevent damage to your instrument and loss of your statutory rights arising from defects due to incorrect use.
- Please pay particular attention to the safety notices!
- Please keep this instruction manual safe for future reference.

### 2. Delivery contents

- Universal lamp
- Charging cable USB-C
- Instruction manual

### 3. For your safety

- This product should only be used as described within these instructions.



**Caution!**  
**Risk of electrocution!**

- Connect the device via the USB cable only to a suitable USB power source.
- The product must not come into contact with water or moisture while loading.
- Do not charge the product if the housing is damaged.
- Charge the device out of reach of persons (including children) who cannot fully appreciate the potential risks of handling electrical equipment.
- Disconnect the device from the charging power source immediately if any fault occurs.



**WARNING!**  
**Risk of injury!**

- Do not shine light directly into eyes!
- Small parts can be swallowed by children (under three years old).
- Batteries containing lithium carry a risk of fire or explosion due to heat or mechanical damage!
- Protect it from high temperatures. Do not throw into fire, short-circuit or take apart.
- If the device becomes hot while charging or the battery is no longer charged, this is a sign of a defect. Disconnect the device from the charging power source immediately.
- The battery cannot and must not be replaced or removed by you. There is a risk of explosion if the battery is replaced incorrectly. If necessary, a qualified person can obtain instructions on how to dismantle the permanently installed battery from [info@tfa-dostmann.de](mailto:info@tfa-dostmann.de), should this be necessary for the purpose of repairing or recycling the product.



**CAUTION**

- Unauthorised repairs, alterations or changes to the product are prohibited.
- Do not expose the device to extreme temperatures, vibrations or shocks.
- The instrument is not unbreakable. In case of falling down parts can break.
- Clean the device with a soft damp cloth. Do not use solvents or scouring agents.

### 4. Elements

- A:** Carabiner  
**B:** Bottle opener  
**C:** COB light  
**D:** USB-C port  
**E:** LED charging status indicator  
**F:** ON/OFF button  
**G:** Magnet  
**H:** Flexible folding stand

### 5. Charging

- Pull off the rubber protection. Make sure that the rubber protection does not get lost. Plug the supplied USB-cable into the designated port on the device and connect the unit to a suitable USB power source.
- To fully charge, leave the device connected for approximately 70 minutes.
- The battery's charge status is indicated by the LED indicator light.
- Red light: the battery is charging, green light: the battery is fully charged.
- Disconnect the device from the charging power source.
- Recharge the battery every six months, even if the product is not in use.
- After charging, be sure to reseal the charging port with the rubber protection.

### 6. Getting started/Operation

- Remove the protective film.
- Before the first use, please charge it fully.
- Press the ON/OFF button shortly and select your respective light setting. The sequence is shown as follows:
  - White light normal

## Instruction manual – COB mini work light

GB

- White light low
- Red flashing light
- Red light
- Pressing the button again switches the light off.
- If you press and hold the ON/OFF button, the strong light switches on.

### 7. Troubleshooting

| Problem  | Solution                                                                                         |
|----------|--------------------------------------------------------------------------------------------------|
| No light | → Press the ON/OFF button to switch on the device<br>→ Charge the battery via USB charging cable |

If your device fails to work despite these measures, please contact the retailer where you purchased the product from for advice.

### 8. Waste disposal

This product and its packaging have been manufactured using high-grade materials and components which can be recycled and reused. This reduces waste and protects the environment.

Dispose of the packaging in an environmentally friendly manner using the collection systems that have been set up.



#### Disposal of the electrical device

**Caution!** This device contains a built-in battery that cannot be removed without damaging the housing. Improper removal represents a safety risk. Hand in the device unopened at the collection point; the device and battery will be disposed of properly. This product is labelled in accordance with the EU Waste Electrical and Electronic Equipment Directive (WEEE). This product must not be disposed of in ordinary household waste. As a consumer, you are required to take end-of-life devices to a designated collection point for the disposal of electrical and electronic equipment, in order to ensure environmentally-compatible disposal. Observe the current regulations in place!



**WARNING!**  
**Batteries containing lithium can explode**

- Old batteries and rechargeable batteries containing lithium (Li=lithium) present a high risk of fire and explosion due to heat or mechanical damage with potentially serious consequences for people and the environment. Pay particular attention to correct disposal.

### 9. Specifications

|                           |                                                  |
|---------------------------|--------------------------------------------------|
| Light source              | 6W COB LED                                       |
| Power consumption         | Built-in Li-Ion rechargeable battery             |
| Rechargeable battery type | 3.7V, 300 mAh                                    |
| Charging input            | USB Type C                                       |
| Lumen                     | 350/180/40                                       |
| Accessories               | USB-C charging cable                             |
| Charging time             | Approx 70 minutes                                |
| Battery runtime           | Approx. 1-3,5 hours (depending on light setting) |
| Housing dimension         | 47 x 22 x 62 mm                                  |
| Weight                    | 40 g (device only)                               |

TFA Dostmann GmbH & Co.KG, Zum Ottersberg 12, 97877 Wertheim, Germany

No part of this manual may be reproduced without written consent of TFA Dostmann. The technical data are correct at the time of going to print and may change without prior notice. The latest technical data and information about this product can be found in our homepage by simply entering the product number in the search box.

E-Mail: [info@tfa-dostmann.de](mailto:info@tfa-dostmann.de)

[www.tfa-dostmann.de](http://www.tfa-dostmann.de)

03/24



#### Instruction manuals

[www.tfa-dostmann.de/en/service/downloads/instruction-manuals](http://www.tfa-dostmann.de/en/service/downloads/instruction-manuals)