

G&G Mini Label Printer

The Inkless Sticker Printer

The inkless sticker printer uses thermal printing technology and includes 3 rolls of thermal printing paper. This ink-free printer features 2-inch wide paper that can be cut to any length or shape, allowing you to create custom stickers anytime, anywhere (Black and White only).




Scan the QR Code to Explore the Printer

Compact and Portable Design

This mini thermal printer fits easily in a schoolbag or handbag and takes up minimal space on desks or counters. Perfect for recording study notes or work plans.

Easy to Use—Only 4 Steps Needed!

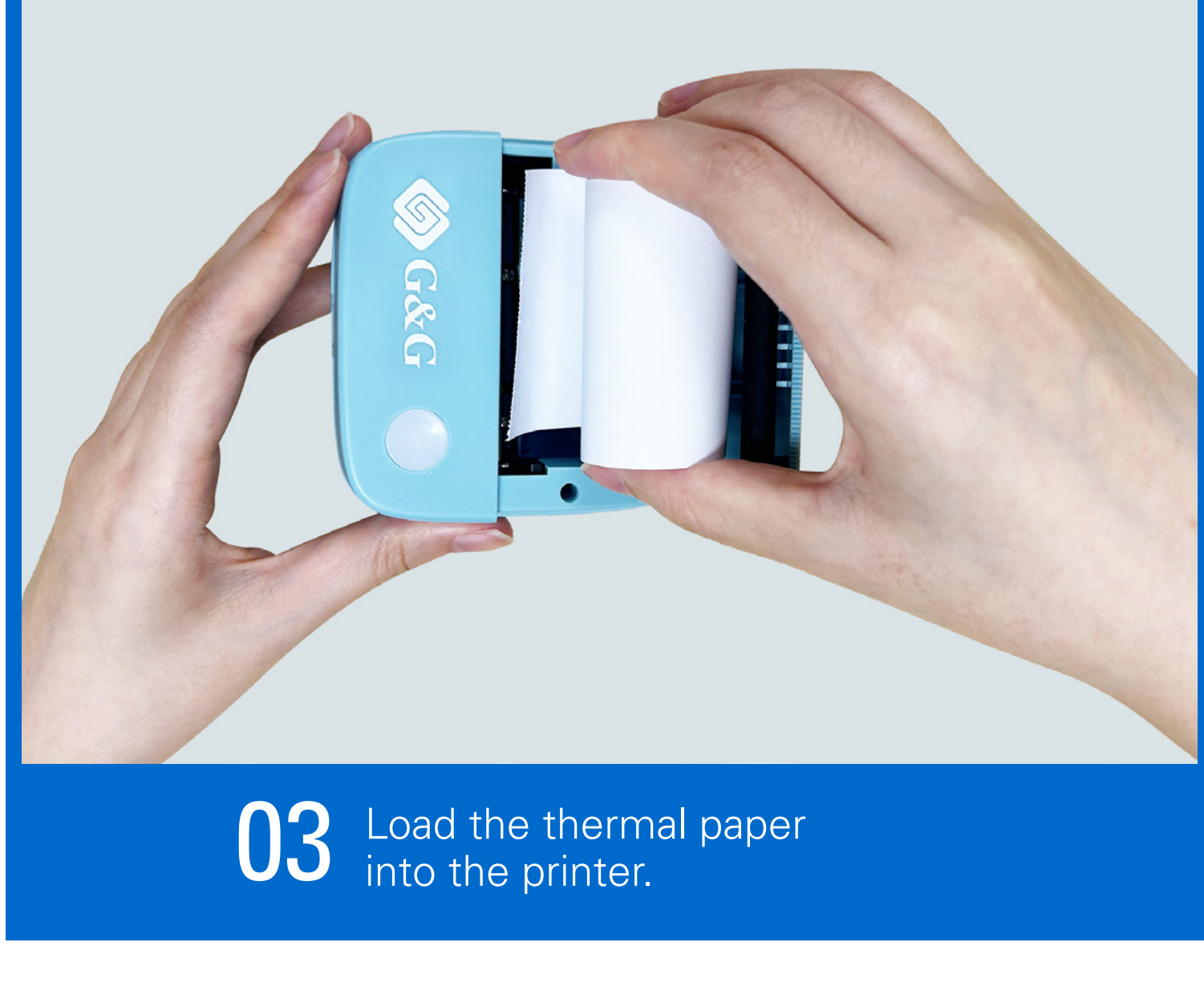

Versatile Printing Capabilities

Print black and white photos, images, notes, to-do lists, and shopping lists. Customize bookmarks, labels, magazines, and greeting cards with the app's templates. Compatible with Android and iOS.



203dpi High-resolution Printing Protects Children's Eyes




Specifications


Printing	Printing Technology	DirectThermal
	Resolution	203 dpi
	Print Speed	10mm/s
	Print Color	Black & White
	Interface	USB, Bluetooth
	Print Width	Maximum 57mm
	Compatible with	Android 5.0 and iOS 11.0 or above
Media	Type	Thermal paper & thermal self-adhesive paper
Power	Battery	1000mAH
	Input Voltage	5V, 1A
	Charging	USB charging
Temperature & Humidity	Operating Environment	Temperature: 5°C to 40°C
		Humidity: 20% to 70% RH (no condensation)
Physical Properties	Dimensions	82 × 82 × 40 mm
	Weight	140 g
Print Cycles	Print Life	30km

Available Mini Printer Paper

Thermal Paper

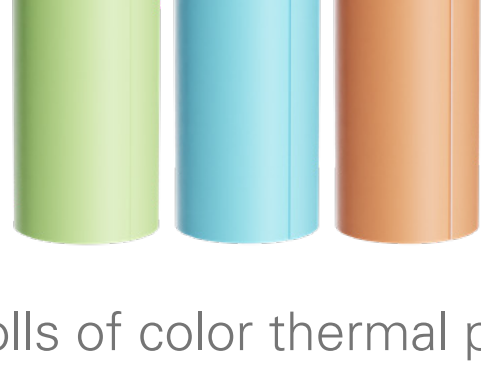

3 rolls of color thermal paper

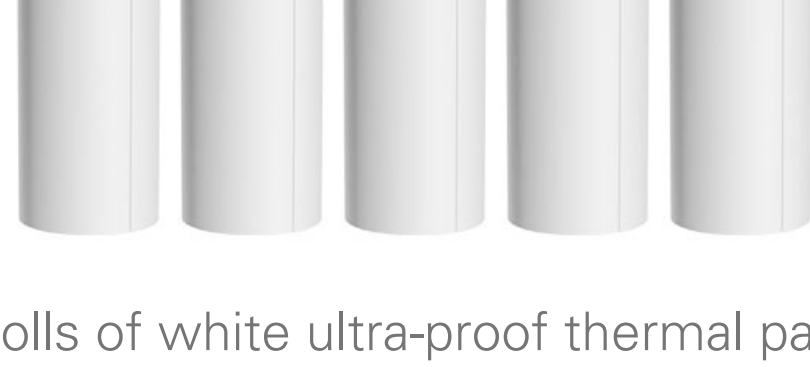


5 rolls of white ultra-proof thermal paper



5 rolls of white thermal paper

Self-adhesive

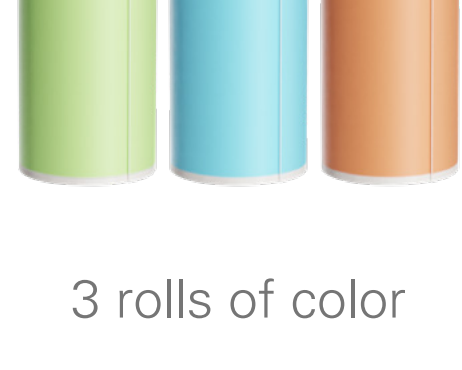

3 rolls of color self-adhesive thermal paper



5 rolls of white self-adhesive thermal paper



5 rolls of white self-adhesive stickers (57mm*15mm)



5 rolls of white self-adhesive stickers (57mm*30mm)