



Model #980514 / 240347 / 692978

3 TON

DOUBLE LOCK JACK STANDS

Operating and Maintenance
Instruction Manual

DOUBLE LOCK JACK STANDS

Operating and Maintenance
Instruction Manual




Double Locking Safety Pin
Double Locking Safety Pin



Please retain these instructions for future reference. If you encounter any problems or difficulties please do not return this jack to the store.

Please retain these instructions for future reference. If you encounter any problems or difficulties please do not return this jack to the store.

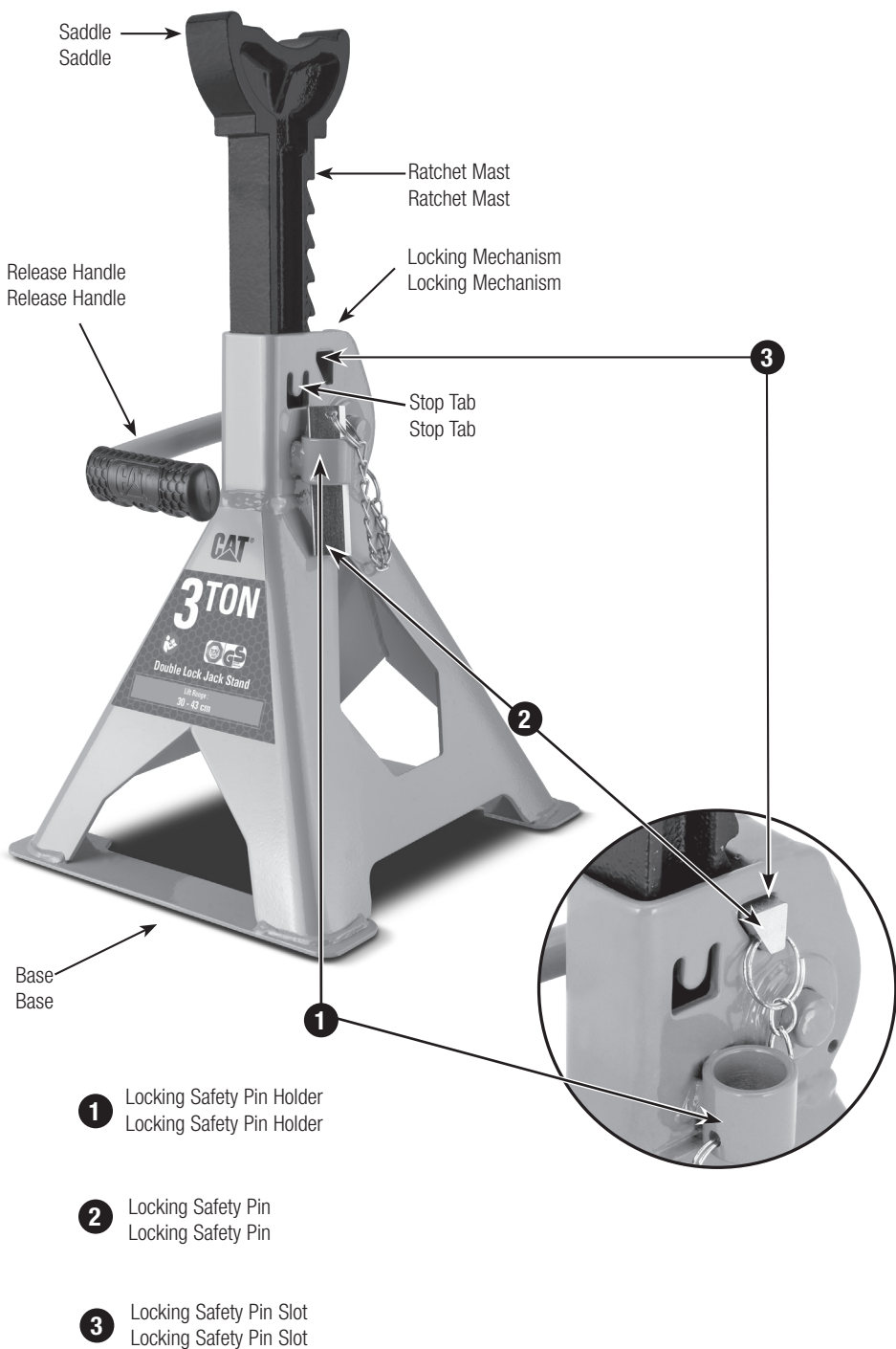

DOUBLE LOCK JACK STANDS






OPERATING AND MAINTENANCE INSTRUCTION MANUAL

SPECIFICATIONS

Rated Capacity (Safe Working Load)	3000 KG
Weight (for 1 jack stand)	3.2 KG
Minimum Lift Height	30 cm
Maximum Lift Height	43 cm

⚠ WARNING

- STUDY, UNDERSTAND, AND FOLLOW ALL INSTRUCTIONS BEFORE OPERATING THIS DEVICE.
- DO NOT EXCEED RATED CAPACITY.
- USE ONLY ON A HARD LEVEL SURFACE.
- CENTER LOAD ON SADDLE.
- USE AS A MATCHED PAIR TO SUPPORT ONE END OF A VEHICLE ONLY.
- FAILURE TO HEED THESE WARNINGS MAY RESULT IN PERSONAL INJURY AND/OR PROPERTY DAMAGE.
- STANDS ARE NOT TO BE USED TO SIMULTANEOUSLY SUPPORT BOTH ENDS OR ONE SIDE OF A VEHICLE.
- NO ALTERATIONS SHALL BE MADE TO THIS PRODUCT.

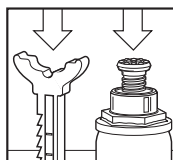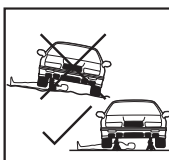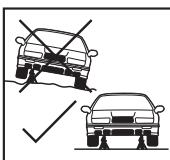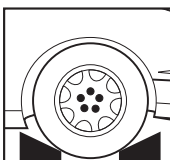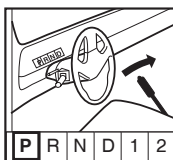

OWNER AND/OR OPERATOR RESPONSIBILITY

It is the owner and/or operator's responsibility to read and understand all WARNINGS and operating instructions contained on the product labels and instruction manual prior to operation of these stands.

It is also the owner and/or operator's responsibility to periodically inspect and maintain these stands and labels in good working order.

ASSEMBLY

These stands are completely assembled except for the ratchet mast stop tab. Place the ratchet mast down through the base locking mechanism and bend the stop tab toward the mast. This prevents accidental removal of the ratchet mast from the base.

POSITIONING STANDS

1. Lift the vehicle following the jack instructions. Be sure to set the parking brake and block the unlifted tires.
2. Consult the vehicle's owner's manual to determine the location of support points and position the stands beneath the ideal points. Do not crawl under the vehicle to position the stands. Raise the mast to the highest position making sure the tooth is fully engaged by the locking mechanism. Insert locking safety pin as shown for added safety. Make sure both stands are at an equal height.
3. Slowly lower the vehicle onto the stands making sure the load is centered on the saddles. Make sure the load and stands are stable.



Locking Safety Pin

REMOVING STANDS

1. Raise the vehicle high enough to clear the stands.
2. Remove the stands being careful not to crawl under the vehicle.
3. Slowly lower the vehicle to the ground.

INSPECTION

Periodically inspect the stands for broken or cracked welds, broken or worn teeth on the ratchet mast or locking mechanism, loose or missing parts. If you notice anything remove the stands from service until repaired or replaced.

DOUBLE LOCK JACK STANDS






OPERATING AND MAINTENANCE INSTRUCTION MANUAL

SPECIFICATIONS

Rated Capacity (Safe Working Load)	3000 KG
Weight (for 1 jack stand)	3.2 KG
Minimum Lift Height	30 cm
Maximum Lift Height	43 cm

⚠️WARNUNG

- LESEN, VERSTEHEN UND BEFOLGEN SIE ALLE ANWEISUNGEN, BEVOR SIE DIESES GERÄT IN BETRIEB NEHMEN.
- DIE NENNKAPAZITÄT NICHT ÜBERSCHREITEN.
- NUR AUF EINER HARTEN, EBENEN OBERFLÄCHE VERWENDEN.
- ZENTRALLAST AUF SATTEL.
- ALS PASSENDES PAAR VERWENDEN, UM NUR EIN ENDE EINES FAHRZEUGS ZU HALTEN.
- DIE NICHTBEACHTUNG DIESER WARHNHINWEISE KANN ZU VERLETZUNGEN UND/ODER SACHSCHÄDEN FÜHREN.
- STÄNDER DÜRFEN NICHT VERWENDET WERDEN, UM BEIDE ENDEN ODER EINE SEITE EINES FAHRZEUGS GLEICHZEITIG ZU STÜTZEN.
- AN DIESEM PRODUKT DÜRFEN KEINE ÄNDERUNGEN VORGENOMMEN WERDEN.

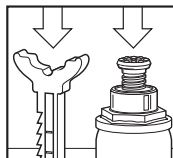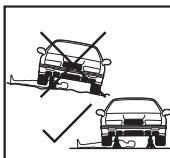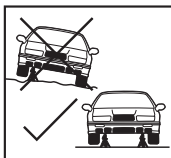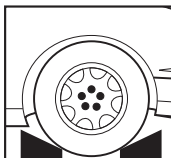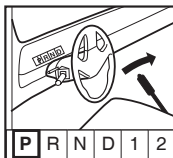

OWNER AND/OR OPERATOR RESPONSIBILITY

It is the owner and/or operator's responsibility to read and understand all WARNINGS and operating instructions contained on the product labels and instruction manual prior to operation of these stands.

It is also the owner and/or operator's responsibility to periodically inspect and maintain these stands and labels in good working order.

ASSEMBLY

These stands are completely assembled except for the ratchet mast stop tab. Place the ratchet mast down through the base locking mechanism and bend the stop tab toward the mast. This prevents accidental removal of the ratchet mast from the base.

POSITIONING STANDS

1. Lift the vehicle following the jack instructions. Be sure to set the parking brake and block the unlifted tires.
2. Consult the vehicle's owner's manual to determine the location of support points and position the stands beneath the ideal points. Do not crawl under the vehicle to position the stands. Raise the mast to the highest position making sure the tooth is fully engaged by the locking mechanism. Insert locking safety pin as shown for added safety. Make sure both stands are at an equal height.
3. Slowly lower the vehicle onto the stands making sure the load is centered on the saddles. Make sure the load and stands are stable.



Locking Safety Pin

REMOVING STANDS

1. Raise the vehicle high enough to clear the stands.
2. Remove the stands being careful not to crawl under the vehicle.
3. Slowly lower the vehicle to the ground.

INSPECTION

Periodically inspect the stands for broken or cracked welds, broken or worn teeth on the ratchet mast or locking mechanism, loose or missing parts. If you notice anything remove the stands from service until repaired or replaced.



©2025 Caterpillar. CAT, CATERPILLAR, and their design marks are registered trademarks of Caterpillar Inc.
©2025 Caterpillar. CAT, CATERPILLAR, and their design marks are registered trademarks of Caterpillar Inc.

Alltrade Pacific Co., Ltd.
Distributed by Conrad Electronic SE
Klaus-Conrad-Str. 1 D-92240 Hirschau
www.conrad.de



importer information



©2025, Alltrade Tools, LLC
Reno, NV 89508

www.catpremiumproducts.com
Made in China / Made in China