



Data Sheet - TRU Components


BN: 3367838

Last updated: 24 Mar 2025

Dia. 19 mm, Flat head push button



Drawing:

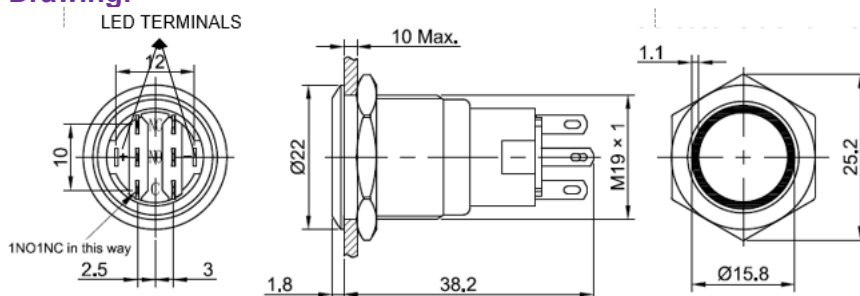

Unit: mm

10 max: means the panel thickness, the max. thickness for the panel no more than 10 mm.

Technical data:

Mounting diameter:	19mm
Head shape	Flat round head
Operation type	Momentary
Contact structure	2NO2NC
Switch rating	3A/250VAC
Illumination type	Ring
LED Colour	Orange
LED Voltage	24V AC/DC
LED Current	about 5mA
Terminal	Soldering Pins
Body material	Stainless steel
Operating and storage temperature	-25 to +55 °C
Base material	PA
IP rating	IP65 (Front panel)
Mechanical lifetime	1,000,000 cycles
Electrical lifetime	50,000 cycles
Dielectric strength	1500V, AC 50HZ, 1 minute
Insulation resistance	≥100MΩ (500VDC)