

LED ELN-RGB 560 PMMA_d-M8d

Art. Nr. 1-000000-06986

Ktl. Nr. 15071014

EAN Nr. 4260654163452

Normen / Norms

DIN EN 60598-1 :2021/A11:2022


DIN EN 60529 :1991/A2:2013/AC:2019-02

DIN EN 55015:2019+A11:2020

DIN EN IEC 63000:2018

DIN EN 61547:2009

DIN EN 62471:2009

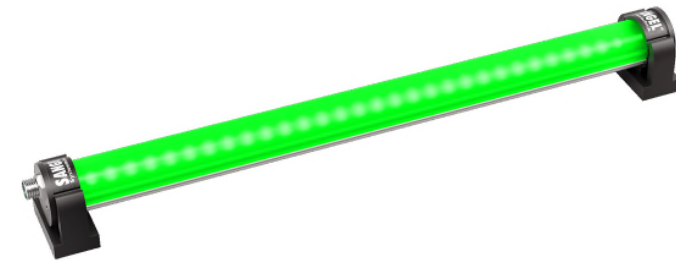

Elektrische Rahmenbedingungen / Electrical characteristic


Netzanschluss / Main Supply	24 VDC
Leistung / Power (R/G/B)	4,2W / 1,8W / 4,8W
Dimmbar / Dimmable	extern PWM
Anschluss / Connection Type	Flansch, M8, 4-Pol, A-Codiert
Kaskadierbar / Cascadable	Ja
Polbild	

Licht / Light

Bestückt / Fitted With	LED
Lichtfarbe / Light Colour	-
Lichtstrom / Luminous Flux (R/G/B)	88lm / 143lm / 58lm
Effizienz / Efficiency	27 lm/W
Abstrahlwinkel / Beam Angle	120°
Farbtreue / Colour Rendering	-
Photobiological Safety	RG-1

Mechanik / Mechanics

Gehäuse / Housing	Aluminium
Abdeckung / Cover	PMMA, Diffus
Befestigung / Fastening	Drehbar
Gewicht(Netto) / Weight(Net)	0,32 kg
Betriebstemperatur / Operating Temp.	-20°C / +50°C
Lebensdauer / Lifetime	min. 60000 h
Zubehör / Equipment	2x Endhalter

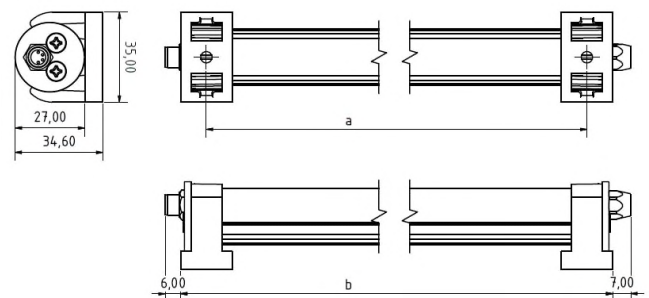

a= 570mm b= 586,5mm