


LED SL-RGBW 140 S-PMMA-d-M8d-57

Art. Nr. 1-000000-07378

Ktl. Nr. 15071062

EAN Nr. 4260654164480

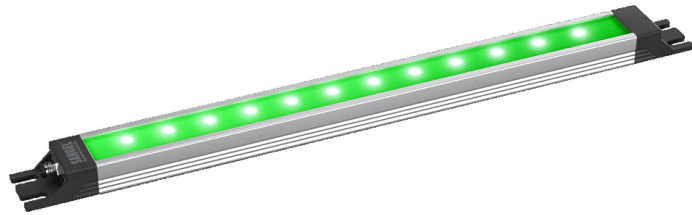

Normen / Norms

DIN EN 60598-1 :2021/A11:2022

DIN EN 60529 :1991/A2:2013/AC:2019-02

DIN EN 55015:2019+A11:2020

DIN EN IEC 63000:2018

DIN EN 61547:2009

DIN EN 62471:2009




Elektrische Rahmenbedingungen / Electrical characteristic

Netzanschluss / Main Supply	24 VDC
Leistung / Power (W/R/G/B)	2,9W / 1,6W / 1,3W / 1,3W
Dimmbar / Dimmable	extern PWM
Anschluss / Connection Type	Flansch, M8, 5-Pol, B-Codiert
Kaskadierbar / Cascadable	Ja
Polbild	


Licht / Light

Bestückt / Fitted With	LED
Lichtfarbe / Light Colour	5700 K
Lichtstrom / Luminous Flux (W/R/G/B)	379lm / 54lm / 135lm / 39lm
Effizienz / Efficiency	87 lm/W
Abstrahlwinkel / Beam Angle	100°
Farbtreue / Colour Rendering	RA / CRI 80
Photobiological Safety	RG-1

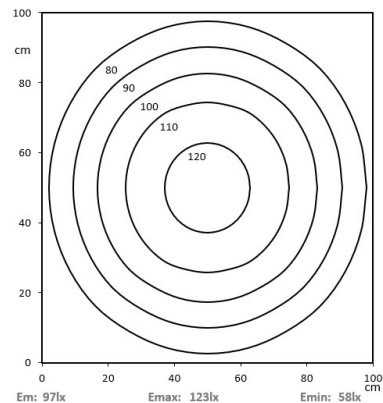

Mechanik / Mechanics

Gehäuse / Housing	Aluminium
Abdeckung / Cover	PMMA, Diffus
Befestigung / Fastening	Starr
Gewicht(Netto) / Weight(Net)	0,13 kg
Betriebstemperatur / Operating Temp.	-20°C / +50°C
Lebensdauer / Lifetime	min. 60000 h
Zubehör / Equipment	-

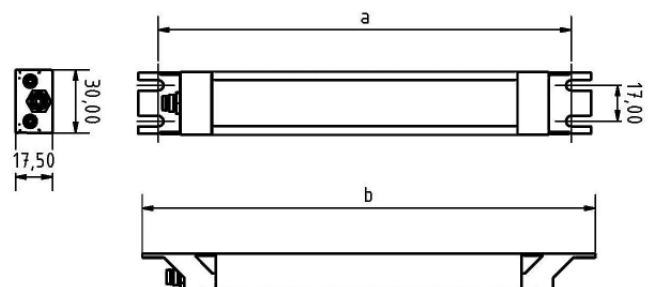

a= 203mm b= 215mm